


## 2104MSBU2

By TradeSelect  
 Catalog Number [2104MSBU2](#)

Steel Stud Device Box, 2-1/2 in. Deep, 25 Cu. In., with MSB Metal Stud Bracket, 2-3/8 & 3-5/8 Stud Size, Cable Pryouts Ends, Raised ground screw, NMD90 and AC90 (20-Pack).

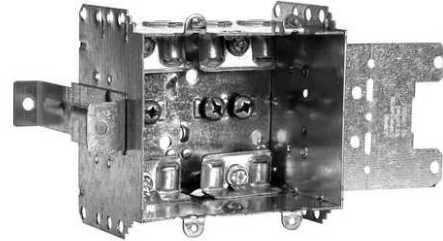

### General

Application	Steel stud boxes are used in Commercial, Residential and Industrial construction.
Bracket Setback	0.4375
Bracket Type	MSB, for Steel Stud
Color	<ul style="list-style-type: none"> <li>• Gray</li> <li>• Gris</li> </ul>
Drawn or Welded	Welded
Ends Cable	8
Gangable	No
Material	Steel
Number of Gang(s)	2-Gang
Plaster Ears	No
Sub Brand	tradeSELECT
Type	Switch Box, Box
UPC	626463020951
Wiring System	Non-Metallic Sheathed (NMD)/ Armoured Cable (AC) 14/2 8/3

### Dimensions

Actual Depth	2.5 in
Raised Ground	Yes
Weight	0.64 lb

### Conductor Related

Cable Entry	Universal Cable Clamps
-------------	------------------------

### Certifications and Compliance

Certified Listed	CSA
Industry Standard(s)	CSA Certified

### Logistics

Carton Quantity	20
Pallet Quantity	720

### Product Assets

[3D Product View](#)

