


Switched Disconnects and Enclosures


Dimensions

Type 1

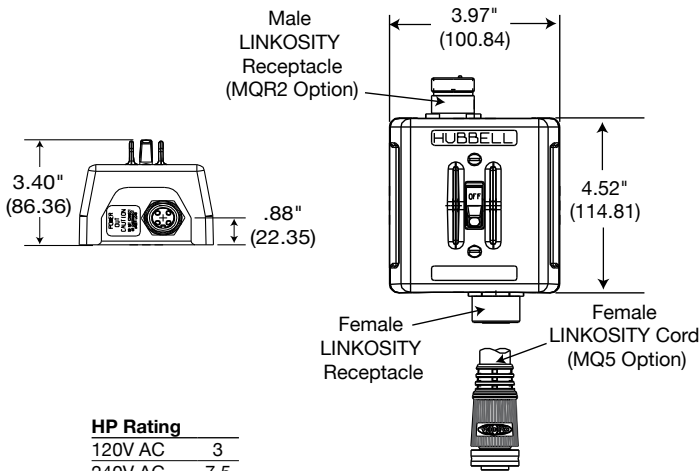

HP Rating	
120V AC	3
240V AC	7.5
480V AC	15
600V AC	20

Type 4X

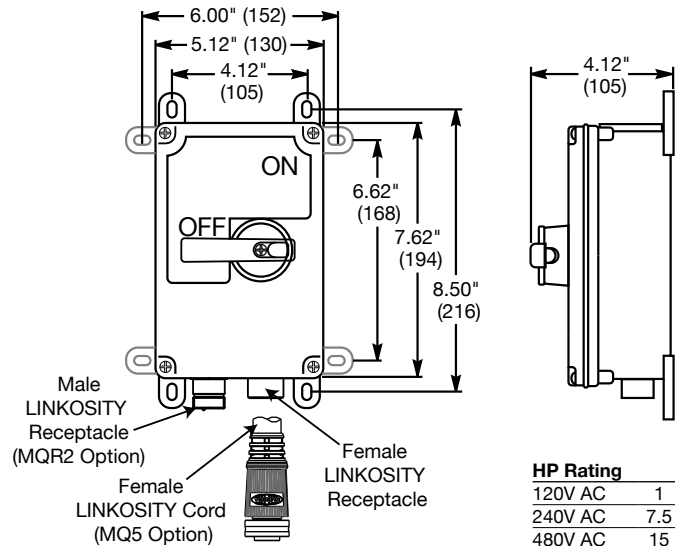

HP Rating	
120V AC	1
240V AC	7.5
480V AC	15
600V AC	15

Hubbell-PRO 30 & 60A Motor Disconnects

Hubbell-PRO motor disconnects are value engineered for commercial and light duty applications. They are available in 30A and 60A versions with optional early break auxiliary contacts for use with VFDs and other auxiliary equipment.

Features

- UL 508 / UL 60947-4-1
- HP Rated
- Type 4X, 12
- Accepts up to 2 Auxiliary Contacts
- OSHA Compliant LO/TO Handle
- Compact, Installation Friendly Enclosure



Ordering Information

Catalog Number	Amps	Description	HP Rating			NO & NC Aux Contacts*	2 NO Aux Contacts*
			240 3ØVAC	480 3ØVAC	600 3ØVAC		
MD30	30 Amp	Disconnect Enclosure	7.5	15	15	MDAC2	MDAC2NO
MD30XL	30 Amp	XL Disconnect Enclosure	7.5	15	15	MDAC2	MDAC2NO
MD60	60 Amp	Disconnect Enclosure	20	40	40	MDAC2	MDAC2NO

*Break before main action

30 Amp Accessories

30 Amp	Catalog Number
Ground Module	MDGB
Neutral Pole	MDNB
30A Additional Pole	MD4P

60 Amp Accessories

60 Amp	Catalog Number
Ground Module	MD60GB
Neutral Pole	MD60NB

Materials

Cover	Polycarbonate
Base	Polycarbonate
Handle	Polycarbonate
Assy. Screws	Stainless Steel

Dimensions in Inches (mm)