


Countertop Receptacles

| Description | Finish | Color/Material | 15A 125V Receptacle | | 20A 125V Receptacle | |
|--|---------------|----------------|---------------------|------------------|---------------------|------------------|
| | | | Surface Mount | Flush Mount | Surface Mount | Flush Mount |
| Tamper-resistant pop-up kitchen counter receptacle, rated for 20A circuits Cover: machined aluminum, wiring chamber accepts 1/2" MC or non-metallic sheath cable | Powder Coated | Black | RCT200BK | RCT201BK | RCT220BK | RCT221BK |
| | | White | RCT200W | RCT201W | RCT220W | RCT221W |
| | | Bronze | RCT200BZE | RCT201BZE | RCT220BZE | RCT221BZE |
| | Brushed | Aluminum | RCT200ALU | RCT201ALU | RCT220ALU | RCT221ALU |
| | | Brass | RCT200BR | RCT201BR | RCT220BR | RCT221BR |
| | | Nickel | RCT200NI | RCT201NI | RCT220NI | RCT221NI |
| | Polished | Chrome | RCT200CH | RCT201CH | RCT220CH | RCT221CH |

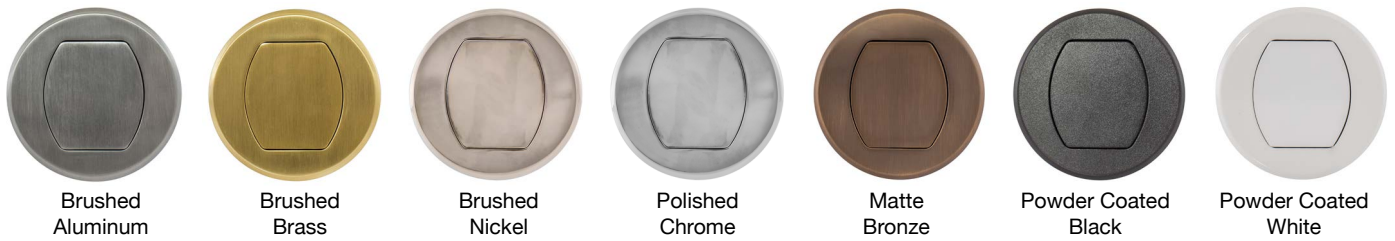

RCT200BK



| | | | | | | |
|--|---------------|----------|------------------|---|------------------|---|
| Tri-Power AC, includes: tamper-resistant pop-up kitchen counter receptacle, USB Type AC and wireless inductive, rated for 20A circuits Cover: machined aluminum, wiring chamber accepts 1/2" MC or non-metallic sheath cable; surface mount only | Powder Coated | Black | RCT600BK | — | RCT620BK | — |
| | | White | RCT600W | — | RCT620W | — |
| | | Bronze | RCT600BZE | — | RCT620BZE | — |
| | Brushed | Aluminum | RCT600ALU | — | RCT620ALU | — |
| | | Brass | RCT600BR | — | RCT620BR | — |
| | | Nickel | RCT600NI | — | RCT620NI | — |
| | Polished | Chrome | RCT600CH | — | RCT620CH | — |



RCT221ALU



RCT600NI

Customizable Color Kits

Installable in surface mount option only, available in 7 different finishes



Note: Recommended to be fed by a GFCI circuit, up to 20 Amp Service.

Dimensions in Inches (mm)