

# UCP PUCK

Single LED Puck, 130 Lumens, 2 Watt  
Cove, Under Cabinet & Millwork

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

## Features

### Puck Light

A 2 watt LED puck maintains a cool to the touch LED. The LEDs are rated for 50,000 hours. The opal glass shield provides for even lighting.

### Light Output

This LED puck light is available in warm white (3000 K) or neutral white (4000 K) colour temperature, providing 130 lumen output, 120° beam angle.

### Linkability

Any two puck lights may be linked together with a maximum distance of 52". Up to five pucks from a 12V DC desktop driver (15W max) may be linked in-line (maximum distance from driver to last puck is 10m (33')).

### Mounting

These pucks can be surface mounted or recessed. Surface mounting is achieved with the included mounting ring (mounting hardware included), while recessed mounting is achieved with the pressure clips provided on the puck light.

### Dimming

Dimmable when used with a dimming driver.

### Operating Temperature

-20°C ~ 55°C (-4°F ~ 131°F).

### Approvals

cETLus listed.

SPECIFICATION	
Application	Under Cabinet
Approved Location	Indoor / Dry
Beam Angle	120°
CCT	3000 K / 4000 K
Certification	cETLus
Color	BK / BRN / CH / MN / PB / WH
CRI	80+
Dimming	Yes
Hole Cut	Ø 2 <sup>3</sup> / <sub>16</sub> " (59mm)
Input	12V DC
Lumens	Up to 130
Lumens per Watt	Up to 65
Projected Life	70% @ 50,000 hrs
Warranty	3 Years
Wattage	2W




## Description

This LED puck light provides an even warm light that delivers enough illumination for any work surface or display, all while consuming less energy than their halogen equivalent. They provide task or accent illumination in residential and commercial indoor applications.



**Notes:** Accessories sold separately. For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

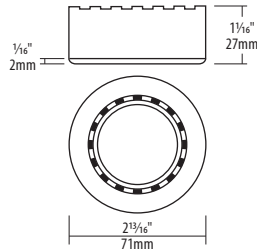

2<sup>3</sup>/<sub>16</sub>"  
59mm

## Ordering Guide



**UCP-LED1-BK**  
Single black LED puck light, 3000 K.



**UCP-LED1-4K-BK**  
Single black LED puck light, 4000 K.



**UCP-LED1-BRN**  
Single brown LED puck light, 3000 K.



**UCP-LED1-4K-BRN**  
Single brown LED puck light, 4000 K.



**UCP-LED1-CH**  
Single chrome LED puck light, 3000 K.



**UCP-LED1-4K-CH**  
Single chrome LED puck light, 4000 K.



**UCP-LED1-MN**  
Single matte nickel LED puck light, 3000 K.



**UCP-LED1-4K-MN**  
Single matte nickel LED puck light, 4000 K.



**UCP-LED1-PB**  
Single polished brass LED puck light, 3000 K.



**UCP-LED1-4K-PB**  
Single polished brass LED puck light, 4000 K.



**UCP-LED1-WH**  
Single white LED puck light, 3000 K.



**UCP-LED1-4K-WH**  
Single white LED puck light, 4000 K.

OnCloud Driver Kit 



**OC-HWB-24WUCP-1C**

100-240VAC, 24W 1-Channel 12VDC  
OnCloud driver kit, powers and controls wireless dimming and on/off capability through WiZ app, Room Controller and smart speakers.

OnCloud Adapter 



**LC-DVR-CV96W1UCP-1C**

12V, 1-Channel OnCloud adapter , controls dimming and on/off capability through WiZ app, Room Controller and smart speakers.

Power feed required



**UCP-LED-6-EL**

LED extension lead with bare wire.

Accessories



**LED-TP10-WH**

12W LED in-line driver, 12V, white.



**LED-DVR-DIM-12V-20W**

20W LED dimmable in-line driver.



**LED-EL16-WH**

LED extension lead.



**LED-HWB12-WH**

LED hardwire box.



**LED-HWB-DIM-12V-20W**

20W LED dimmable hardwire box.



**UCP-LED-6-EL**

LED extension lead with bare wire.



**UCT-LED24**

24W LED in-line driver.