

## DA2012

DELTA LED Track Fixture  
Track Systems

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

### Features

#### Body

Constructed of aluminum, the body features an aesthetically pleasing smooth cylindrical shape. Includes a CCT selectable switch (2700K, 3000K, 3500K, 4000K, 5000K).

#### Beam Spread

The fixture is available in 25° and 38° beam spread for optimal light distribution.

#### Dimming

The track fixture is 100~10% dimmable when used with TRIAC/ELV dimming controls (Consult factory for compatible dimmers).

#### Adjustability

Adjustable up to 90° tilt and 358°

rotation to allow for spotlight into multiple directions.

#### LED Characteristics

Available in 12 Watt LED engine maintains uniform intensity with a typical luminous flux up to 1010 lumens, with up to 90 CRI.

#### Compatibility

Fixture is provided with a A-style, LL-style connector. For other configurations, please refer to ordering guide.

#### Labels

- cETLus


SPECIFICATION	
Application	Track
Approved Location	Dry / Indoor
Beam Angle	25° / 38°
CCT	2700 K - 3000 K - 3500 K - 4000 K - 5000 K
Certification	cETLus
Colour	BK / SL / WH
CRI	90
Dimming	Yes
Dimming Tech	TRIAC/ELV
Energy Star	Yes
LM80	Yes
Lumens	Up to 1010
Lumens per Watt	Up to 84
Power Factor	≥0.97
Primary Voltage	120
Projected Life	50,000 hrs
Rotation	358°
Tilt	90°
TM-30 Annex E	P2V-/F2
Warranty	5 Years
Wattage	12W

Color Temp.	Lumens
2700 K	890
3000 K	940
3500 K	990
4000 K	1010
5000 K	1005



### Description

DELTA is an aluminum designer track fixture with up to 12 watt LED module. It provides directional light source for specific aiming and assures a secure lock on the angle position. Includes a CCT selectable switch.

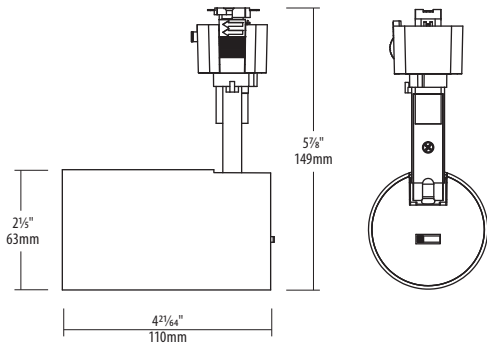

**JA8**  
TITLE 24

ICES-005



### Ordering Guide

#### Connector Type

- DA2012 - CCT

#### Beam Angle

T -

#### Finish Color



**QUICKSHIP**  
7-DAY

Highlighted option denotes Quick Ship.

- A : A-Line (ATK Track)
- LL : Liteline (TK Track)
- H : H-style
- L : L-style

- 25 : 25°
- 38 : 38°

- BK : Black
- WH : White
- SL : Silver

#### Notes:

Quick Ship option is available on orders of 100 pieces or less, and will ship within 5 business days. Options must be selected from Quick Ship section to qualify.

For additional options please consult your Liteline representative. All trademarks are the property of their respective owners. Halo is a registered trademark of Cooper Lighting. Lightolier is a registered trademark of Philips.

Due to our continued efforts to improve our products, product specifications are subject to change without notice.


Liteline Corporation  
Copyright © 2023  
All rights reserved.

Telephone  
416.996.1856  
1.866.730.7704

Fax  
905.709.5255  
1.888.738.9736

[LITELINE.COM](http://LITELINE.COM)

DA2012-CCT25T-WH : 12W DELTA TRACK FIXTURE, 25° BEAM SPREAD, WHITE

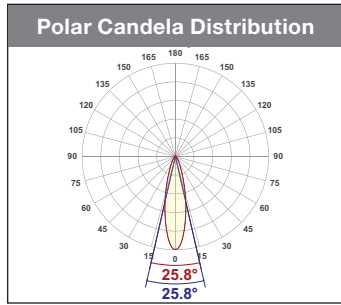


**Beam Details**

D	Lux	FC	L	W
4'	1928	179	1.8'	1.8'
8'	482	45	3.7'	3.7'
12'	214	20	5.5'	5.5'
16'	121	11	2.2'	2.2'
20'	77	7	9.2'	9.2'

**Zonal Lumen Summary**

Zone	Lumens	% Luminaire
0-30	717	78.36%
0-40	818	89.40%
0-60	900	98.36%
60-90	11.7	1.28%
70-100	5.07	0.55%
90-120	0.979	0.11%
0-90	912	99.67%
90-180	2.32	0.25%
0-180	915	100.00%

DA2012-CCT38T-WH : 12W DELTA TRACK FIXTURE, 38° BEAM SPREAD, WHITE

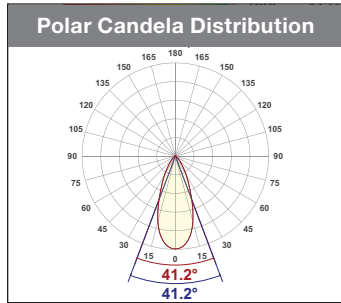

**Beam Details**

D	Lux	FC	L	W
4'	999	93	3'	3'
8'	250	23	6'	6'
12'	111	10	9'	9'
16'	62	6	12'	12'
20'	40	4	15'	15'

**Zonal Lumen Summary**

Zone	Lumens	% Luminaire
0-30	669	72.56%
0-40	805	87.31%
0-60	902	97.83%
60-90	17.2	1.87%
70-100	7.12	0.77%
90-120	0.920	0.10%
0-90	919	99.67%
90-180	2.41	0.26%
0-180	922	100.0%