


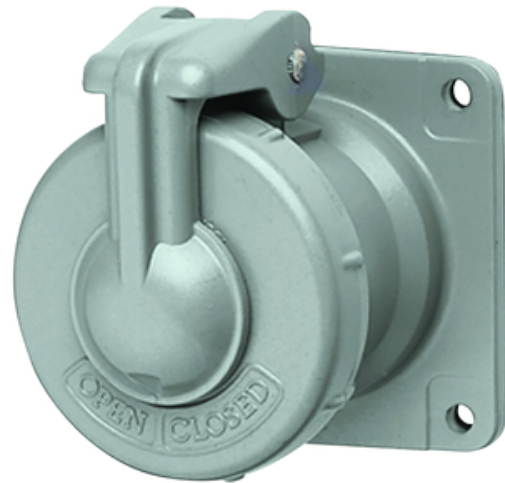

## Versamate Series 150A 3 Pole 4 Wire Receptacle Assembly

By Killark  
Catalog # [VRA15034](#)

150A 3 Pole 4 Wire Receptacle Assembly.



### Features

Boxes come with a green grounding screw.

### General

EU RoHS Indicator	Contact Manufacturer
Finish Type	Finition époxy/polyester en poudre cuite
Material	Body-Copper-free aluminum; Contacts-Brass; Spring tensioner-Patented beryllium copper; External screws-316 stainless steel
Series	VersaMate
Style	Style II
Type	
UPC	783936084046

### Dimensions

Dimensions	5.37 in x 4.25 in x 4.75 in
Height	4.75 in
Length	5.37 in
Weight	4 lb
Width	4.25 in

### Electrical Ratings

Amperage Rating	150 A
Frequency Rating	50-400 Hz
Voltage Rating	<ul style="list-style-type: none"><li>• 600 VAC</li><li>• 250 VDC</li></ul>

### Conductor Related

Number Of Wires	3
-----------------	---

### Product Assets

[Certifications - VRA Series 150A Versamate UL Certification](#)  
[Certifications - CSA Certificate - 150 Amp Versamate](#)  
[Customer Notices - Prop 65 Notice](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
KILL\_CA-VRA15034-SPEC-EN | REV 5/2024