




Versamate Series 200A 3 Pole 4 Wire Plug Assembly

By Killark
Catalog # [VP204612](#)

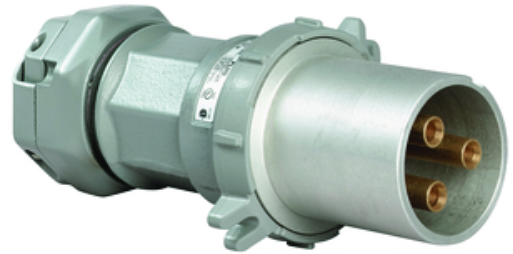

200A 3 Pole 4 Wire Plug Assembly.

*Representative Image

Features

- Feature an octagonal body style, ensuring a sure grip when connecting or disconnecting.
- Insulators have high mechanical and dielectric strength.
- “Increased Safety” type box terminals with gripper ribs securely clamp around conductors.
- Funneled conductor entry chambers lead all properly stripped conductors into terminals simultaneously.
- Type 4X rating when inserted into VersaMate receptacle and locking ring is tightened.
- Includes suitability for Type P marine cable.

Application

Suitable for indoor or outdoor use. Applications include the wet, cold, hosedown, hazardous or corrosive areas in such industrial applications as: Pulp & Paper Mills, Electrical Power Plants, Petrochemical Plants, Wastewater Treatment, Marine, Docks, Ports, Construction Sites, Breweries, Refineries, Chemical Plants, Grain Facilities, Textile Manufacturing, Food Processing Facilities

General

Finish Type	Baked Powder Epoxy/Polyester Finish
Grommet Range	1.0-2.5
Material	Body-Copper-free aluminum; Contacts-Brass; Spring tensioner-Patented beryllium copper; External screws-316 stainless steel
Series	VersaMate
Style	Style II
Type	<ul style="list-style-type: none">• Pin & Sleeve• Pin & Sleeve
UPC	783936833064

Dimensions

Dimensions	12.62 in x 6.38 in x 6.38 in
Height	6.38 in
Length	12.62 in
Width	6.38 in

Electrical Ratings

Amperage Rating	200 A
Frequency Rating	50-400 Hz
Voltage Rating	<ul style="list-style-type: none">• 600 VAC• 250 VDC

Conductor Related

Number Of Wires	3
-----------------	---

Product Assets

[Certifications - Versamate Series UL Certification](#)
[Certifications - CSA Certificate - 200 Amp Versamate Series](#)
[Customer Notices - Prop 65 Notice](#)
[Installation Manuals - Versamate 200 Amp IOM K1206](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
KILL_CA-VP204612-SPEC-EN | REV 1/2024