




Versamate Series 30A 3 Pole 4 Wire Receptacle - AT Type

By Killark
Catalog # [VR3034](#)

30A 3 Pole 4 Wire Receptacle - AT Type.

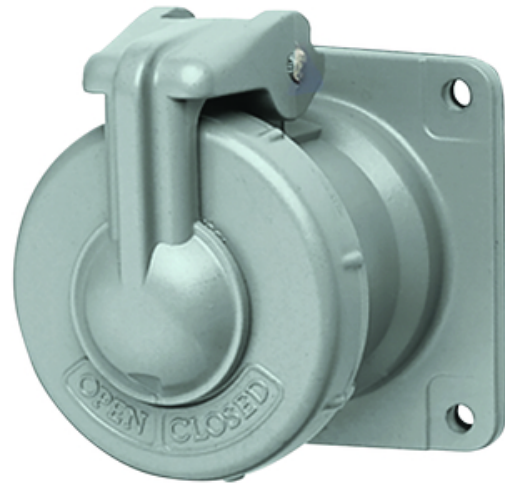

General

EU RoHS Indicator	Contact Manufacturer
Finish Type	Finition époxy/polyester en poudre cuite
Material	Body-Copper-free aluminum; Contacts-Brass; Spring tensioner-Patented beryllium copper; External screws-316 stainless steel
Series	VersaMate
Style	Style II
Type	
UPC	783936078823

Dimensions

Dimensions	3.25 in x 3.41 in x 3.89 in
Height	3.89 in
Length	3.25 in
Weight	1.48 lb
Width	3.41 in

Electrical Ratings

Amperage Rating	30 A
Frequency Rating	50-400 Hz
Voltage Rating	<ul style="list-style-type: none">• 600 VAC• 250 VDC

Conductor Related

Number Of Wires	3
-----------------	---

Product Assets

[Customer Notices - Prop 65 Notice](#)
[Installation Manuals - Versamate 30 Amp Allen Terminal IOM K1381](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
KILL_CA-VR3034-SPEC-EN | REV 5/2024