

47CM-60

15 Amp, 277 Volt, Single Locking Receptacle, Industrial Grade

15 Amp, 277 Volt, NEMA L7-15R, 2P, 3W, Single Locking Receptacle, Industrial Grade, Grounding, Corrosion-Resistant - YELLOW

Leviton's Industrial Grade Locking Devices are built to provide unparalleled quality and superior performance in the most severe industrial settings. Leviton combines the best materials available with superior production standards to produce a broad selection of Locking Devices of unmatched flexibility and dependability.



UPC Code : 078477106679

Country Of Origin : Mexico

NEMA :  L7-15R

Technical Information

AC Horsepower Ratings

At Rated Voltage : 2 HP

Electrical Specifications

Amperage : 15 A

Current Limiting : Full Rated Current

Dielectric Voltage :
Withstands 2000V per UL498

Grounding : Grounding

Pole : 2

Temperature Rise : Max 30C
after 250 cycles OL at 200
percent rated current

Voltage : 277 VAC

Wire : 3

Environmental Specifications

Environment : Corrosive

Flammability : Rated V-0 per
UL 94

Operating Temperature : -40°
C to 60°C

Material Specifications

Base Material : Nylon

Color : Yellow

Face Material : Nylon

Grounding Screw : Nickel-
Plated Brass 8-32

Line Contacts : Nickel-Plated
Brass .040 Thick

Strap Material : Nickel-Plated
Brass

Terminal Screws : Nickel-
Plated Brass 10-32

Yoke : Nickel-Plated Brass .
050 Thick

Mechanical Specifications

Product ID : Ratings and
NEMA I.D. permanently marked
on device

Product Features

Body Material : Nylon

Color : Yellow

Screw Terminal Torque : 14-18 in-lbs

NEMA : L7-15R

Terminal Accom. : 18-10 AWG

Termination : Side

Terminal ID : Brass-Hot,
Green-Ground, Silver-Neutral

Warranty : 10-Year Limited

Termination : Side

Standards and Certifications

ANSI : C-73

CSA C22.2 No. 42 : File LR-406

NEMA : WD-6


NOM : 057

UL Fed Spec WC-596 : File E13399

UL498 : File E13399

Warranty : 10-Year Limited

Wiring Diagram

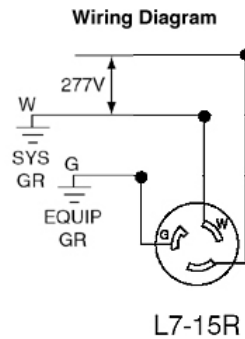

SPECIFICATION SUBMITTAL

<p>JOB NAME:</p> <input type="text"/>	<p>CATALOG NUMBERS:</p> <input type="text"/>
<p>JOB NUMBER:</p> <input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.
T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·
FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)
5386- 1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2024 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:
www.leviton.com/international/contacts

© 2024 Leviton Manufacturing Co., Inc.