



# 47CM-10

15 Amp, 125 Volt, Single Locking Receptacle, Industrial Grade

15 Amp, 125 Volt, NEMA L5-15R, 2P, 3W, Single Locking Receptacle, Industrial Grade, Grounding, Corrosion-Resistant - YELLOW

Leviton's Industrial Grade Locking Devices are built to provide unparalleled quality and superior performance in the most severe industrial settings. Leviton combines the best materials available with superior production standards to produce a broad selection of Locking Devices of unmatched flexibility and dependability.

UPC Code : 078477811078

Country Of Origin : Mexico

NEMA :  L5-15R

## Technical Information

### AC Horsepower Ratings

**At Rated Voltage** : 1/2 HP

### Electrical Specifications

**Amperage** : 15 A

**Current Limiting** : Full Rated Current

**Dielectric Voltage** :  
Withstands 2000V per UL498

**Grounding** : Grounding

**Pole** : 2

**Temperature Rise** : Max 30C  
after 250 cycles OL at 200  
percent rated current

**Voltage** : 125 VAC

**Wire** : 3

### Environmental Specifications

**Environment** : Corrosive

**Flammability** : Rated V-0 per  
UL 94

**Operating Temperature** : -40°  
C to 60°C

### Material Specifications

**Base Material** : Nylon

**Color** : Yellow

**Face Material** : Nylon

**Grounding Screw** : Nickel-  
Plated Brass 8-32

**Line Contacts** : Nickel-Plated  
Brass .040 Thick

**Strap Material** : Nickel-Plated  
Brass

**Terminal Screws** : Nickel-  
Plated Brass 10-32

**Yoke** : Nickel-Plated Brass .  
050 Thick

### Mechanical Specifications

**Product ID** : Ratings and  
NEMA I.D. permanently marked  
on device

### Product Features

**Body Material** : Nylon

**Color** : Yellow

**Screw Terminal Torque :** 14-18 in-lbs

**NEMA :** L5-15R

**Terminal Accom. :** 18-10 AWG

**Termination :** Side

**Terminal ID :** Brass-Hot, Green-Ground, Silver-Neutral

**Warranty :** 10-Year Limited

**Termination :** Side

Standards and Certifications

**ANSI :** C-73

**CSA C22.2 No. 42 :** File LR-406

**NEMA :** WD-6


**NOM :** 057

**UL Fed Spec WC-596 :** File E13399

**UL498 :** File E13399

**Warranty :** 10-Year Limited

## Wiring Diagram

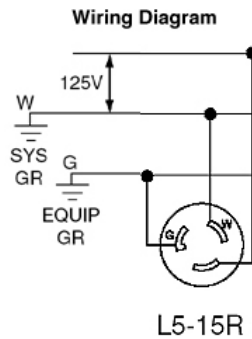

### SPECIFICATION SUBMITTAL

<p><b>JOB NAME:</b></p> <input type="text"/>	<p><b>CATALOG NUMBERS:</b></p> <input type="text"/>
<p><b>JOB NUMBER:</b></p> <input type="text"/>	<input type="text"/>

#### Leviton Manufacturing Co., Inc

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.

T. Monday-Friday): +1-800-824-3005

#### Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

#### Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)

5386- 1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)

© 2024 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:  
[www.leviton.com/international/contacts](http://www.leviton.com/international/contacts)

© 2024 Leviton Manufacturing Co., Inc.