

4765-C

15 Amp, 125 Volt, Straight Blade Connector, Industrial Grade

15 Amp, 125 Volt / 10 Amp, 250 Volt, Non-NEMA, 3P, 3W, Connector, Straight Blade, Industrial Grade, Non-Grounding - BLACK-WHITE

ROHS Compliant : Yes

- One piece contacts reduce friction and overheating
- Unique cord clamp accepts wide range of cord sizes
- Rugged nylon construction resists impact, sunlight, chemicals, and rough use
- 10-year limited warranty

Technical Information

Electrical Specifications

Amperage : 15 A

Current Interrupting : Certified for current interrupting at full rated current

Dielectric Voltage : Withstands 2000V per UL498

Grounding : Non-Grounding

Pole : 3

Temperature Rise : Max 30C after 250 cycles OL at 200 percent rated current

Voltage : 125 VAC

Wire : 3

Material Specifications

Assembly Screws : Steel, Zinc Plated

Back Cover : Thermoplastic

Blades/Contacts : Solid Brass

Body Material : Impact Modified Nylon

Clamp Insert : Nylon

Color : Black-White

Cord-Clamp : Nylon

Terminal Screws : Brass

Wire Module : Nylon

Product Features

Brand : Black and White

Environmental Specifications

Environment : Dry

Flammability : Rated HB or better UL94

Operating Temperature : -40° C to 60°C

Mechanical Specifications

Cord Range : .245 - .700

Product ID : Ratings and NEMA I.D. permanently marked on device

Terminal Accom. : 18-10 AWG

Terminal ID : Brass-Hot, Green-Ground, Silver-Neutral

Standards and Certifications

ANSI : C-73



UPC Code : 078477477441

Country Of Origin : Mexico

NEMA : Non-NEMA

Color : Black-White

CSA C22.2 No. 42 : File LR-406

Device Type : Straight Blade
Connector

NEMA : WD-6

NEMA : Non-NEMA


NOM : 057

UL 498 : File E13399

UL Fed Spec WC-596 : File
E13393

Warranty : Limited Lifetime
Warranty Warranty

Dimensional Drawing

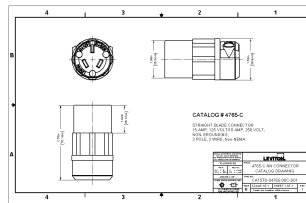

SPECIFICATION SUBMITTAL

JOB NAME: <input type="text"/>	CATALOG NUMBERS: <input type="text"/>	<input type="text"/>
JOB NUMBER: <input type="text"/>	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.
T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·
FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)
5386- 1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2024 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without
notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts

© 2024 Leviton Manufacturing Co., Inc.