



LED PAR20

5.5PAR20/COR/F40/927-922/DIM/P/T20 6/1FB

Philips is driving the switch to energy-efficient solutions. Upgrade your track and accent lights with our small diameter reflectors for instant energy savings and unbeatable quality. Available in both Glass and Plastic casings, Philips LED Par20s are the ideal replacement for halogen.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	25,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
Light Technical	
Color Code	922-927 [CCT of 2200K-2700K]
Beam Angle (Nom)	40 degree(s)
Luminous Flux	600 lm
Luminous Intensity (Nom)	800 cd
Color Designation	Warm Glow(WG)
Luminous Efficacy (rated) (Nom)	109 lm/W
Correlated Color Temperature (Nom)	2200 2700 K
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power Consumption	5.5 W
Lamp Current (Nom)	65 mA
Wattage Equivalent	50 W

Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V
Temperature	
Ambient temperature range	-40 to +113 °F
T-Case Maximum (Nom)	185 °F
Controls and Dimming	
Dimmable	Only with specific dimmers
Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	PAR20
UL Wet/ damp/ dry location	Damp location
Approval and Application	
Suitable For Accent Lighting	Yes
EU RoHS compliant	Yes
T20 compliant	Yes

LED PAR20

Application Conditions


can it be used in closed luminaires Yes

Product Data

Order product name	5.5PAR20/COR/F40/927-922/DIM/P/T20 6/1FB
Full product name	5.5PAR20/COR/F40/927-922/DIM/P/T20 6/1FB
Order code	586362


Material Nr. (12NC)	929003739404
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.11 lb
EAN/UPC - Product/Case	046677586362
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677586367

Dimensional drawing

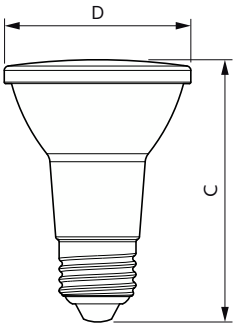


Product	D	C
5.5PAR20/COR/F40/927-922/DIM/P/T20 6/1FB	2-9/16 inch	3-7/16 inch

Photometric data

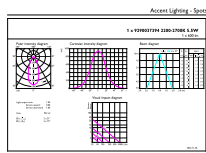

Accent Lighting - Spots
Page 11

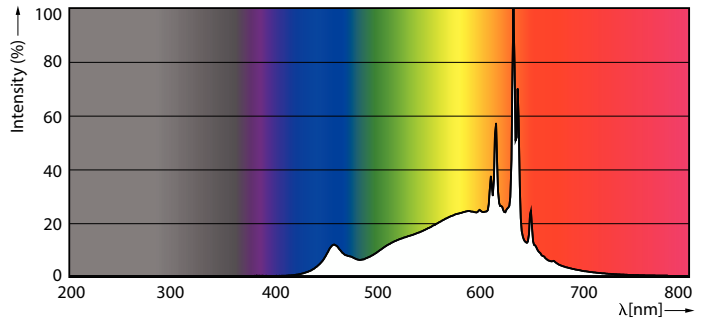


Accent Lighting Spots - 5.5PAR20/COR/F40/927-922/DIM/P/T20 6/1FB

Spectral Power Distribution Colour - 5.5PAR20/COR/
F40/927-922/DIM/P/T20 6/1FB


LED PAR20

Photometric data

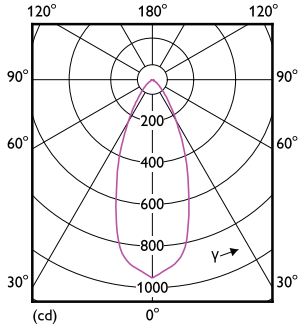


Light Distribution Diagram - 5.5PAR20/COR/F40/927-922/DIM/P/T20
6/1FB

Lifetime

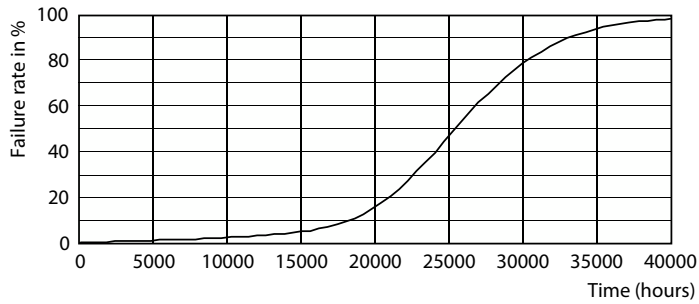

Life Expectancy Diagram

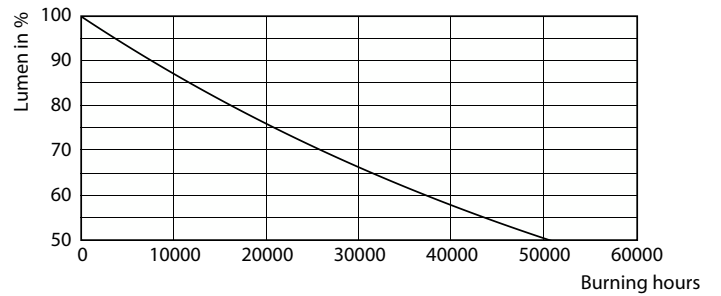

Lumen Maintenance Diagram - 5.5PAR20/COR/F40/927-922/DIM/P/T20
6/1FB

