



Contractor-grade Plastic (Dimmable) A-Shape Lamps

11A19/CNG/840/FR/P/E26/D 12/1CT

Plastic A19 offering dimmability and a lifetime over 15,000 hours. Ideal for contractor-grade residential and multi-family spaces.

Product data


General Information		Lamp Current (Nom)	
Cap-Base	E26		115 mA
Nominal lifetime	15,000 hour(s)	Wattage Equivalent	75 W
Switching Cycle	50,000	Starting Time (Nom)	0.5 s
Lighting Technology	LED	Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.7
		Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	840 [CCT of 4000K]	Ambient temperature range	-4 to +113 °F
Beam Angle (Nom)	180 degree(s)	T-Case Maximum (Nom)	221 °F
Luminous Flux	1,100 lm		
Color Designation	Cool White (CW)	Controls and Dimming	
Luminous Efficacy (rated) (Nom)	100 lm/W	Dimmable	Only with specific dimmers
Correlated Color Temperature (Nom)	4000 K		
Color Consistency	<6	Mechanical and Housing	
Color rendering index (CRI)	80	Bulb Finish	Frosted
LLMF At End Of Nominal Lifetime (Nom)	70 %	Bulb Material	Plastic
		Bulb Shape	A19
Operating and Electrical		UL Wet/ damp/ dry location	Damp location
Input Frequency	60 Hz		
Power Consumption	11 W		

Contractor-grade Plastic (Dimmable) A-Shape Lamps

Approval and Application	
EU RoHS compliant	Yes
T20 compliant	No
Application Conditions	
can it be used in closed luminaires	No
Product Data	
Order product name	11A19/CNG/840/FR/P/E26/D 12/1CT
Full product name	11A19/CNG/840/FR/P/E26/D 12/1CT



Order code	589705
Material Nr. (12NC)	929003751964
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.071 lb
EAN/UPC - Product/Case	046677589707
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677589702

Dimensional drawing

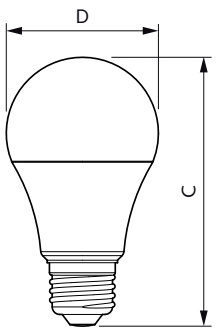

Product	D	C
11A19/CNG/840/FR/P/E26/D 12/1CT	2-3/8 inch	4-3/16 inch

Photometric data

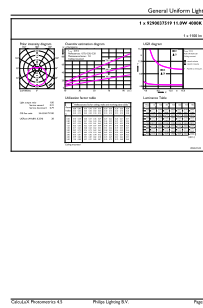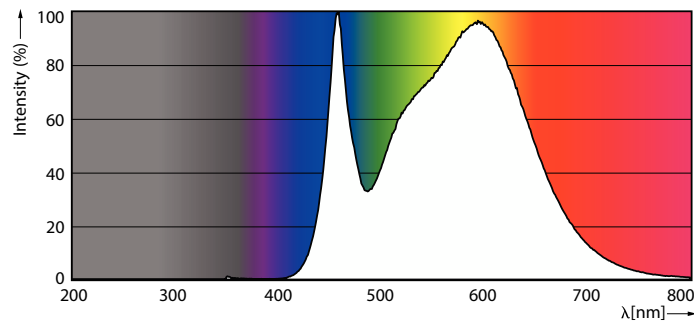


Spectral Power Distribution Colour - 11A19/CNG/840/FR/P/E26/D 12/1CT

General uniform lighting - 11A19/CNG/840/FR/P/E26/D 12/1CT

Contractor-grade Plastic (Dimmable) A-Shape Lamps

Photometric data

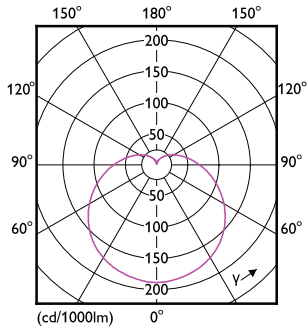

Light Distribution Diagram - 11A19/CNG/840/FR/P/E26/D 12/1CT

Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram - 11A19/CNG/840/FR/P/E26/D 12/1CT

