



LED PAR38

10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Product data

General Information		Temperature	
Cap-Base	E26 [Single Contact Medium Screw]	Warm-up time to 60% light	0.5 s
Nominal lifetime	25,000 hour(s)	Power Factor (Fraction)	0.7
Switching Cycle	50,000	Voltage (Nom)	120 V
Lighting Technology	LED	Temperature	
Light Technical		Ambient temperature range	-40 to +113 °F
Color Code	930 [CCT of 3000K]	T-Case Maximum (Nom)	176 °F
Beam Angle (Nom)	40 degree(s)	Controls and Dimming	
Luminous Flux	1,000 lm	Dimmable	Only with specific dimmers
Luminous Intensity (Nom)	1,900 cd	Mechanical and Housing	
Color Designation	White (WH)	Bulb Finish	Clear
Luminous Efficacy (rated) (Nom)	100 lm/W	Bulb Material	Plastic
Correlated Color Temperature (Nom)	3000 K	Bulb Shape	PAR38
Color Consistency	<4	UL Wet/ damp/ dry location	Wet location
Color rendering index (CRI)	90	Approval and Application	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Suitable For Accent Lighting	Yes
Operating and Electrical		EU RoHS compliant	Yes
Input Frequency	60 Hz	T20 compliant	Yes
Power Consumption	10 W		
Lamp Current (Nom)	120 mA		
Wattage Equivalent	90 W		
Starting Time (Nom)	0.5 s		

LED PAR38

Application Conditions


can it be used in closed luminaires Yes

Product Data

Order product name	10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB
Full product name	10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB
Order code	586248


Material Nr. (12NC)	929003738204
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.287 lb
EAN/UPC - Product/Case	046677586249
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677586244

Dimensional drawing

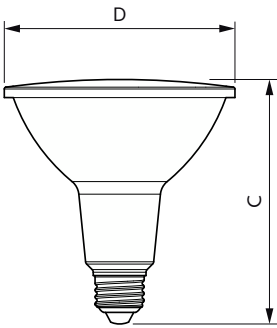


Product	D	C
10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB	4-7/8 inch	5-1/8 inch

Photometric data

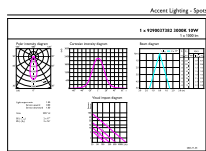

Spotlight Performance 111 Photo Lighting Ltd Page 117


Accent Lighting Spots - 10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

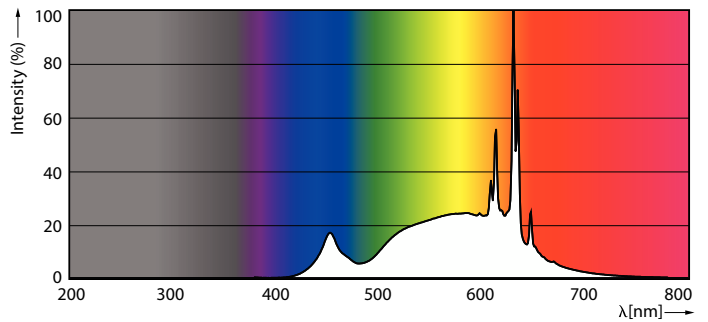

Spectral Power Distribution Colour -
10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

LED PAR38

Photometric data

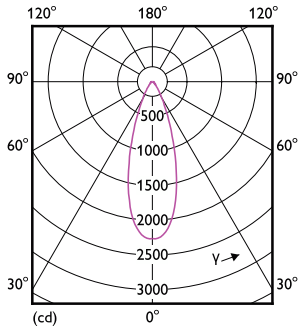

Light Distribution Diagram - 10PAR38/COR/930/F40/DIM/P/ULW/T20
6/1FB

Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram - 10PAR38/COR/930/F40/DIM/P/ULW/T20
6/1FB

