



LED PAR38

13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	25,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
EU RoHS compliant	Yes
Light Technical	
Color Code	927 [CCT of 2700K]
Beam Angle (Nom)	40 degree(s)
Luminous Flux	1,300 lm
Luminous Intensity (Nom)	2,450 cd
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	100 lm/W
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power Consumption	13 W
Lamp Current (Nom)	150 mA
Wattage Equivalent	120 W

Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V

Temperature	
Ambient temperature range	-40 to +113 °F
T-Case Maximum (Nom)	185 °F

Controls and Dimming	
Dimmable	Only with specific dimmers

Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	PAR38
UL Wet/ damp/ dry location	Wet location

Approval and Application	
Suitable For Accent Lighting	Yes
T20 compliant	Yes

LED PAR38

Application Conditions


can it be used in closed luminaires Yes

Product Data

Order product name	13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB
Full product name	13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB



Order code	586123
Material Nr. (12NC)	929003737004
Numerator - Quantity Per Pack	1
EAN/UPC - Product/Case	046677586126
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677586121

Dimensional drawing

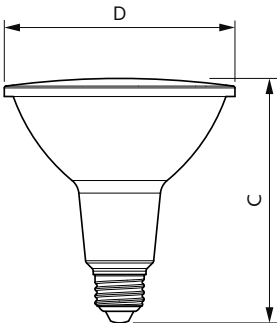

Product	D	C
13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB	4-7/8 inch	5-1/8 inch

Photometric data

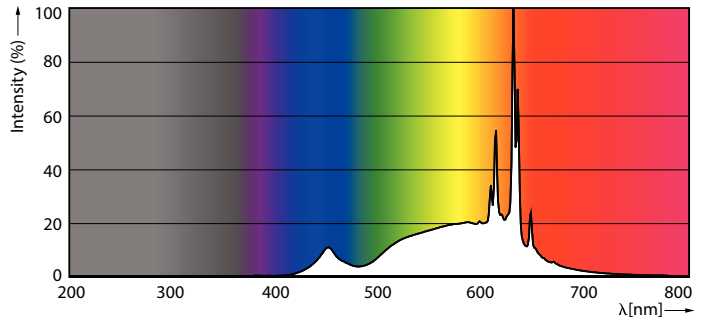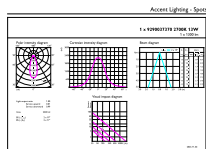


Accent Lighting Spots - 13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB

Spectral Power Distribution Colour - 13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB


LED PAR38

Photometric data

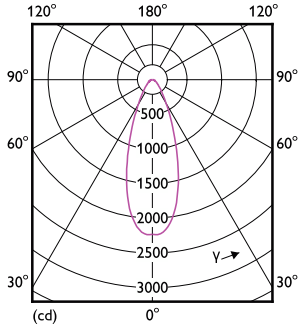


Light Distribution Diagram - 13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB

Lifetime

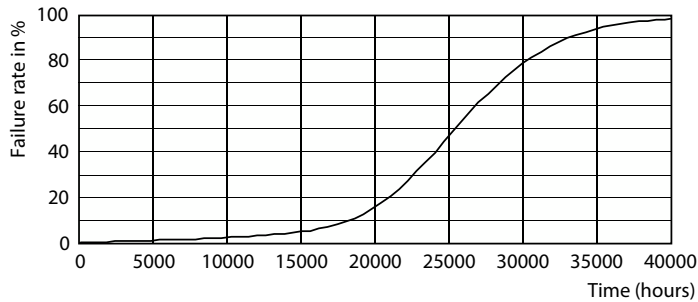

Life Expectancy Diagram - 13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB

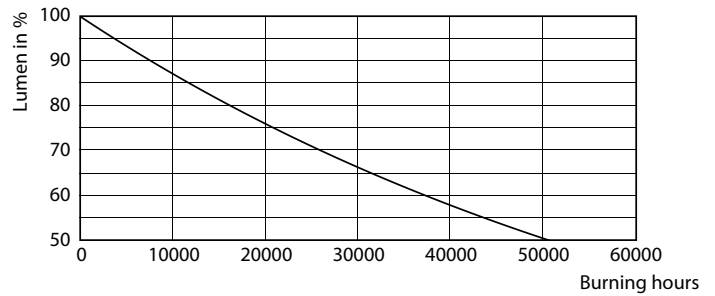

Lumen Maintenance Diagram - 13PAR38/COR/927/F40/DIM/P/ULW/T20 6/1FB

