



LED PAR30 S/L

8.5PAR30L/LED/940/F40/DIM/GULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

Product data


General Information		Starting Time (Nom)	
Cap-Base	E26 [Single Contact Medium Screw]		0.5 s
Nominal lifetime	25,000 hour(s)	Warm-up time to 60% light	0.5 s
Switching Cycle	50,000	Power Factor (Fraction)	0.9
Lighting Technology	LED	Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	940 [CCT of 4000K]	T-Case Maximum (Nom)	70 °C
Beam Angle (Nom)	40 degree(s)	Controls and Dimming	
Luminous Flux	850 lm	Dimmable	Only with specific dimmers
Luminous Intensity (Nom)	1,600 cd	Mechanical and Housing	
Luminous Efficacy (rated) (Nom)	100.00 lm/W	Bulb Finish	Clear
Color Designation	Cool White (CW)	Bulb Material	Glass
Correlated Color Temperature (Nom)	4000 K	Bulb Shape	PAR30L
Color Consistency	<4	Approval and Application	
Color rendering index (CRI)	90	Suitable For Accent Lighting	Yes
LLMF At End Of Nominal Lifetime (Nom)	70 %	Energy Certifications	Energy Star
		EU RoHS compliant	Yes
Operating and Electrical		Product Data	
Line Frequency	50 to 60 Hz	Order product name	8.5PAR30L/LED/940/F40/DIM/GULW/T20
Input Frequency	50 to 60 Hz		6/1FB
Power Consumption	8.5 W		
Lamp Current (Nom)	80 mA		
Wattage Equivalent	75 W		

LED PAR30 S/L

Full product name	8.5PAR30L/LED/940/F40/DIM/GULW/T20 6/1FB
Order code	567999
Material Nr. (12NC)	929003027404
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.285 kg



EAN/UPC - Product/Case	046677567996
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677567991

Dimensional drawing

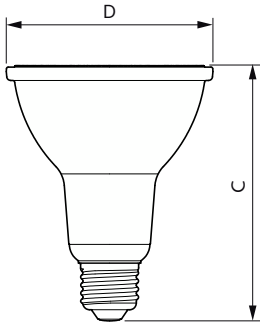


Product	D	C
8.5PAR30L/LED/940/F40/DIM/GULW/T20 6/1FB	94 mm	116 mm

Photometric data

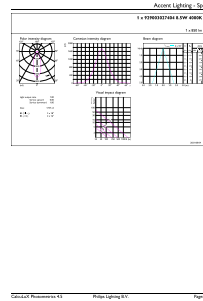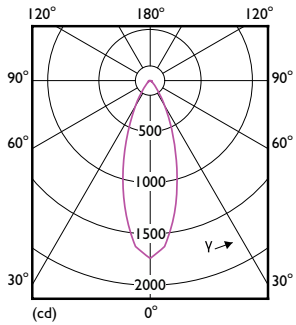

Light Distribution Diagram - 8.5PAR30L/LED/940/F40/DIM/GULW/T20 6/1FB

Accent Lighting Spots - 8.5PAR30L/LED/940/F40/DIM/GULW/T20 6/1FB

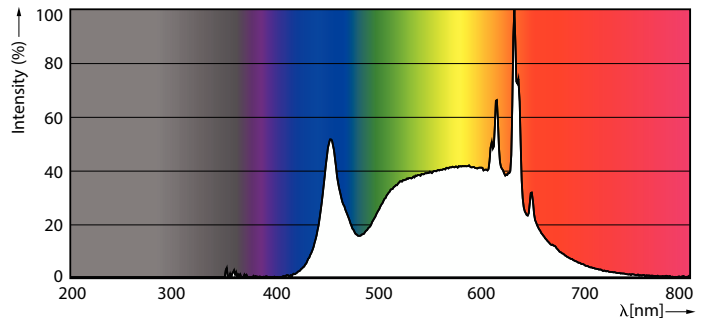

Spectral Power Distribution Colour - 8.5PAR30L/LED/940/F40/DIM/GULW/T20 6/1FB

LED PAR30 S/L

Lifetime



Life Expectancy Diagram

Lumen Maintenance Diagram - 8.5PAR30L/LED/940/F40/DIM/GULW/T20
6/1FB

