









# Juno® Canless









Canless downlights are installed directly into the ceiling which eliminates the need for traditional recessed housings. These IC rated fixtures possess a slim profile that allows for them to install safely and securely into as little as 2" of plenum. No need to purchase a housing, trim, and lamp anymore, simply purchase a canless product for a cost efficient solution. Juno® canless solutions provide an array of product families including: Wafers, Podz, and 1" and 2" LED downlights.



	Application	Size	Trim Style	Lumen	CCT	CRI	Dimming	Install Type	Finishes	Special Applications
<b>Wafers</b>										
 <p>Flat Switchable WF4   WF6</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial	4"	Flat, Modern Aesthetic	670	Switchable White 2700K- 5000K	90	Dimmable to 10% only with Triac Dimmers	Canless Installs directly into ceiling drywall 2" of plenum space needed	Matte White Black Brushed Nickel Oil Rubbed Bronze	
		6"		950						
		8"		1600						
 <p>Flat Switchable/ Adjustable WF2   WF4   WF6</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial	2"	Flat, Modern Aesthetic	Adjustable Lumens 500 675 850	Switchable White 2700K- 5000K	90	Dimming 100% to 10% with most Standard Incandescent Dimmers	Canless Installs directly into ceiling drywall 2" of plenum space needed	Matte White Color Finished Trim Inserts Available	
		4"		Adjustable Lumens 700 900 1100						
		6"		Adjustable Lumens 800 1050 300						
 <p>Regressed WF4   WF6</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial	4"	Regressed, Traditional Aesthetic	670	Switchable White 2700K- 5000K	90	Dimming 100% to 10% with most Standard Incandescent Dimmers	Canless Installs directly into ceiling drywall 2" of plenum space needed	Matte White	
		6"		950						
 <p>Deep Regressed Baffle WF2   WF4   WF6</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial	2"	Deep Regressed Baffle, Traditional Aesthetic	Adjustable Lumens 525 700 900	Switchable White 2700K- 5000K	90	Dimming 100% to 10% with most Standard Incandescent Dimmers	Canless Installs directly into ceiling drywall 3" of plenum space needed	Matte White Color Finished Trim Inserts Available	
		4"		Adjustable Lumens 700 900 1100						
		6"		Adjustable Lumens 967 1091 1123						



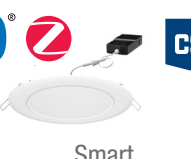







Application	Size	Trim Style	Lumen	CCT	CRI	Dimming	Install Type	Finishes	Special Applications
<b>Wafers</b>									
 <p>Deep Regressed Smooth WF2   WF4   WF6</p>	2"	Deep Regressed Smooth, Traditional Aesthetic	Adjustable Lumens 525 700 900	Switchable White 2700K-5000K	90	Dimming 100% to 10% with most Standard Incandescent Dimmers	Canless Installs directly into ceiling drywall 3" of plenum space needed	Matte White Color Finished Trim Inserts Available	
	4"		Adjustable Lumens 700 900 1100						
	6"		Adjustable Lumens 967 1091 1123						
 <p>Adjustable WF4   WF6</p>	4"	Adjustable, Modern Aesthetic	850	Tunable White 2700K-5000K	90	Dimming down to 10% with most Standard Incandescent Dimmers	Canless Installs directly into ceiling drywall 3" of plenum space needed	Matte White Matte Black	
	6"		1000						
 <p>Smart WF4   WF6</p>	4"	Flat, Modern Aesthetic	650	Tunbale White 2700K-5000K	90	Dimmable to 1% (Not for use with wall dimmers). Perfect for use as a nightlight	Canless Installs directly into ceiling drywall 2" of plenum space needed	Matte White	
	6"		950						



	Application	Size	Trim Style	Lumen	CCT	CRI	Dimming	Install Type	Finishes	Special Applications
<b>Wafers</b>										
<p>Smart Regressed Wafer WF4C   WF6C</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial	4"	Regressed, Modern Aesthetic	640 - 680	Tunable White 2700K- 5000K	90	Dimmable to 1% (Not for use with wall dimmers). Perfect for use as a nightlight	Canless Installs directly into ceiling drywall 2" of plenum space needed	Matte White Black Brushed Nickel Oil Rubbed Bronze	
		6"		944 - 992						
<p>Smart Adjustable Wafer WF4C   WF6C</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial	4"	Adjustable, Modern Aesthetic	770 - 825	Tunable White 2700K- 5000K	90	Dimmable to 1% (Not for use with wall dimmers). Perfect for use as a nightlight	Canless Installs directly into ceiling drywall 2" of plenum space needed	Matte White	
		6"		1085 - 1170						
<b>Podz (Round &amp; Square) JPDZ</b>										
<p>Round &amp; Square Podz JPDZ</p>	Indoor/Outdoor Single Family Multi-Family Light Commercial New Construction & Remodel	4" 5" 6"	Regressed, Traditional Baffle or Smooth Aesthetic Options	Adjustable Lumen Output 700 1000 1200	Switchable White 2700K- 5000K plus WarmDim	90	Dimming 100% to 5% with use of forward, reverse phase or 0-10V Dimmers	Canless Installs directly into ceiling drywall 4" of plenum space needed	Black Clear Haze Wheat Haze White	
<b>2" LED Downlights (Round &amp; Square) 2LED</b>										
<p>2 LED Round Cone</p>	Indoor Single Family Multi-Family Light Commercial New Construction or Remodel	2"	Regressed, Smooth Traditional Aesthetic	600 1000	2700K 3000K 3500K 4000K	80 90	Dimming 100% to 5% with use of forward, reverse phase or 0-10V Dimmers	Canless Installs directly into ceiling drywall 5.5" of plenum space needed	Black Clear Haze Wheat Haze White	
<p>2 LED Round Baffle</p>	Indoor Single Family Multi-Family Light Commercial New Construction or Remodel	2"	Regressed, Baffle Traditional Aesthetic	600 1000	2700K 3000K 3500K 4000K	80 90	Dimming 100% to 5% with use of forward, reverse phase or 0-10V Dimmers	Canless Installs directly into ceiling drywall 5.5" of plenum space needed	Black Bronze Satin Nickel White	
<p>2 LED Round Adjustable</p>	Indoor Single Family Multi-Family Light Commercial New Construction or Remodel	2"	Adjustable, Low profile gimbal Modern Aesthetic	600 1000	2700K 3000K 3500K 4000K	80 90	Dimming 100% to 5% with use of forward, reverse phase or 0-10V Dimmers	Canless Installs directly into ceiling drywall 5.5" of plenum space needed	Black Bronze Satin Nickel White	
<p>2 LED Square Downlight</p>	Indoor Single Family Multi-Family Light Commercial New Construction or Remodel	2"	Regressed, Square Traditional Aesthetic	600 1000	2700K 3000K 3500K 4000K	80 90	Dimming 100% to 5% with use of forward, reverse phase or 0-10V Dimmers	Canless Installs directly into ceiling drywall 5.5" of plenum space needed	Black Bronze Satin Nickel White	
<p>2 LED Square Adjustable</p>	Indoor Single Family Multi-Family Light Commercial New Construction or Remodel	2"	Square Adjustable, Low profile gimbal Modern Aesthetic	600 1000	2700K 3000K 3500K 4000K	80 90	Dimming 100% to 5% with use of forward, reverse phase or 0-10V Dimmers	Canless Installs directly into ceiling drywall 5.5" of plenum space needed	Black Bronze Satin Nickel White	



	Application	Size	Trim Style	Lumen	CCT	CRI	Dimming	Install Type	Finishes	Special Applications
<b>Mini MD1LG2</b>										
 Round MD1LG2 RD	Indoor/Outdoor Single Family Multi-Family Light Commercial	1"	Regressed, Smooth Traditional Aesthetic	300	2700K 3000K 3500K 4000K	80 90	May be dimmed with dimmers tested and qualified by Juno for use with TL602E and MAGXFMR transformers	Canless Installs directly into ceiling drywall 4" of plenum space needed	Black Bronze Satin Nickel White	
 Square MD1LG2 SQ	Indoor/Outdoor Single Family Multi-Family Light Commercial	1"	Regressed, Smooth Traditional Aesthetic	300	2700K 3000K 3500K 4000K	80 90	May be dimmed with dimmers tested and qualified by Juno for use with TL602E and MAGXFMR transformers	Canless Installs directly into ceiling drywall 4" of plenum space needed	Black Bronze Satin Nickel White	
 Adjustable, Round MG1LG2 RD	Indoor Single Family Multi-Family Light Commercial	1"	Adjustable, Round Modern Aesthetic	300	2700K 3000K 3500K 4000K	80 90	May be dimmed with dimmers tested and qualified by Juno for use with TL602E and MAGXFMR transformers	Canless Installs directly into ceiling drywall 4" of plenum space needed	Black Bronze Satin Nickel White	
 Adjustable, Square MG1LG2 SQ	Indoor Single Family Multi-Family Light Commercial	1"	Adjustable, Square Modern Aesthetic	300	2700K 3000K 3500K 4000K	80 90	May be dimmed with dimmers tested and qualified by Juno for use with TL602E and MAGXFMR transformers	Canless Installs directly into ceiling drywall 4" of plenum space needed	Black Bronze Satin Nickel White	

**Notes:**

1. Wet Location is an ordering OPTION for the round and square mini downlights.
2. Mini LED fixtures require an electronic/magnetic transformer (sold separately) to operate