




ROBOGRIP®

by



THE ORIGINAL DESIGN

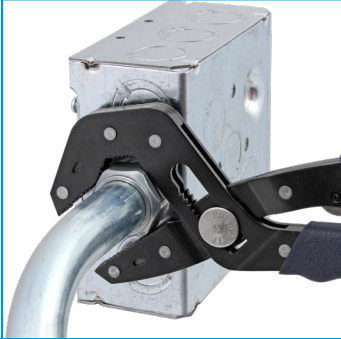

The legacy lives on.

FASTER

Spring loaded for one-handed operation

STRONGER

Laminated steel construction design for extra strength

EASIER

Ergonomically designed handles for superior comfort



35-451

35-450

Part No.	Description
35-450	7 in. Curved Jaw RoboGrip® Self-Adjusting Plier
35-451	10 in. V-Notch Jaw RoboGrip® Self-Adjusting Plier
35-452	2-Pack, 7 in. & 10 in. RoboGrip® Self Adjusting Pliers

THE ELECTRICIAN'S
CHAMPION™



WWW.IDEALIND.COM

MORE TOOLS from

OPEN JAW CABLE CUTTER

- Cuts hard drawn copper up to 600 MCM and soft copper, aluminum and multi-conductor cable up to 750 MCM
- Open jaw for easy access in tight areas
- Hardened steel blades ensure consistent cuts and long-term durability



35-055



LEARN MORE

HEAVY-DUTY FORGED WIRE STRIPPERS

- 45-110 strips: 8-16 AWG solid wire and 10-18 AWG stranded wire
- 45-112 strips: 12/2, 14/2, 12 and 14 AWG wires
- 45-113 strips: 10-18 AWG solid wire & 12-20 AWG stranded wire



45-110

45-113

45-112



LEARN MORE

WIRE STRIPPERS



LEARN MORE

BENDERS



LEARN MORE

FISH TAPES



LEARN MORE

IDEAL® PRO SERIES BAGS



Backpacks



Large Mouth Bags



Tool Carriers



Tool Pouches



Zipper Pouches



LEARN MORE



IDEAL INDUSTRIES, INC.

IDEAL INDUSTRIES, INC.

1800 S. Prairie Drive, Sycamore, IL 60178, USA / 815-895-5181 • 800-435-0705 in USA

International offices:

Australia • Canada • China • India • Mexico • UK

For complete sales office contact information, visit us at:

idealind.com