



T5 High Output

F54T5/850/HO/ALTO 40PK

Philips T5 HO lamps are environmentally-responsible, ultra-slim and have extraordinary light output and longer life.

Warnings and Safety

- Lamp contains mercury.
- Manage in Accord with Disposal Laws.
- See: www.lamprecycle.org or 1-800-555-0050


Product data

General Information	
Cap-Base	G5
Features	HO Alto® [High Output Alto]
Light Technical	
Color Code	850 [CCT of 5000K]
Luminous Flux	4,800 lm
Color Designation	Daylight
Luminous Efficacy (rated) (Nom)	80 lm/W
Correlated Color Temperature (Nom)	5000 K
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	54.1 W
Lamp Current (Nom)	0.455 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	F54T5/850/HO/ALTO 40PK
Full product name	F54T5/850/HO/ALTO 40PK
Order code	135103
Material Nr. (12NC)	927993185022
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.233 lb
EAN/UPC - Product/Case	046677135102
Numerator - Packs per outer box	40
EAN/UPC - Case	50046677135107


T5 High Output

Dimensional drawing

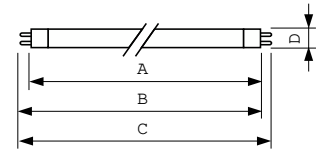


Product	D (max)	A (max)	B (max)	B (min)	C (max)
F54T5/850/HO/ ALTO 40PK	11/16 inch	45-1/4 inch	45-9/16 inch	45-7/16 inch	45-13/16 inch

Photometric data

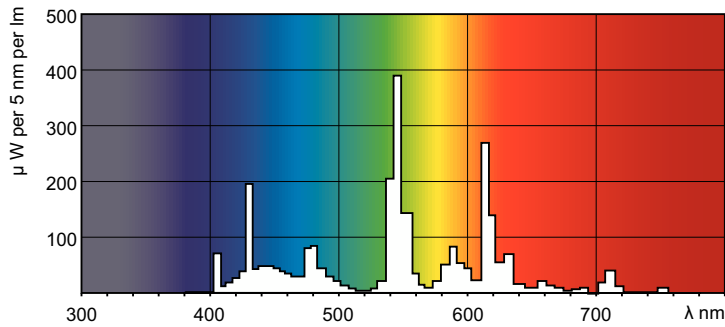


Spectral Power Distribution Colour - F54T5/850/HO/ALTO 40PK

Lifetime

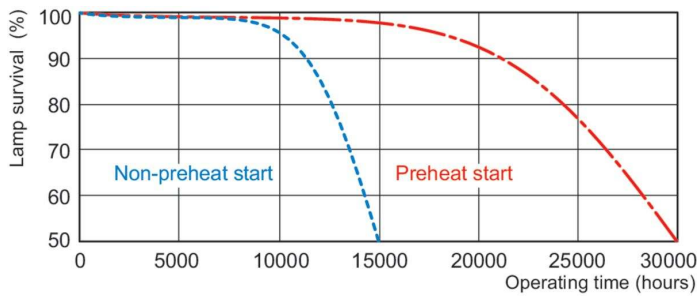

Life expectancy diagram - 3 hour cycle

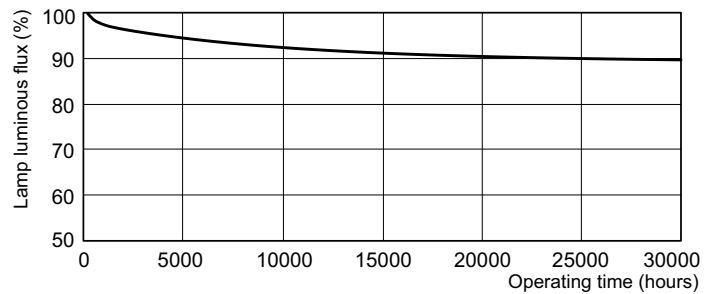

Lumen Maintenance Diagram - F54T5/850/HO/ALTO 40PK

T5 High Output

Lifetime

Life expectancy diagram - 12 hour cycle

