



Contractor-grade Plastic (Dimmable) A-Shape Lamps

8.8A19/CNG/850/FR/P/E26/D 12/1CT

Plastic A19 offering dimmability and a lifetime over 15,000 hours. Ideal for contractor-grade residential and multi-family spaces.

Product data

General Information	
Cap-Base	E26
Nominal lifetime	15,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
Light Technical	
Color Code	850 [CCT of 5000K]
Beam Angle (Nom)	180 degree(s)
Luminous Flux	800 lm
Luminous Efficacy (rated) (Nom)	90 lm/W
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Color Consistency	<6
Color rendering index (CRI)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power Consumption	8.8 W


Lamp Current (Nom)	95 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V
Temperature	
Ambient temperature range	-20 to +45 °C
T-Case Maximum (Nom)	90 °C
Controls and Dimming	
Dimmable	Only with specific dimmers
Mechanical and Housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A19
UL Wet/ damp/ dry location	Damp location

Contractor-grade Plastic (Dimmable) A-Shape Lamps

Approval and Application	
EU RoHS compliant	Yes
T20 compliant	No
Application Conditions	
can it be used in closed luminaires	No
Product Data	
Order product name	8.8A19/CNG/850/FR/P/E26/D 12/1CT
Full product name	8.8A19/CNG/850/FR/P/E26/D 12/1CT



Order code	929003579664
Material Nr. (12NC)	929003579664
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.026 kg
EAN/UPC - Product/Case	046677589653
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677589658

Dimensional drawing

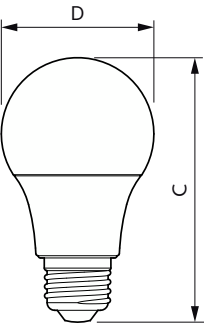

Product	D	C
8.8A19/CNG/850/FR/P/E26/D 12/1CT	60 mm	104 mm

Photometric data

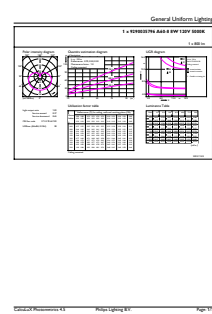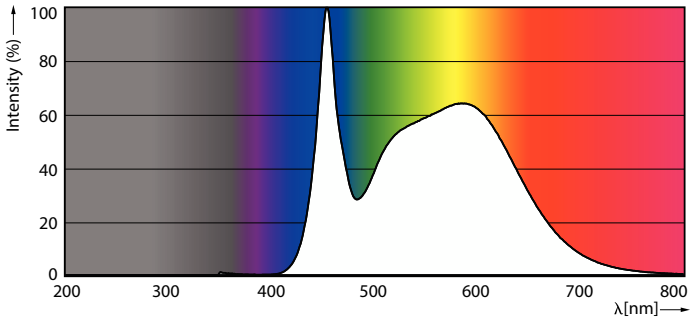


Spectral Power Distribution Colour - 8.8A19/CNG/850/FR/P/E26/D 12/1CT

General uniform lighting - 8.8A19/CNG/850/FR/P/E26/D 12/1CT

Contractor-grade Plastic (Dimmable) A-Shape Lamps

Photometric data

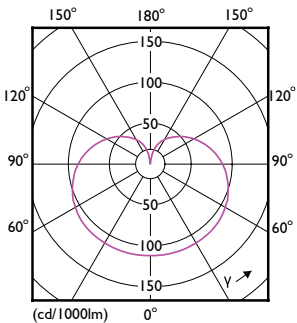


Light Distribution Diagram - 8.8A19/CNG/850/FR/P/E26/D 12/1CT

Lifetime



Life Expectancy Diagram

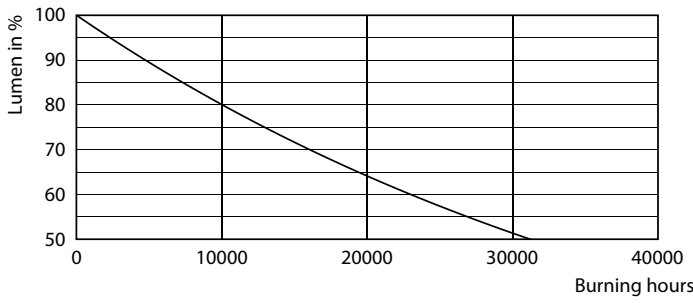

Lumen Maintenance Diagram - 8.8A19/CNG/850/FR/P/E26/D 12/1CT

