

H16,0/22 GN


Weidmüller Interface GmbH & Co. KG

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

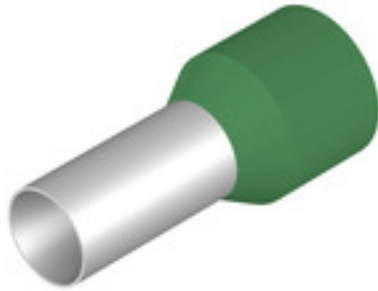

- supplied loose in poly-bag
- Weidmüller colour code
- DIN colour code
- other colour code

General ordering data

Version	Wire-end ferrule, Standard, 15 mm, 12 mm, green
Order No.	0565900000
Type	H16,0/22 GN
GTIN (EAN)	4008 190022 18 1
Qty.	100 pc(s).
Packaging	loose

Creation date July 2, 2024 6:57:14 AM CEST

Catalogue status 29.06.2024 / We reserve the right to make technical changes.

H16,0/22 GN

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 26
 D-32758 Detmold
 Germany

www.weidmueller.com

Technical data

Dimensions and weights

Net weight 0.534 g

Technical data

Description of article	Wire end ferrule with plastic collar, green	Version	Standard
------------------------	---	---------	----------

Wire-end ferrules

Collar diameter (D2)	8.8 mm	Colour code	Weidmüller
Conductor cross-section	16 mm ²	Contact surface diameter (D1)	5.8 mm
Contact surface length (L2)	12 mm	L1 in mm	22 mm
Metal sleeve thickness (S1)	0.2 mm	Military designation	T 20A 025 A
Plastic collar thickness (S2)	0.4 mm	Stripping length	15 mm
Wire connection cross section AWG, max.	AWG 6		

Classifications

ETIM 6.0	EC000005	ETIM 7.0	EC000005
ETIM 8.0	EC000005	ETIM 9.0	EC000005
ECLASS 9.0	27-40-02-01	ECLASS 9.1	27-40-02-01
ECLASS 10.0	27-40-02-01	ECLASS 11.0	27-40-02-01
ECLASS 12.0	27-40-02-01	ECLASS 13.0	27-40-02-01

Environmental Product Compliance

REACH SVHC /

Approvals

Approvals



ROHS	Conform
UL File Number Search	UL Website
Certificate no. (cULus)	E499744

Downloads

Engineering Data	CAD data – STEP
Engineering Data	Zuken E3.S
Catalogues	Catalogues in PDF-format
Brochures	

Data sheet

H16,0/22 GN

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

Drawing

