



Rough / Vibration Service

100A/2P/RS 12/2

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. Rough Service incandescent lamps have an exceptionally strong filament for which a special filament wire is used, which makes these lamps extremely suitable for places where shocks, bumps and vibrations frequently occur. The clear version, with its completely visible filament, is a brilliant light source, whereas the inside-frosted lamp is used wherever well diffused light is required.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Rated Lifetime (Hours)	2,000 hour(s)
Lighting Technology	Incandescent


Operating and Electrical	
Power Consumption	100 W
Voltage (Nom)	130 V

Mechanical and Housing	
Bulb Finish	Frosted
Bulb Shape	A19

Product Data	
Order product name	100A/2P/RS 12/2
Full product name	100A/2P/RS 12/2
Order code	111724
Material Nr. (12NC)	925283534304
Numerator - Quantity Per Pack	2
Net Weight (Piece)	0.032 kg
EAN/UPC - Product/Case	046677286903
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677286908

Rough / Vibration Service

Dimensional drawing

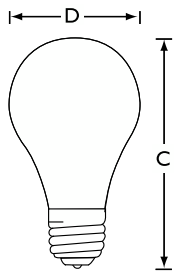

A19

Product	D	C (max)
100A/2P/RS 12/2	2.375 inch	4.438 inch

