



Switch Start Metal Halide Standard

MH1500/U 1/6PK

High performance, Long life and Superior light quality. A compact, energy efficient metal halide lamp that provides crisp, sparkling light with long life and high efficiency.

Warnings and Safety

• R "WARNING: These lamps can cause serious skin burn and eye inflammation from short wave ultraviolet radiation if outer envelope of the lamp is broken or punctured. Do not use where people will remain for more than a few minutes unless adequate shielding or other safety precautions are used. Certain lamps that will automatically extinguish when the outer envelope is broken or punctured are commercially available." This lamp complies with FDA radiation performance standard 21 CFR subchapter J. (USA:21 CFR 1040.30 Canada: SOR/DORS/80-381)

Product data


General Information		Operating and Electrical	
Cap-Base	E39 [Single Contact Mogul Screw]	Lamp Current (Nom)	6.2 A
Operating Position	H15 [Hanging +/-15D or Base Up (BU)]	Voltage (Nom)	268 V
Life to 50% Failures (Nom)	6,000 hour(s)		
Light Technical		Mechanical and Housing	
Color Code	640 [CCT of 4000K]	Bulb Finish	Clear
Luminous Efficacy (rated) (Nom)	113 lm/W	Bulb Material	Hard Glass
Color Designation	White (WH)	Bulb Shape	BT56
Chromaticity Coordinate X (Nom)	0.385		
Chromaticity Coordinate Y (Nom)	0.390	Approval and Application	
Correlated Color Temperature (Nom)	4000 K	Energy Saving Product	Not Applicable
Color rendering index (CRI)	65	Mercury (Hg) Content (Nom)	228.0 mg
Product Data			
Order product name	MH1500/U 1/6PK		

Switch Start Metal Halide Standard

Full product name	MH1500/U 1/6PK
Order code	131623
Material Nr. (12NC)	928601179401
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.400 kg

EAN/UPC - Product/Case	046677131623
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677131628

Dimensional drawing

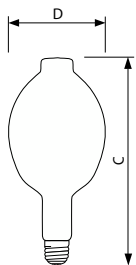

Product	D	C (max)
MH1500/U 1/6PK	7 inch	15.4 inch

