



T5 Standard

F14T5/835/ALTO 40PK

Philips T5 Fluorescent Lamps featuring ALTO® Lamp Technology offer increased energy savings and low toxicity in a slim profile.


Product data

General Information	
Cap-Base	G5
Features	HE Alto® [High Efficiency Alto]
Light Technical	
Color Code	835 [CCT of 3500K]
Luminous Flux	1,350 lm
Color Designation	White (WH)
Luminous Efficacy (rated) (Nom)	86 lm/W
Correlated Color Temperature (Nom)	3500 K
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	14.0 W
Lamp Current (Nom)	0.165 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	14W/835 Min Bipin T5 HE ALTO UNP/40
Full product name	F14T5/835/ALTO 40PK
Order code	230797
Material Nr. (12NC)	927990483522
Numerator - Quantity Per Pack	1
Net Weight (Piece)	54.000 g
EAN/UPC - Product/Case	046677230791
Numerator - Packs per outer box	40
EAN/UPC - Case	50046677230796


T5 Standard

Dimensional drawing

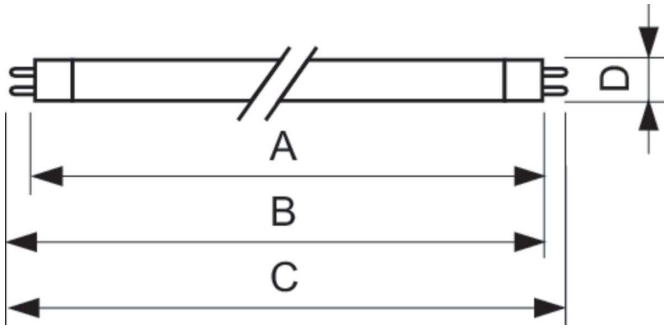


Product	D (max)	A (max)	B (max)	B (min)	C (max)
14W/835 Min Bipin T5 HE ALTO UNP/40	17 mm	549.0 mm	556.1 mm	553.7 mm	563.2 mm

Photometric data

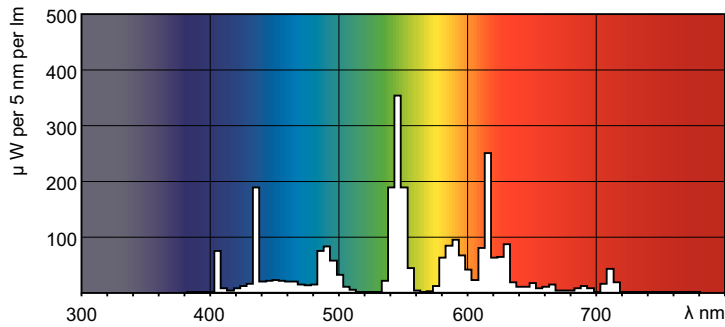


Spectral Power Distribution Colour - 14W/835 Min Bipin T5 HE ALTO UNP/40

Lifetime

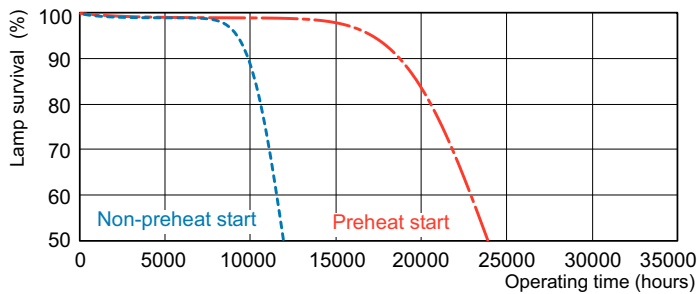


Life expectancy diagram - 3 hour cycle

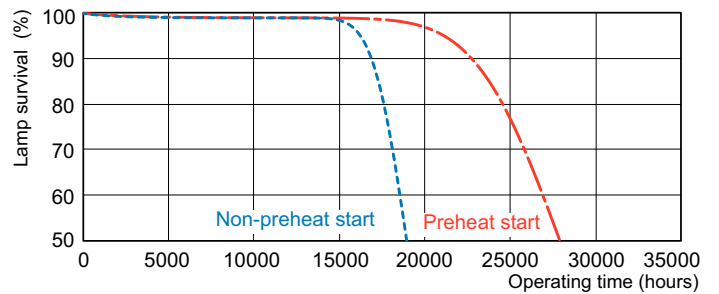

Life expectancy diagram - 12 hour cycle

T5 Standard

Lifetime

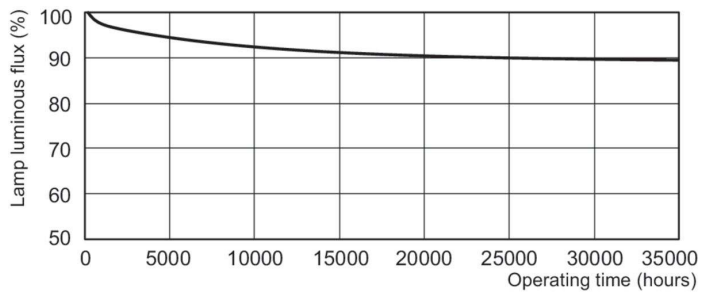

Lumen Maintenance Diagram - 14W/835 Min Bipin T5 HE ALTO UNP/40

