



T5 High Output

F24T5/835/HO/ALTO 40PK

Philips T5 HO lamps are environmentally-responsible, ultra-slim and have extraordinary light output and longer life.


Product data

General Information	
Cap-Base	G5
Features	HO Alto® [High Output Alto]
Light Technical	
Color Code	835 [CCT of 3500K]
Luminous Flux	1,950 lm
Color Designation	White (WH)
Luminous Efficacy (rated) (Nom)	76 lm/W
Correlated Color Temperature (Nom)	3500 K
Color rendering index (CRI)	82
Operating and Electrical	
Power Consumption	22.5 W
Lamp Current (Nom)	0.295 A
Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Shape	T5
Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg
Product Data	
Order product name	24W/835 Min Bipin T5 HO ALTO UNP
Full product name	F24T5/835/HO/ALTO 40PK
Order code	290205
Material Nr. (12NC)	927992183522
Numerator - Quantity Per Pack	1
Net Weight (Piece)	54.000 g
EAN/UPC - Product/Case	046677290207
Numerator - Packs per outer box	40
EAN/UPC - Case	50046677290202


T5 High Output

Dimensional drawing

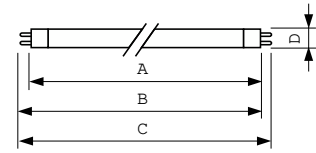


Product	D (max)	A (max)	B (max)	B (min)	C (max)
24W/835 Min Bipin T5 HO ALTO UNP	17 mm	549.0 mm	556.1 mm	553.7 mm	563.2 mm

Photometric data

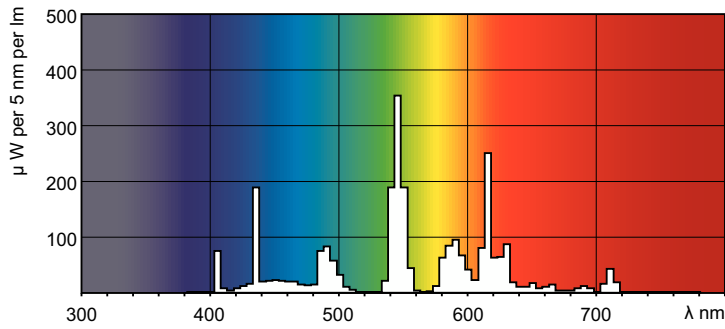


Spectral Power Distribution Colour - 24W/835 Min Bipin T5 HO ALTO UNP

Lifetime

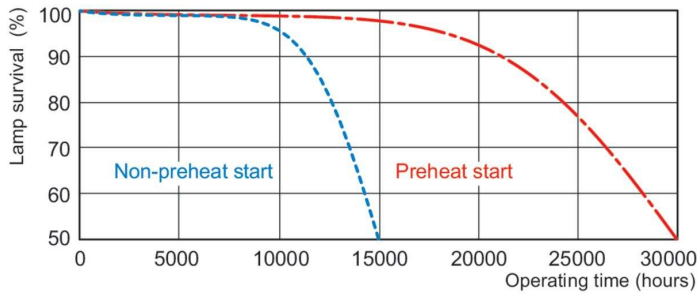

Life expectancy diagram - 3 hour cycle

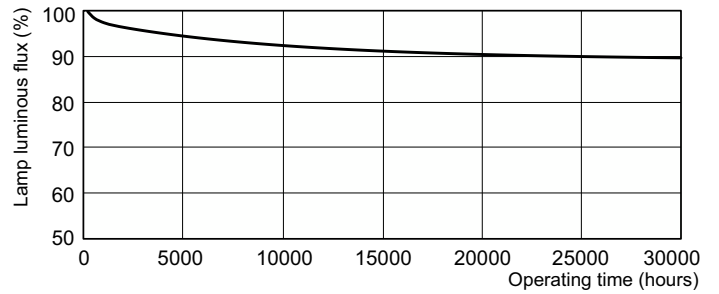

Lumen Maintenance Diagram - 24W/835 Min Bipin T5 HO ALTO UNP

T5 High Output

Lifetime

Life expectancy diagram - 12 hour cycle

