



PL-L Long 4-Pin Base

PL-L 40W/835/4P/RS/IS 1CT/25

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

Product data

General Information	
Cap-Base	2G11
Life to 50% Failures (Nom)	10,000 hour(s)

Light Technical	
Color Code	835 [CCT of 3500K]
Luminous Flux	3,500 lm
Luminous Efficacy (rated) (Nom)	87 lm/W
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3500 K
Color rendering index (CRI)	82


Operating and Electrical	
Power Consumption	40 W
Lamp Current (Nom)	0.320 A
Voltage (Nom)	126 V

Controls and Dimming	
Dimmable	Yes

Product Data	
Order product name	PL-L 40W/835/4P/RS/IS 1CT/25
Full product name	PL-L 40W/835/4P/RS/IS 1CT/25
Order code	300434
Material Nr. (12NC)	927908083529
Numerator - Quantity Per Pack	1
Net Weight (Piece)	140.000 g
EAN/UPC - Product/Case	046677111793
Numerator - Packs per outer box	25
EAN/UPC - Case	50046677111798


PL-L Long 4-Pin Base

Dimensional drawing

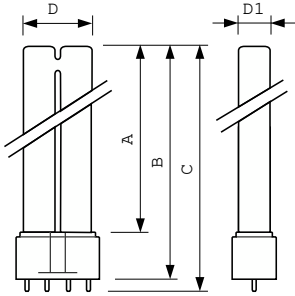

Product	D (max)	D1 (max)	A (max)	B (max)	C (max)
PL-L 40W/835/4P/RS/IS 1CT/25	39.0 mm	18.0 mm	540 mm	565 mm	571.6 mm

Photometric data

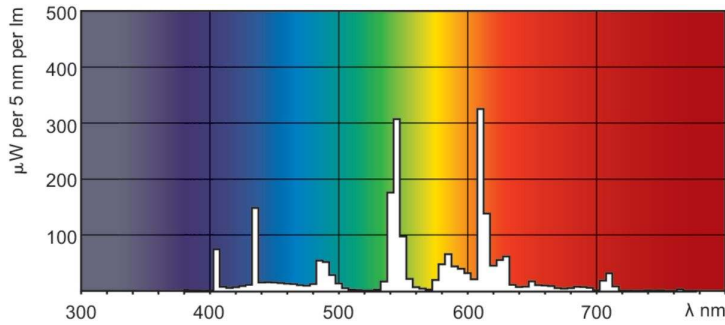

Spectral Power Distribution Colour - PL-L 40W/835/4P/RS/IS 1CT/25

