



T5 Preheat

F8T5/CW PH 25PK

Philips T5 Fluorescent Lamps are incredibly powerful, environmentally responsible, long life lamps with an ultra-slim profile. This translates into reduced maintenance and disposal costs and also allows the use of smaller fixtures—which reduces ceiling clutter.


Product data

General Information		Mechanical and Housing	
Cap-Base	G5	Bulb Shape	T5
Life to 50% Failures (Nom)	10,000 hour(s)		
Light Technical		Approval and Application	
Color Code	33-640	Mercury (Hg) Content (Nom)	4.4 mg
Luminous Flux	410 lm	Energy Consumption kWh/1000 h	8 kWh
Color Designation	Cool White (CW)		
Luminous Efficacy (rated) (Nom)	51 lm/W	Product Data	
Correlated Color Temperature (Nom)	4100 K	Order product name	F8T5/CW PH 25PK
Color rendering index (CRI)	60	Full product name	F8T5/CW PH 25PK
Operating and Electrical		Order code	332478
Power Consumption	7.1 W	Material Nr. (12NC)	928001003321
Lamp Current (Nom)	0.145 A	Numerator - Quantity Per Pack	1
Voltage (Nom)	56 V	Net Weight (Piece)	27.000 g
Controls and Dimming		EAN/UPC - Product/Case	046677114640
Dimmable	Yes	Numerator - Packs per outer box	25
		EAN/UPC - Case	50046677114645


T5 Preheat

Dimensional drawing

Product	D (max)	A (max)	B (max)	B (min)	C (max)
F8T5/CW PH 25PK	16 mm	288.3 mm	295.4 mm	293.0 mm	302.5 mm

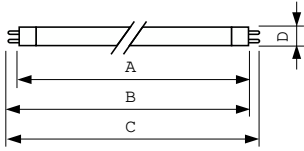

Photometric data

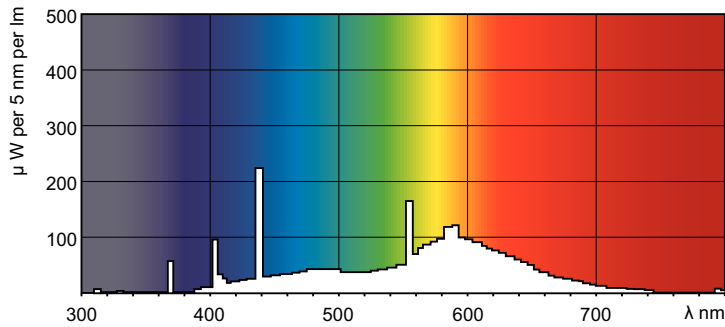

Spectral Power Distribution Colour - F8T5/CW PH 25PK

