



Switch Start Metal Halide Standard

MH150/U/M 12PK

High performance, Long life and Superior light quality. A compact, energy efficient metal halide lamp that provides crisp, sparkling light with long life and high efficiency.

Warnings and Safety

- R "WARNING: These lamps can cause serious skin burn and eye inflammation from short wave ultraviolet radiation if outer envelope of the lamp is broken or punctured. Do not use where people will remain for more than a few minutes unless adequate shielding or other safety precautions are used. Certain lamps that will automatically extinguish when the outer envelope is broken or punctured are commercially available." This lamp complies with FDA radiation performance standard 21 CFR subchapter J. (USA:21 CFR 1040.30 Canada: SOR/DORS/80-381)

Product data


General Information		Operating and Electrical	
Cap-Base	E26 [Single Contact Medium Screw]	Lamp Current (Nom)	1.5 A
Operating Position	UNIVERSAL [Any or Universal (U)]	Voltage (Nom)	110 V
Life to 50% Failures (Nom)	10,000 hour(s)		
Light Technical		Mechanical and Housing	
Color Code	640 [CCT of 4000K]	Bulb Finish	Clear
Luminous Efficacy (rated) (Nom)	90 lm/W	Bulb Material	Hard Glass
Color Designation	White (WH)	Bulb Shape	ED17
Chromaticity Coordinate X (Nom)	0.385		
Chromaticity Coordinate Y (Nom)	0.390	Approval and Application	
Correlated Color Temperature (Nom)	4000 K	Energy Saving Product	Not Applicable
Color rendering index (CRI)	65	Mercury (Hg) Content (Nom)	23 mg
Product Data			
Order product name	MH150/U/M 12PK		

Switch Start Metal Halide Standard

Full product name	MH150/U/M 12PK
Order code	354621
Material Nr. (12NC)	928601179801
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.001 kg

EAN/UPC - Product/Case	046677354626
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677354621

Dimensional drawing

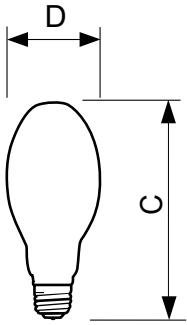

Product	D	C (max)
MH150/U/M 12PK	2.125 inch	5.438 inch

