



MasterColor CDM-R Elite

MASTERColor CDM-R Elite 70W/930 E26/24 PAR30L 40D

The Elite family is at the very top of the MasterColor CDM range, and gives a unique combination of unbeatable light quality and consistent performance over lifetime, while keeping running costs low. MasterColor metal halide lamps deliver consistent white light and higher color rendering than any standard metal halide source for architectural lighting. MasterColor CDM Elite PAR30L lamps deliver similar performance as the MasterColor Elite family lamps in the familiar PAR30L shape.

Warnings and Safety

- R "WARNING: These lamps can cause serious skin burn and eye inflammation from short wave ultraviolet radiation if outer envelope of the lamp is broken or punctured. Do not use where people will remain for more than a few minutes unless adequate shielding or other safety precautions are used. Certain lamps that will automatically extinguish when the outer envelope is broken or punctured are commercially available." This lamp complies with FDA radiation performance standard 21 CFR subchapter J. (USA: 21 CFR 1040.30 Canada: SOR/DORS/80-381)

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Switching Cycle	1,350
Life to 50% Failures (Nom)	15,000 hour(s)
Light Technical	
Color Code	930 [CCT of 3000K]
Beam Angle (Nom)	40 degree(s)
Luminous Intensity (Nom)	9,300 cd

Color Designation	Warm White (WW)
Luminous Efficacy (rated) (Nom)	70 lm/W
Chromaticity Coordinate X (Nom)	0.443
Chromaticity Coordinate Y (Nom)	0.402
Correlated Color Temperature (Nom)	3000 K
Color rendering index (CRI)	92
LLMF At End Of Nominal Lifetime (Nom)	80 %
Luminous Flux in 90° Cone (Rated)	4,400 lm

MasterColor CDM-R Elite

Operating and Electrical

Power Consumption	73.0 W
Warm-up time to 60% light	120 s
Voltage (Nom)	86 V

Controls and Dimming

Dimmable	No
----------	----

Mechanical and Housing

Bulb Finish	Clear
Bulb Shape	PAR30L


Approval and Application

Mercury (Hg) Content (Nom)	6.6 mg
Energy Consumption kWh/1000 h	80 kWh

Product Data


Order product name	MC CDM-R Elite 70W/930 E26 PAR30L 40D
Full product name	MASTERColor CDM-R Elite 70W/930 E26/24 PAR30L 40D
Order code	426544
Material Nr. (12NC)	928109800615
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.220 kg
EAN/UPC - Product/Case	046677426545
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677426540

Dimensional drawing

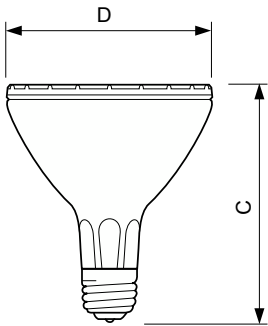


Product	D (max)	C (max)
MC CDM-R Elite 70W/930 E26 PAR30L 40D	97 mm	123 mm

Photometric data

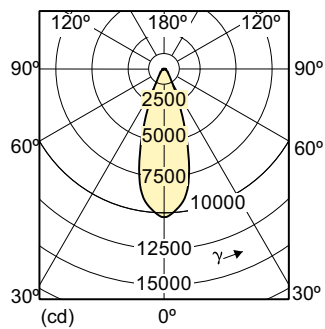



Light Distribution Diagram - MC CDM-R Elite 70W/930 E26 PAR30L 40D

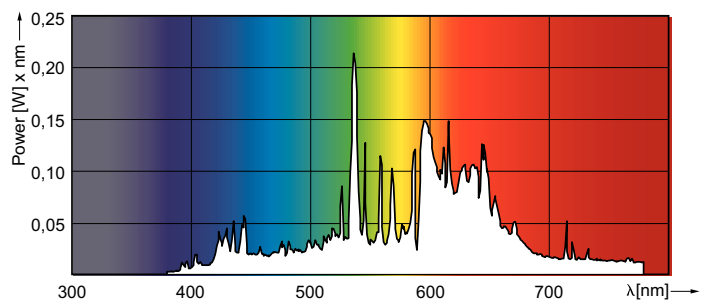

Spectral Power Distribution Colour - MC CDM-R Elite 70W/930 E26 PAR30L 40D

MasterColor CDM-R Elite

Lifetime

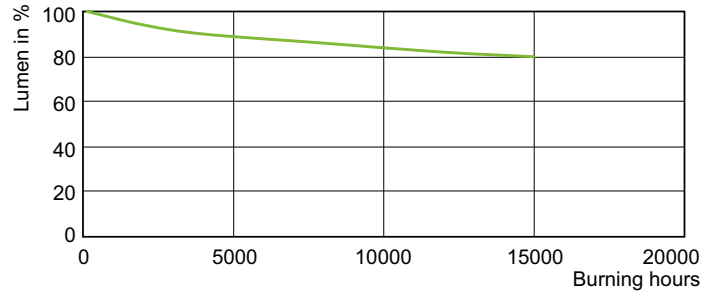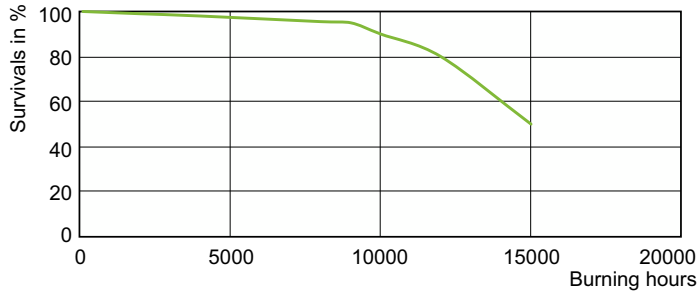

LDLE_CDM-R-E_930_PAR30L-Life expectancy diagram

Lumen Maintenance Diagram - MC CDM-R Elite 70W/930 E26 PAR30L 40D

