



PL-C/T

10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1

Philips PLED 4-pin & 2-pin lamps are an affordable LED solution to replace compact fluorescent lamps. The product provides a natural lighting effect for use in many lighting applications, and provides instant energy savings, making them an environmentally-friendly solution. Available as replacements for 13W, 26W and 32W compact fluorescent lamps.

Product data

General Information		Lamp Current (Min)	
Cap-Base	GX24q		150 mA
Nominal lifetime	50,000 hour(s)	Wattage Equivalent	26 W
Switching Cycle	50,000	Starting Time (Nom)	0.5 s
Lighting Technology	LED	Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.9
		Voltage (Nom)	120 V
		UL Type	UL Type A
Light Technical		Temperature	
Color Code	840 [CCT of 4000K]	Ambient temperature range	-20 °C to 45 °C
Beam Angle (Nom)	120 degree(s)	T-Case Maximum (Nom)	60 °C
Luminous Flux	1,300 lm		
Luminous Efficacy (rated) (Nom)	123.00 lm/W	Controls and Dimming	
Color Designation	Cool White (CW)	Dimmable	Yes
Correlated Color Temperature (Nom)	4000 K		
Color Consistency	<6	Mechanical and Housing	
Color rendering index (CRI)	82	Bulb Finish	Frosted
LLMF At End Of Nominal Lifetime (Nom)	70 %	Bulb Material	Plastic
		Product Length	100 mm
		Bulb Shape	PL-C;PL-T
Operating and Electrical			
Line Frequency	20000-100000 Hz		
Input Frequency	20000-100000 Hz		
Power Consumption	10.5 W		
Lamp Current (Max)	550 mA		

PL-C/T

Approval and Application

Energy Saving Product	Yes
Approval Marks	RoHS compliance UL certificate KEMA Keur certificate DLC compliance
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	DLC Standard
EU RoHS compliant	Yes

Application Conditions


can it be used in closed luminaires	Yes
-------------------------------------	-----

Product Data

Order product name	10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1
--------------------	--



Full product name	10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1
Order code	458430
Material Nr. (12NC)	929001388704
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.091 kg
EAN/UPC - Product/Case	046677458430
Numerator - Packs per outer box	10
EAN/UPC - Case	50046677472820

Dimensional drawing

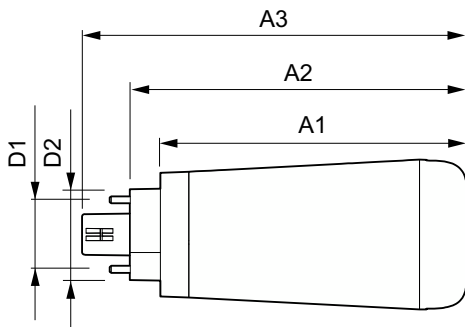

Product	D1	D2	A1	A2	A3
10.5PL-C/T/COR/26V-840/ IF13/P/4P/DIM10/1	24.3 mm	29 mm	99.9 mm	109.9 mm	125.5 mm

Photometric data

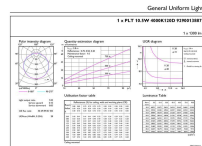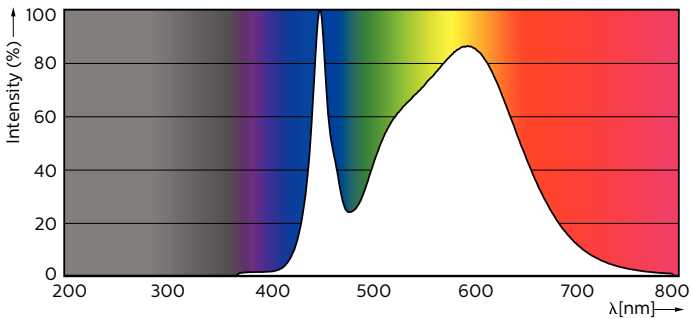


Spectral Power Distribution Colour - 10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1

General uniform lighting - 10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1


PL-C/T

Photometric data

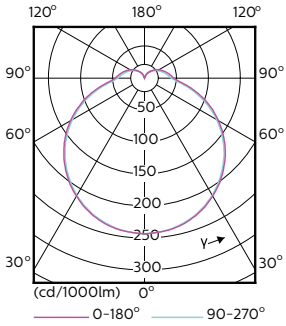


Light Distribution Diagram - 10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1


Lifetime

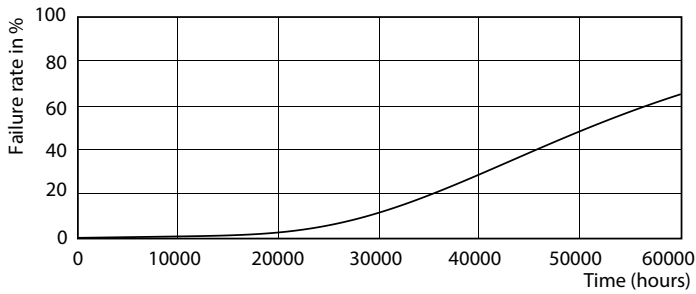


LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

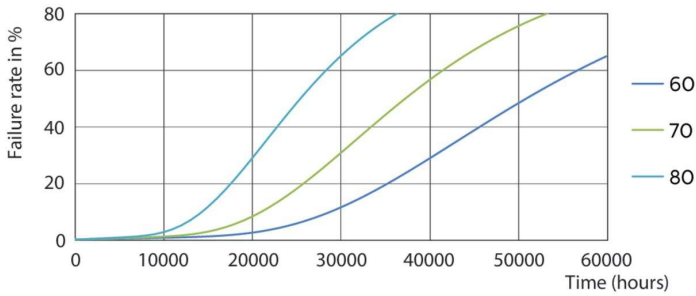

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

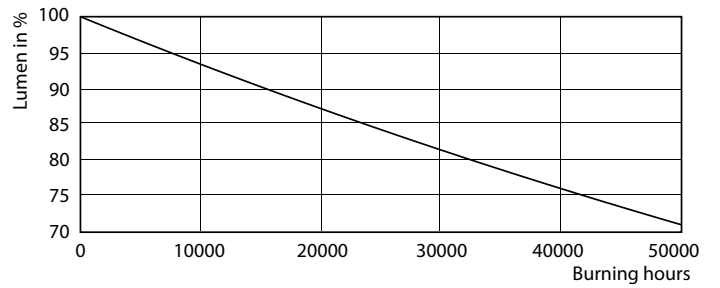


Lumen Maintenance Diagram - 10.5PL-C/T/COR/26V-840/IF13/P/4P/DIM10/1

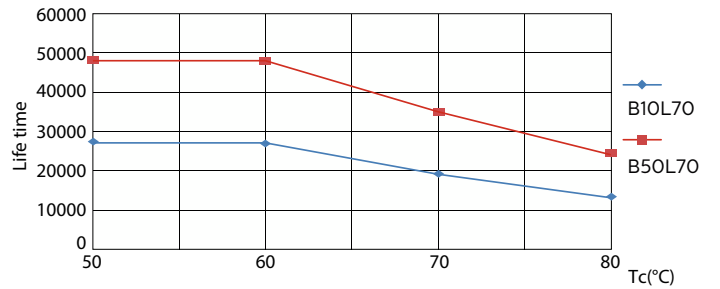

LEDtube PLC 100mm 9W G24Q GX24Q 827 850lm

PL-C/T

Lifetime

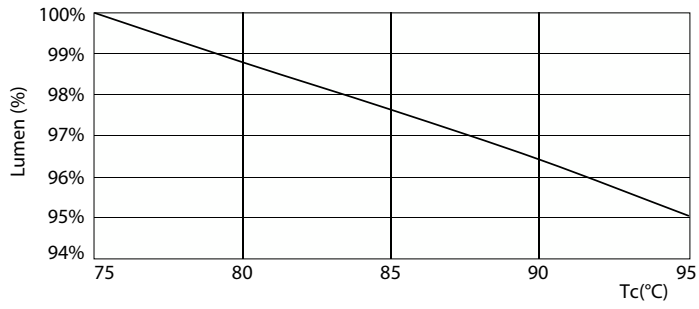

Lumen Maintenance Diagram - 10.5PL-C/T/COR/26V-840/IF13/P/4P/
DIM10/1

