



# InstantFit (UL Type-A) T5

## 24T5HO/46-840/IF35/P/DIM 10/1

The InstantFit TLED lamps provide hassle-free installation with simple lamp-for-lamp replacements. They deliver what we promise, with at least 40% energy savings, flicker-free performance, and the life you would expect. Other lamps claim compatibility but only InstantFit (UL Type-A) has been proven to work with over 200 ballasts and drivers, delivering even light output, with proven energy savings and a long average lifetime. End users will be delighted being under these comfortable and high quality InstantFit lamps with no visible flicker and optimized optics. Energy managers will enjoy the InstantFit lamps too as they can count the savings delivered by our lamps. To enjoy more energy savings, the InstantFit lamps can be paired with the Advance TLED drivers to create a Type C system.

### Product data


General Information		LLMF At End Of Nominal Lifetime (Nom) 70 %	
Cap-Base	G5		
Nominal lifetime	50,000 hour(s)		
Switching Cycle	50,000		
Lighting Technology	LED		
Light Technical		Operating and Electrical	
Color Code	840 [CCT of 4000K]	Line Frequency	40000-80000 Hz
Beam Angle (Nom)	140 degree(s)	Input Frequency	40000-80000 Hz
Luminous Flux	3,500 lm	Power Consumption	24 W
Luminous Efficacy (rated) (Nom)	145.00 lm/W	Lamp Current (Max)	600 mA
Color Designation	Cool White (CW)	Lamp Current (Min)	400 mA
Correlated Color Temperature (Nom)	4000 K	Wattage Equivalent	54 W
Color Consistency	<5	Starting Time (Nom)	0.5 s
Color rendering index (CRI)	82	Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.9
		Voltage (Nom)	39-64 V
		UL Type	UL Type A

# InstantFit (UL Type-A) T5

Temperature	
Ambient temperature range	-20 °C to 45 °C
T-Case Maximum (Nom)	45 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Product Length	1,200 mm
Bulb Shape	T5
Approval and Application	
Energy Saving Product	Yes
Approval Marks	UL certificate RoHS compliance DLC compliance
Energy Consumption kWh/1000 h	- kWh



Energy Certifications	DLC Standard
EU RoHS compliant	Yes
Application Conditions	
can it be used in closed luminaires	Yes
Product Data	
Order product name	24T5HO/46-840/IF35/P/DIM 10/1
Full product name	24T5HO/46-840/IF35/P/DIM 10/1
Order code	467142
Material Nr. (12NC)	929001283904
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.170 kg
EAN/UPC - Product/Case	046677467142
Numerator - Packs per outer box	10
EAN/UPC - Case	50046677467147

## Dimensional drawing

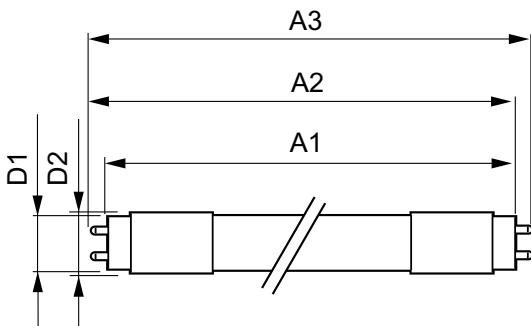

Product	D1	D2	A1	A2	A3
24T5HO/46-840/IF35/P/DIM 10/1	15.2 mm	17.8 mm	1,147.8 mm	1,154.9 mm	1,162 mm

## Photometric data

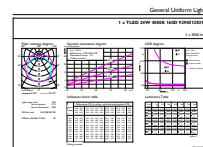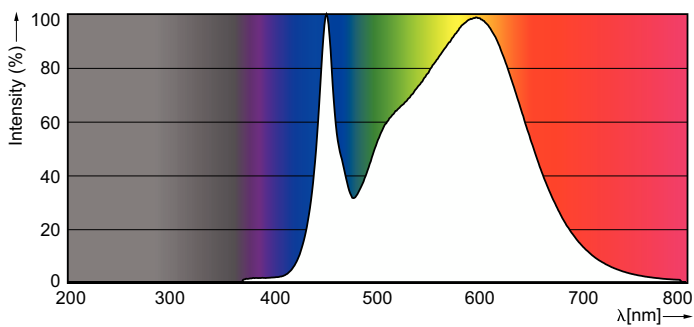


General uniform lighting - 24T5HO/46-840/IF35/P/DIM 10/1

Spectral Power Distribution Colour - 24T5HO/46-840/IF35/P/DIM 10/1

General uniform lighting - 24T5HO/46-840/IF35/P/DIM 10/1

# InstantFit (UL Type-A) T5

## Photometric data

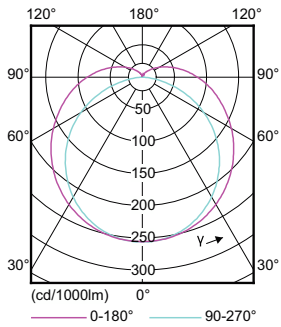

Light Distribution Diagram - 24T5HO/46-840/1F35/P/DIM 10/1

