



# Ceramalux ALTO Non-Cycling

## C70S62/ALTO NC HPS 1/12PK

Philips Ceramalux High Pressure Sodium Non-Cycling Lamps are a better value than standard high pressure sodium lamps, with longer life and reduced maintenance cost.

### Product data

General Information	
Cap-Base	E39 [Single Contact Mogul Screw]
Operating Position	UNIVERSAL [Any or Universal (U)]
Features	ALTO® Non-Cycling

Light Technical	
Luminous Efficacy (rated) (Nom)	90 lm/W
Chromaticity Coordinate X (Nom)	0.523
Chromaticity Coordinate Y (Nom)	0.425
Luminous Efficacy (Rated) (Min)	79 lm/W
Color rendering index (CRI)	21

Operating and Electrical	
Power Consumption	70.2 W
Lamp Current (Nom)	1.45 A
Voltage (Nom)	52 V

Mechanical and Housing	
Bulb Finish	Clear

Bulb Material	Hard Glass
Bulb Shape	ED-23 1/2


Approval and Application	
Mercury (Hg) Content (Nom)	1.4 mg

Product Data	
Order product name	C70S62/ALTO NC HPS 1/12PK
Full product name	C70S62/ALTO NC HPS 1/12PK
Order code	467324
Material Nr. (12NC)	928601155990
Numerator - Quantity Per Pack	1
Net Weight (Piece)	126.000 g
EAN/UPC - Product/Case	046677467326
Numerator - Packs per outer box	12
EAN/UPC - Case	50046677467321

# Ceramalux ALTO Non-Cycling

## Dimensional drawing

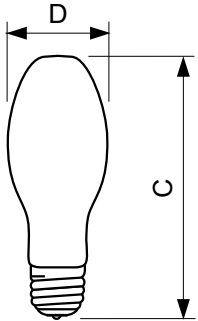

Product	D	L	C (max)
C70S62/ALTO NC HPS 1/12PK	2.94 inch	5.000 inch	7.75 inch

