



CorePro Plastic (Dimmable) A-Shape Lamps

8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

Dimmable A-shape lamps that offer over 25,000 hours lifetime. Title 20 listed lamps that can be sold in California and ideal for commercial spaces nationwide.

Product data

General Information		Power Consumption	
Cap-Base	E26	Power Consumption	8.8 W
Nominal lifetime	25,000 hour(s)	Lamp Current (Nom)	80 mA
Switching Cycle	50,000	Wattage Equivalent	60 W
Lighting Technology	LED	Starting Time (Nom)	0.5 s
		Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.7
		Voltage (Nom)	120 V
Light Technical		Temperature	
Color Code	927 [CCT of 2700K]	Ambient temperature range	-20 to +45 °C
Beam Angle (Nom)	200 degree(s)	T-Case Maximum (Nom)	75 °C
Luminous Flux	800 lm		
Color Designation	Warm White (WW)	Controls and Dimming	
Luminous Efficacy (rated) (Nom)	90 lm/W	Dimmable	Only with specific dimmers
Correlated Color Temperature (Nom)	2700 K		
Color Consistency	<4	Mechanical and Housing	
Color rendering index (CRI)	90	Bulb Finish	Frosted
LLMF At End Of Nominal Lifetime (Nom)	70 %	Bulb Material	Plastic
		Bulb Shape	A19
Operating and Electrical			
Line Frequency	60 Hz		
Input Frequency	60 Hz		

CorePro Plastic (Dimmable) A-Shape Lamps

UL Wet/ damp/ dry location	Damp location
----------------------------	---------------

Approval and Application

Energy Consumption kWh/1000 h	- kWh
Energy Certifications	Energy Star
EU RoHS compliant	Yes
T20 compliant	Yes

Application Conditions


can it be used in closed luminaires	No
-------------------------------------	----

Product Data

Order product name	8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT
--------------------	---------------------------------------



Full product name	8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT
Order code	550434
Material Nr. (12NC)	929002036104
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.060 kg
EAN/UPC - Product/Case	046677550431
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677550436

Dimensional drawing

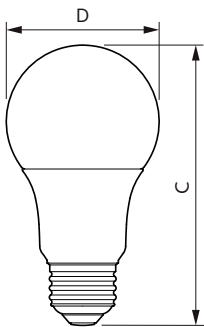

Product	D	C
8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT	62.5 mm	111.5 mm

Photometric data

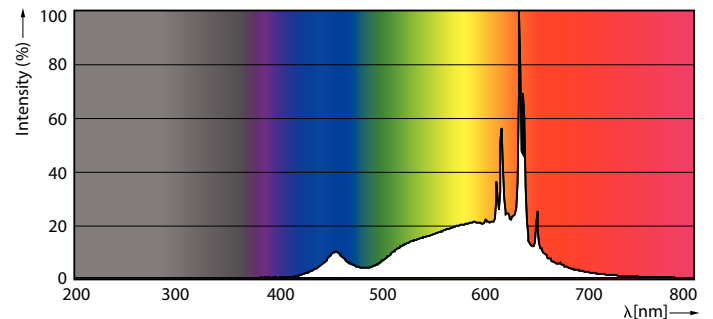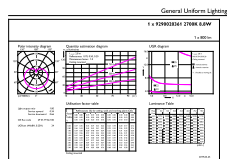


General uniform lighting - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

Spectral Power Distribution Colour - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

CorePro Plastic (Dimmable) A-Shape Lamps

Photometric data

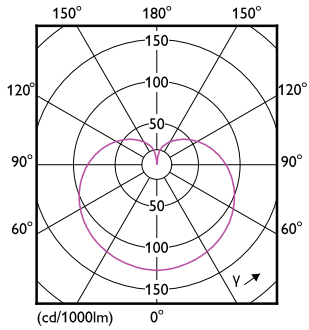

Light Distribution Diagram - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram - 8.8A19/COR/927/FR/P/E26/DIM/T20 6/1CT

