



LED MR16

7MR16/LED/827/F25/DIM 12V 10/1FB

Philips LED MR-16 lamps with single optic technology provide the look and color quality of traditional halogens while using a fraction of the energy. A perfect fit for spot lighting, they are compatible with most existing fixtures with MR16 GU5.3 holders and are designed as a retrofit replacement for halogen or incandescent spots.

Product data

General Information	
Cap-Base	GU5.3
Nominal lifetime	25,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
Light Technical	
Color Code	827 [CCT of 2700K]
Beam Angle (Nom)	25 degree(s)
Luminous Flux	515 lm
Luminous Intensity (Nom)	2,400 cd
Luminous Efficacy (rated) (Nom)	73.00 lm/W
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Color Consistency	<4
Color rendering index (CRI)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Line Frequency	- Hz
Input Frequency	- Hz
Power Consumption	7 W


Lamp Current (Nom)	650 mA
Wattage Equivalent	50 W
Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	ac electronic 12 V
Temperature	
T-Case Maximum (Nom)	90 °C
Controls and Dimming	
Dimmable	Only with specific dimmers
Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Aluminum
Bulb Shape	MR16
UL Wet/ damp/ dry location	Damp location
Approval and Application	
Suitable For Accent Lighting	Yes
Energy Certifications	Energy Star

LED MR16

EU RoHS compliant	Yes
T20 compliant	No
Application Conditions	
can it be used in closed luminaires	Yes
Product Data	
Order product name	7MR16/LED/827/F25/DIM 12V 10/1FB
Full product name	7MR16/LED/827/F25/DIM 12V 10/1FB



Order code	573865
Material Nr. (12NC)	929003076204
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.060 kg
EAN/UPC - Product/Case	046677573867
Numerator - Packs per outer box	10
EAN/UPC - Case	50046677573862

Dimensional drawing

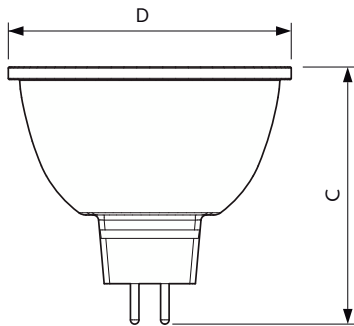


Product	D	C
7MR16/LED/827/F25/DIM 12V 10/1FB	50 mm	46.5 mm

Photometric data

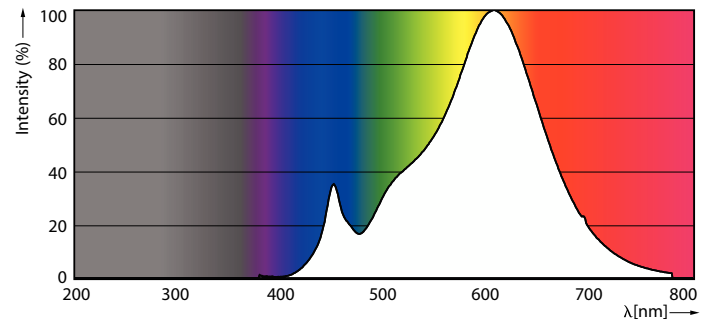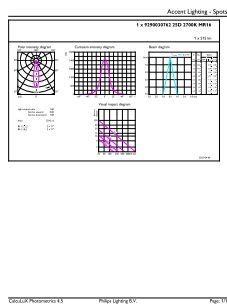

Accent Lighting Spots - 7MR16/LED/827/F25/DIM 12V 10/1FB

Spectral Power Distribution Colour - 7MR16/LED/827/F25/DIM 12V 10/1FB

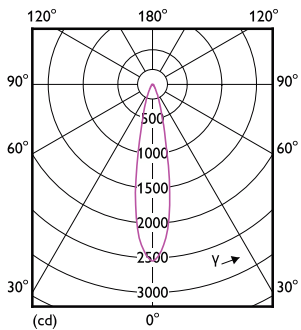

Light Distribution Diagram - 7MR16/LED/827/F25/DIM 12V 10/1FB

LED MR16

Lifetime



Life Expectancy Diagram

Lumen Maintenance Diagram - 7MR16/LED/827/F25/DIM 12V 10/1FB

