



# MainsFit (UL Type-B) T5

## Controls and Dimming

Dimmable	Limited
----------	---------

## Mechanical and Housing

Bulb Finish	Frosted
Bulb Material	Glass
Product Length	1,200 mm
Bulb Shape	T5

## Approval and Application

Energy Saving Product	Yes
Approval Marks	RoHS compliance UL certificate DLC compliance
EU RoHS compliant	Yes


## Application Conditions

can it be used in closed luminaires	Yes
-------------------------------------	-----

## Product Data


Order product name	25T5HO/COR/46-840/MF35/G 25/1
Full product name	25T5HO/COR/46-840/MF35/G 25/1
Order code	576249
Material Nr. (12NC)	929003122504
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.151 kg
EAN/UPC - Product/Case	046677576240
Numerator - Packs per outer box	25
EAN/UPC - Case	50046677576245

## Dimensional drawing

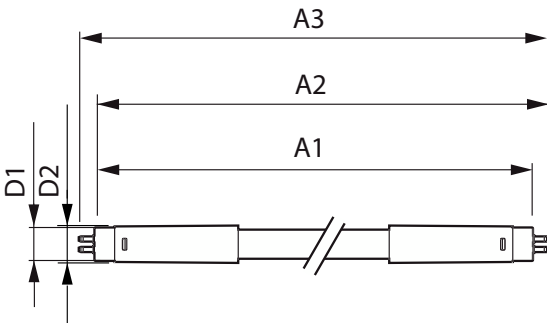


Product	D1	D2	A1	A2	A3
25T5HO/COR/46-840/MF35/G 25/1	15.3 mm	18.2 mm	1,149 mm	1,154.9 mm	1,163.2 mm

## Photometric data

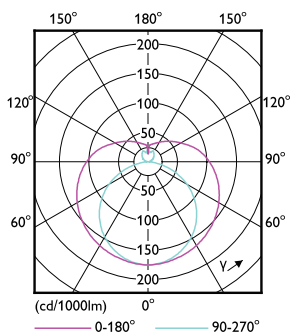


Light Distribution Diagram - 25T5HO/COR/46-840/MF35/G 25/1

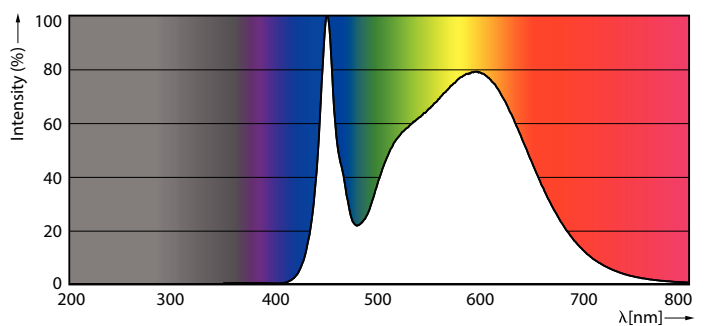

Spectral Power Distribution Colour - 25T5HO/COR/46-840/MF35/G 25/1



# MainsFit (UL Type-B) T5

## Photometric data

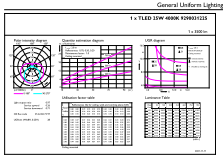



General uniform lighting - 25T5HO/COR/46-840/MF35/G 25/1

## Lifetime

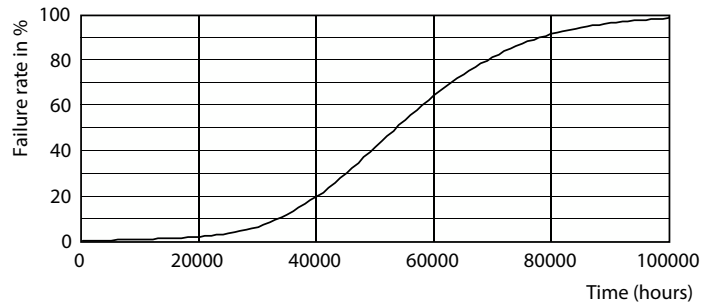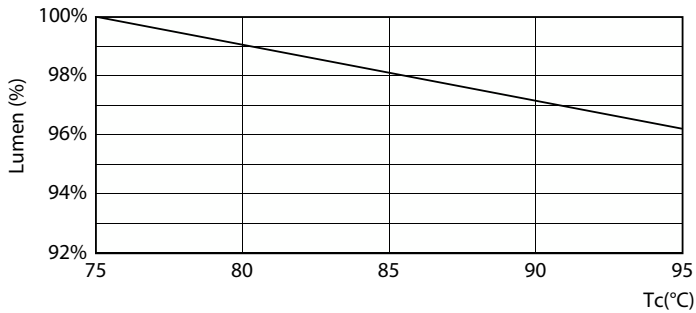

Lumen Maintenance Diagram - 25T5HO/COR/46-840/MF35/G 25/1

Life Expectancy Diagram

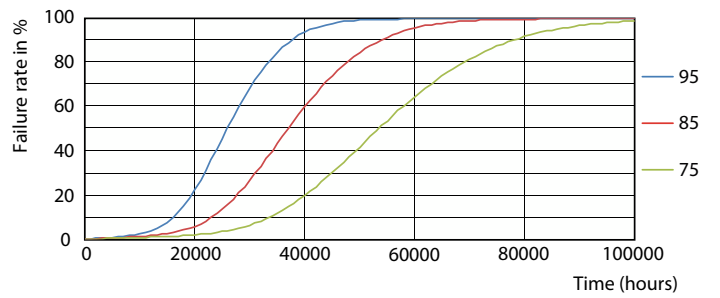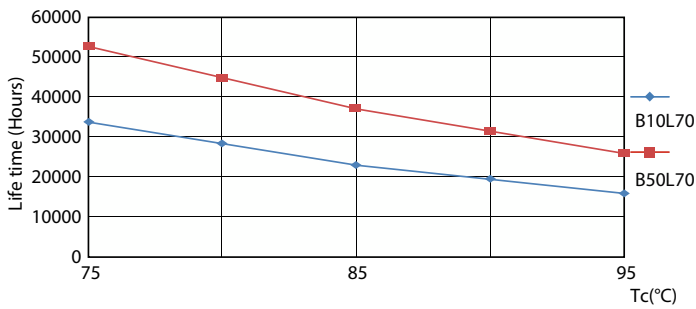

LEDtube 50K 7595 LifetimeVsTc-LED

LEDtube 50K 7595 FailureRate-LED

## MainsFit (UL Type-B) T5

