

200A AC Fork Tester

CL3200

Extra large jaw opening
accepts 3/0 wire

Short jaw depth for
increased access in
tight spaces




**KLEIN
TOOLS®**

PROFESSIONAL SERIES FORK TESTER

200A AC FORK TESTER

CL3200

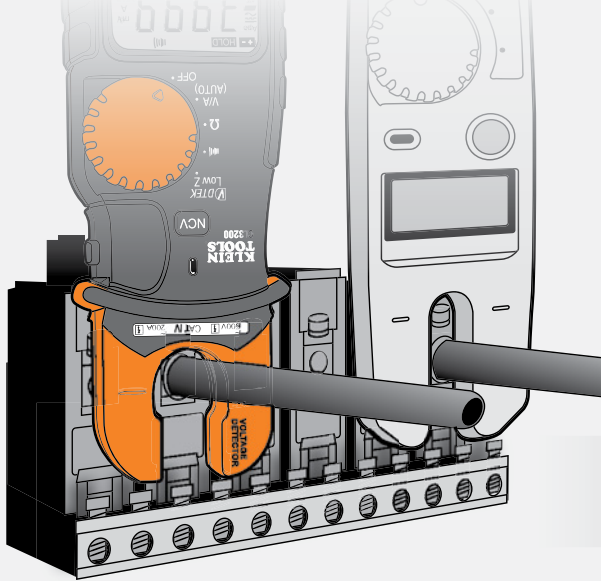

Shorter Jaw Depth allows for a more accurate reading in tight spaces. The large mouth is able to accommodate an oversized wire when needed.

Extra Large Fork Opening accepts 3/0 wire

Shorter Jaw Depth for increased access in tight spaces

Worklight in jaw area

SPECIFICATION	CL3200
AC Current	200A
AC Voltage	750V
DC Voltage	1000V
LCD Display Counts	4000
Resistance Range	40MΩ
HOLD Data Hold	●
AUTO Auto Ranging	●
Apo Auto Power-Off	●
Audible Continuity	●
NCV Non Contact Voltage	●
Safety Rating	CAT IV 600V
Listing	
Dimensions: 7.06" H x 2.56" W x 1.34" D (179.3 mm H x 65 mm W x 34 mm D)	
Weight: 7.9 oz. (223.9 g)	

Non-contact Voltage Tester

Measures Low Impedance

Backlit Display is brighter than most competitive units

Analog Bar Graph measures fast moving readings

Magnetic Mount secures meter and frees hands

Side Mounted Dial for ease of use

Lead Storage protects leads



Backlit Display



Worklight



Lead Storage

See our complete line of Test and Measurement products online

www.kleintools.com

© 2011 Klein Tools, Inc.
Lincolnshire, IL 60069-1418
Printed in U.S.A.



KLEIN TOOLS®