

NetKey® Category 5e Leadframe Jack Modules

SPECIFICATIONS

Category 5e/Class D, 8-position keystone UTP jack module shall terminate unshielded twisted 4-pair, 22 AWG - 24 AWG, 100 ohm cable without the use of a punchdown tool. Optional tool ensures conductors are fully terminated. Universal label is color-coded T568A and T568B wiring schemes.



TECHNICAL INFORMATION

Category 5e/Class D channel and component performance:	Exceeds channel requirements of ANSI/TIA-568.2-D Category 5e and ISO 11801 Class D Standards at swept frequencies 1 to 100 MHz Exceeds component requirements of ANSI/TIA-568.2-D Category 5e and ISO 11801 Class D Standards at swept frequencies 1 to 100 MHz
FCC and ANSI compliance:	Meets ANSI/TIA-1096-A; contacts plated with 50 microinches of gold for superior performance
IEC compliance:	Meets IEC 60603-7 and IEC 60512-99-002
PoE and PoH compliance:	Meets IEEE 802.3af/802.3at and 802.3bt type 3 and type 4. Supports Power over HDBaseT up to 100 watts
c(UL)us listed:	UL 1863 (Use as communications circuit accessory); CSA Standard C22.2
RoHS compliance:	Compliant
Operating temperature:	14°F to 140°F (-10°C to 60°C)

KEY FEATURES AND BENEFITS

100% Performance tested:	Confidence that each jack module delivers specified performance
Termination cap:	Provides strain relief, helps control cable end radius and securely retains wires in place
Modular:	Universal keystone jack modules snap in and out of all NetKey Faceplates, Modular Patch Panels, and Surface Mount Boxes for fast moves, adds, and changes

APPLICATIONS

Applications include:

- Ethernet 10BASE-T, 100BASE-T (Fast Ethernet), and 1000BASE-T (Gigabit Ethernet)
- Voice over internet protocol (VoIP)

NetKey Category 5e Jack Modules

Module: NK5E88M*Y

NetKey Category 5e Patch Cords

24-port, 1 RU: NKFP24Y

48-port, 2 RU: NKFP48Y

Termination Tools

Termination tool: CJT‡



Snipping tool: CWST

Stripping tool: CJUST

*Colors: IW (Off White), EI (Electric Ivory), IG (International Gray), WH (White), BL (Black), OR (Orange), RD (Red), BU (Blue), GR (Green), VL (Violet), AW (Arctic White), or YL (Yellow)
‡Terminates NetKey Keystone Leadframe Jack Modules.

NetKey® Category 5e Leadframe Jack Modules

ENGINEERING DRAWINGS

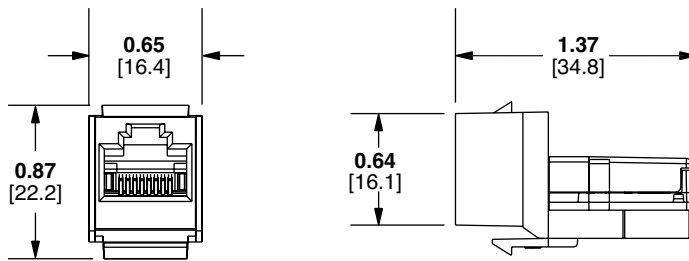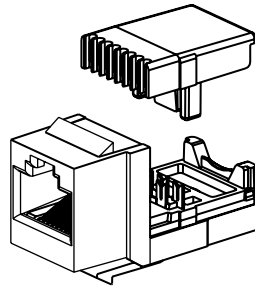

Dimensions are in inches. [Dimensions in brackets are metric].

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty

For more information

Visit us at www.panduit.com
Contact Customer Service by email: cs@panduit.com
or by phone: 800.777.3300

PANDUIT®

© 2024 Panduit Corp.
ALL RIGHTS RESERVED.
COSP580-WW-ENG
7/2024