








circular conduc. terminal TA2.2 2 AWG...350 kcmil large 3 units accessory for: 3VA61/62

| Model | | |
|---|--|-------------|
| product brand name | SETRON | |
| product designation | circular conductor terminal | |
| accessories | Wire connector | |
| General technical data | | |
| designation / of the terminal | TA2.2 | |
| type of electrical connection / with control wire tap | No | |
| Connections according IEC | | |
| connectable conductor cross-section | | |
| <ul style="list-style-type: none"> for copper cable / stranded / minimum for copper cable / stranded / maximum for aluminum cable / stranded / minimum for aluminum cable / stranded / maximum | 50 mm ² 240 mm ² 50 mm ² 240 mm ² | |
| stripped length | 30,5 mm | |
| tightening torque / when using copper cables | | |
| <ul style="list-style-type: none"> stranded finely stranded | 50 - 240 mm ² : 31.1 Nm 50 - 185 mm ² : 31.1 Nm | |
| Connections according UL | | |
| permissible temperature / of connectable conductor / according to UL 486A-486B | 75 °C | |
| stripped length | 1.2 in | |
| connectable conductor cross-section | | |
| <ul style="list-style-type: none"> for copper cable / stranded / minimum for copper cable / stranded / maximum for aluminum cable / stranded / minimum for aluminum cable / stranded / maximum | 2 AWG 350 kcmil 2 AWG 350 kcmil | |
| tightening torque / when using copper cables | | |
| <ul style="list-style-type: none"> stranded | 2 AWG - 350 kcmil: 275 lb-in | |
| Certificates | | |
| General Product Approval | EMV | |
|      | Miscellaneous | |
| Marine / Shipping | other | Environment |

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9243-0JJ13>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9243-0JJ13>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

 




http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9243-0JJ13

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

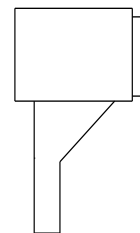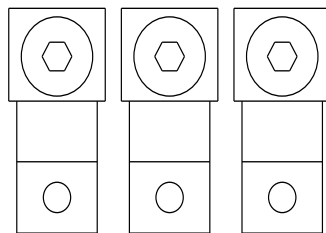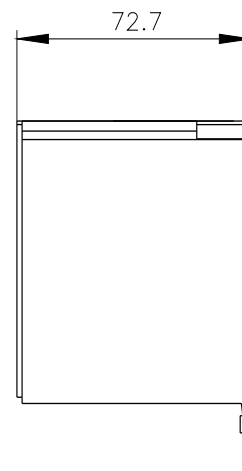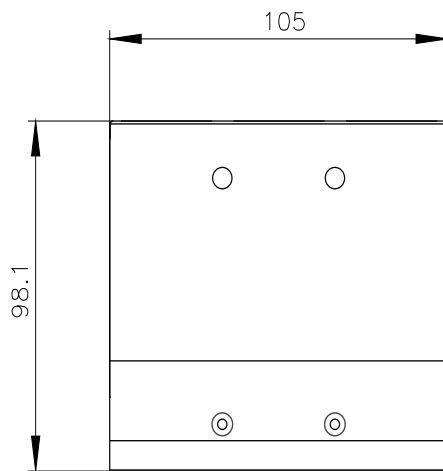

last modified:

8/9/2024

