

Pivot

When searching for lighting flexibility, look no further than our 3", 4" & 6" flat gimbal LED downlights. With powerful lumen output and the ability to direct light with a 360° rotation and a 90° tilt angle, this product will meet your every need.

NEW

WET SWIVEL/DIRECTIONAL 90°

ETL Intertek IC RATED

AIR TIGHT 2700k 3000k 3500k 4000k 5000k ENERGY STAR T24 JA8 CERTIFIED

COLOR TEMPERATURE*



*Models FGM2-CC , FGM3-CC , FGM4-CC, and FGM6-CC only

| Model | Size | Watts | Delivered lumens | CRI | Color °T | Standard voltage | Multi-voltage ⚡ |
|----------------|------|-------|------------------|-----|--------------------------------|---------------------|-------------------------------------|
| FGM4-3K | 4" | 9 W | 700 lm | 90 | 3000 K | 120V, Triac dimming | MV: 120 / 277 / 347V, 0-10V dimming |
| FGM2-CC | 2" | 6 W | 500 lm | 90 | 2700, 3000, 3500, 4000, 5000 K | 120V, Triac dimming | MV: 120 / 277 / 347V, 0-10V dimming |
| FGM3-CC | 3" | 6 W | 570 lm | | | | |
| FGM4-CC | 4" | 9 W | 800 lm | | | | |
| FGM6-CC | 6" | 14 W | 1050 lm | | | | |

Specifications

Every fixture includes a junction box with integrated dimmable driver
 Can be daisy chained
 Superior LED performance and lifespan
 90° tilting, 360° rotation
 Minimal heat emission
 Aluminum construction
 Switch-selectable CCT: 2700K/3000 K/3500 K/4000 K/5000 K*
 Low profile
 40° beam spread
 IC certification (suitable for direct contact with insulation)
 Air-tight certified as per ASTM E283-04
 Suitable for wet locations
 Refer to website for dimmer compatibility
 Ideal operating temperature: -20° to 40° C
 5-year warranty

Finish

- **BK** Black
- **SN** Satin Nickel (FGM4, FGM6 only)
- **WH** White

Accessories

- RFP-UNI**
Universal rough-in plate
- RFP-23**
Rough-in plate for 3" model
- RFP-46**
Rough-in plate for 4" and 6" models
- REC-3K-EXT8FT (FGM4-3K)**
8-foot extension cable
- REC-3K-EXT20FT (FGM4-3K)**
20-foot extension cable
- REC-CC-EXT8FT (FGMX-CC)**
8-foot extension cable
- REC-CC-EXT20FT (FGMX-CC)**
20-foot extension cable



Multi-voltage ⚡

This product family offers multi-voltage drivers (120/277/347) that are dimmable using 0-10V dimming systems. Please note that longer lead times may apply for this option. Kindly reach out to your DALI representative for additional information and to confirm availability.


Note

Other color temperatures, finishes, and voltage options are available but may require minimum order quantities (MOQs) and longer lead times. Please contact your DALI representative for more information.

 
FGM3-CC Ø3-3/8"

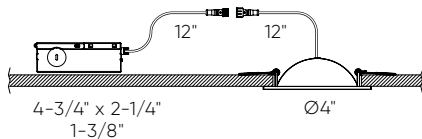

FGM4-CC Ø4-1/4"

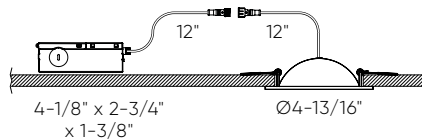

FGM6-CC Ø6-1/4"

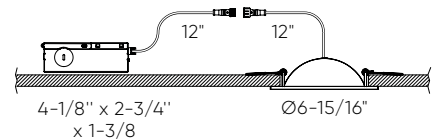

FGM2-CC Ø2-3/4"

