





circular conduc. terminal TA1.5 50...300 mm<sup>2</sup> 3 units accessory for: 3VA13/14;  
3VA23/24



Model		
product brand name	SENTRON	
product designation	Circular conductor terminal 1 cable 3 units	
accessories	Wire connector	
General technical data		
designation / of the terminal	TA1.5	
type of electrical connection / with control wire tap	No	
Connections according IEC		
connectable conductor cross-section		
<ul style="list-style-type: none"> <li>for copper cable / stranded / minimum</li> <li>for copper cable / stranded / maximum</li> <li>for aluminum cable / stranded / minimum</li> <li>for aluminum cable / stranded / maximum</li> </ul>	50 mm <sup>2</sup> 300 mm <sup>2</sup> 50 mm <sup>2</sup> 300 mm <sup>2</sup>	
stripped length	28 mm	
tightening torque / when using copper cables		
<ul style="list-style-type: none"> <li>stranded</li> <li>finely stranded</li> </ul>	50 - 300 mm <sup>2</sup> : 42.4 Nm 50 - 240 mm <sup>2</sup> : 42.4 Nm	
Connections according UL		
permissible temperature / of connectable conductor / according to UL 486A-486B	75 °C	
stripped length	1.1 in	
connectable conductor cross-section		
<ul style="list-style-type: none"> <li>for copper cable / stranded / minimum</li> <li>for copper cable / stranded / maximum</li> <li>for aluminum cable / stranded / minimum</li> <li>for aluminum cable / stranded / maximum</li> </ul>	1 AWG 600 kcmil 1 AWG 600 kcmil	
tightening torque / when using copper cables		
<ul style="list-style-type: none"> <li>stranded</li> </ul>	1 AWG - 600 kcmil: 375 lb-in	
Certificates		
General Product Approval	EMV	Test Certificates
 EG-Konf.		<a href="#">Miscellaneous</a>
		
		<a href="#">Type Test Certificates/Test Report</a>
Marine / Shipping	other	Environment

## Environment

[Environmental Con-  
firmations](#)

## Further information

**Information on the packaging**

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/lowvoltage/catalogs>

**Industry Mall (Online ordering system)**

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9383-0JB13>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9383-0JB13>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**



[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3VA9383-0JB13](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9383-0JB13)

**CAX-Online-Generator**

<http://www.siemens.com/cax>

**Tender specifications**

<http://www.siemens.com/specifications>

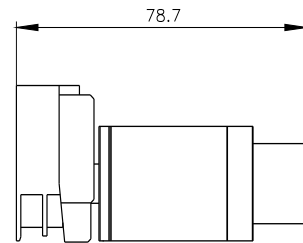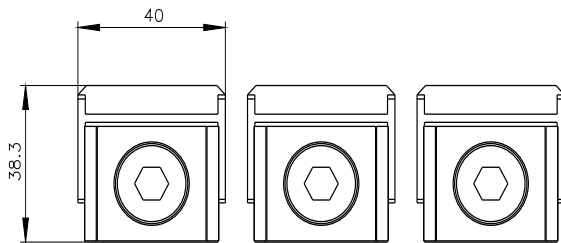

last modified:

4/19/2024 

