



circular conduc. terminal TA2.8 1x250...750 kcmil; 2x250 kcmil for 1 cable 250 - 750 kcmil or 2 cables 250 kcmil 3 units accessory for: 3VA53/54; 3VA63/64 up to 400 A

Model	
product brand name	SETRON
product designation	circular conductor terminal
accessories	Wire connector
General technical data	
designation / of the terminal	TA2.8
type of electrical connection / with control wire tap	No
Connections according UL	
permissible temperature / of connectable conductor / according to UL 486A-486B	90 °C
stripped length	1.5 in
connectable conductor cross-section	
<ul style="list-style-type: none"> for copper cable / stranded / minimum for copper cable / stranded / maximum for aluminum cable / stranded / minimum for aluminum cable / stranded / maximum 	250 kcmil 750 kcmil 250 kcmil 750 kcmil
tightening torque / when using copper cables	
<ul style="list-style-type: none"> stranded 	250-750 kcmil: 410.0 lb-in 250 kcmil: 410.0 lb-in

Certificates		
General Product Approval	EMV	Marine / Shipping



[Miscellaneous](#)



other	Environment			
Confirmation	Miscellaneous	Miscellaneous	Environmental Con- firmations	Environmental Con- firmations

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9373-0JJ24>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3VA9373-0JJ24>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9373-0JJ24

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

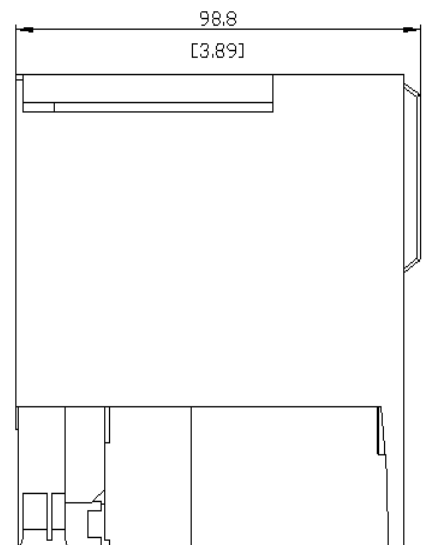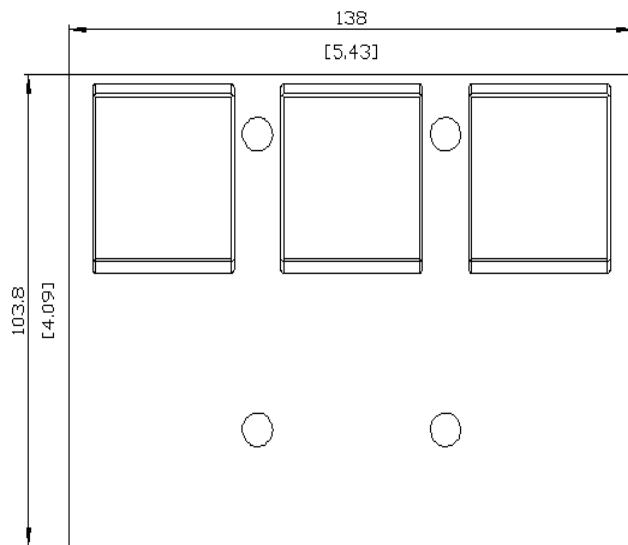

last modified:

8/9/2024 

