



# LED PAR38

## 13PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

### Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal lifetime	25,000 hour(s)
Switching Cycle	50,000
Lighting Technology	LED
EU RoHS compliant	Yes
Light Technical	
Color Code	930 [CCT of 3000K]
Beam Angle (Nom)	40 degree(s)
Luminous Flux	1,300 lm
Luminous Intensity (Nom)	2,500 cd
Color Designation	White (WH)
Correlated Color Temperature (Nom)	3000 K
Luminous Efficacy (rated) (Nom)	100 lm/W
Color Consistency	<4
Color rendering index (CRI)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power Consumption	13 W
Lamp Current (Nom)	150 mA
Wattage Equivalent	120 W

Starting Time (Nom)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (Nom)	120 V

Temperature	
Ambient temperature range	-40 to +113 °F
T-Case Maximum (Nom)	185 °F

Controls and Dimming	
Dimmable	Only with specific dimmers

Mechanical and Housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	PAR38
UL Wet/ damp/ dry location	Wet location

Approval and Application	
Suitable For Accent Lighting	Yes
T20 compliant	Yes

# LED PAR38

## Application Conditions

can it be used in closed luminaires Yes

## Product Data

Order product name 13PAR38/COR/930/F40/DIM/P/ULW/T20  
6/1FB

Full product name 13PAR38/COR/930/F40/DIM/P/ULW/T20  
6/1FB

Order code 586149

Material Nr. (12NC) 92900373204


Numerator - Quantity Per Pack 1

EAN/UPC - Product/Case 046677586140

Numerator - Packs per outer box 6



EAN/UPC - Case 50046677586145

## Dimensional drawing

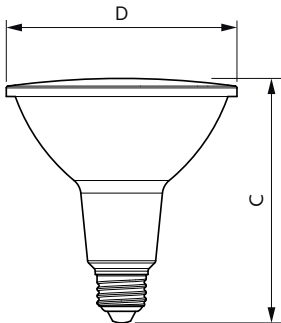


Product	D	C
13PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB	4-7/8 inch	5-1/8 inch

## Photometric data

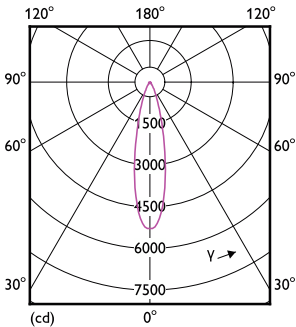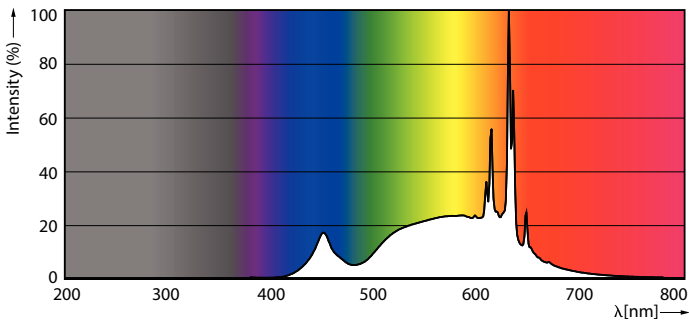

Spectral Power Distribution Colour -  
13PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

Light Distribution Diagram - 13PAR38/COR/930/F40/DIM/P/ULW/T20  
6/1FB

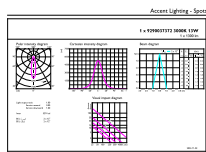

Accent Lighting Spots - 13PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

# LED PAR38

## Lifetime



Life Expectancy Diagram - 13PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

Lumen Maintenance Diagram - 13PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

