




Pass and Seymour  
3-Gang 430 Stainless Steel Wall Plate, 3 Toggle Switch Openings  
Part No. SL3

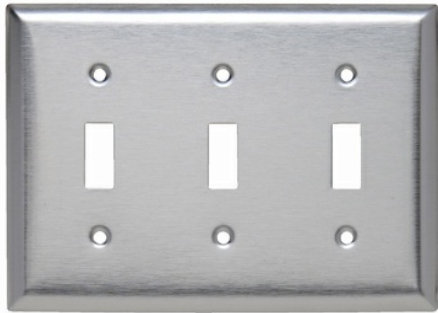

Smooth Metal Wall Plate 3-Gang Toggle 430 Stainless Steel

## Features & Benefits

Type 430 Stainless Steel, magnetic: .032" nominal thickness.

Brushed finish.

Less corrosion-resistant than Type 302, but ideal for general service in high abuse applications in industrial plants, commercial, and industrial buildings.

Constructed of corrosion-resistant stainless steel, brass, aluminum, chrome, brushed bronze, or galvanized steel.

Standard, Jumbo, and Tandem plates available, as well as special Panel plates up to 5-gangs high and 10-gangs wide.

Packaged in protective film, with finish-matching screws.

Variety of special plated finishes.

Paintable to match plastic plates.

Can be silk-screened or engraved, and custom punched with over 300 opening styles.

For covering patents, see [www.legrand.us/patents](http://www.legrand.us/patents).

## Specifications

### General Info

Product Line	Pass & Seymour	Color	Stainless Steel
Finish	Metallic	UPC Number	785007657975
Country Of Origin	United States	Wall Plate Size	Standard Size
Wall Plate Type	Toggle Switch	Application Sector	Commercial, Residential
Warranty Type	1-Year Limited Warranty	Type	Wall Plate

### Dimensions

---

Product Width US	6.375 in	Product Depth US	0.2 in
------------------	----------	------------------	--------

---

Product Height US	4.5 in
-------------------	--------

---

### Listing Agencies / 3rd Party Agencies

---

cULus ListingNumber	143223	cULus Listed	Yes
---------------------	--------	--------------	-----

---

### Technical Information

---

Thickness	0.032 in	Number of Gangs	3
-----------	----------	-----------------	---

---

Indoor/Outdoor	Indoor	Mounting Type	Box Mounted
----------------	--------	---------------	-------------

---

Orientation	Vertical
-------------	----------

---