



banvil

Your Trusted Fan Expert Since 1974

SILVER LINE INDUSTRIAL FANS



Oil Rubbed Bronze
60F9-10ORB



Cement Gray
60F9-10CG





White
60F7-10 & 60F9-10

3 YEAR WARRANTY

FEATURES

- Standard 10" Downrod
- Corrosion-Resistant Epoxy Primer & Finish Coat on all Metal Housing & Blades
- The Aerodynamically Curved-Tip Blade Results in Maximum Air Delivery
- All Metal Design, No Plastic
- Permanent Lubricated Sealed TPI Ball Bearings
- Totally Enclosed Impedance Protected AC Motor
- Non-Polar, Weatherproof Encapsulated, Extra Heavy-duty Capacitor
- Heavy Cast Yoke for Easy Infield Downrod Change
- Downrod lengths 18", 24" & 36" Available
- 16' cord with plug available (CORD-WH16)

MODEL	60F7-10	60F9-10	60F9-10CG	60F9-10ORB
Motor	AC	AC	AC	AC
Safety Cable	60"	60"	60"	60"
Diameter Sweep	56"	56"	56"	56"
Airflow CFM	6,693	6,693	6,693	6,693
CFM per Watt	89	89	89	89
Volts	120	120	120	120
Amps	0.65	0.65	0.65	0.65
Watts	75	75	75	75
RPM (max)	328	328	328	328
Wiring	plug-in	3 + ground	3 + ground	3 + ground
Direction	down only	up & down	up & down	up & down
Weight	13 lbs	13 lbs	13 lbs	13 lbs
Colour	White	White	Cement Gray	Oil Rubbed Bronze

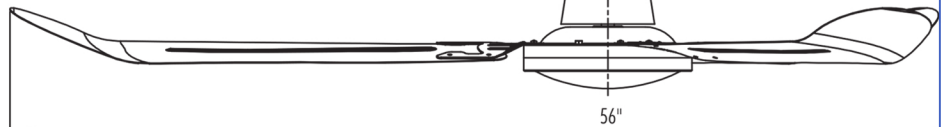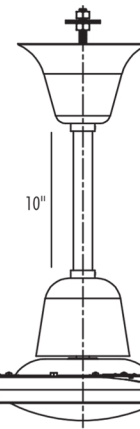

"Generates 19% More Airflow than our Bronze Line"