


NATIONAL ACCOUNTS





INSPIRE NATIONAL ACCOUNTS

No matter what your project type, Liteline has the lighting solution for you. Choose from our wide range of downlights, track, panel, millwork and undercabinet fixtures to enhance your retail, commercial, or hospitality space. Our QuickShip program is a standard feature on most Liteline products, ensuring your products are always delivered on schedule.

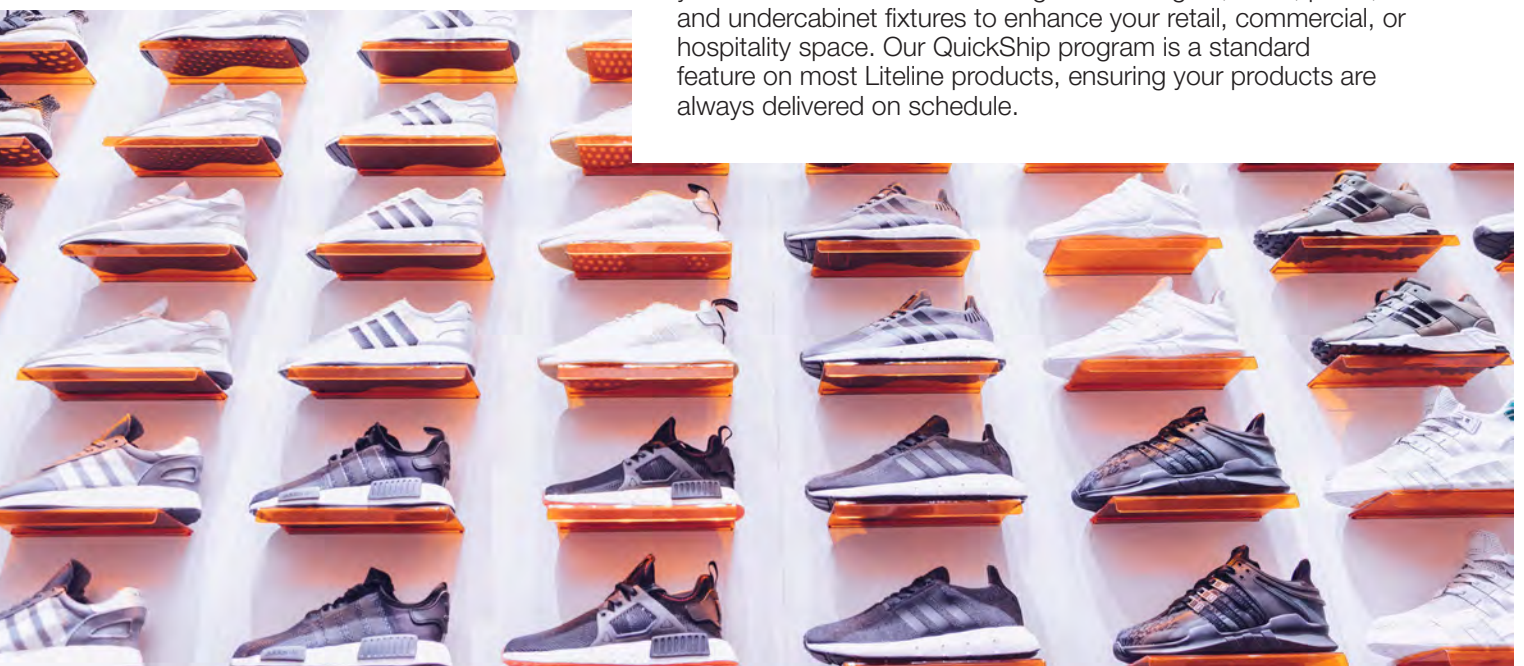



GET THE LOOK

APPLICATION

RETAIL

SIGMA PULLDOWN

Choose from one, two or three fixture configurations that allow for adjust-ability to change with the store merchandising so key products are always highlighted.



SIGMA

Sigma 3000, 4000 and 5000 fixtures provide a quiet ceiling with high lumens to light up your storefront, drawing people in.



FLIGHT

With beam angles as tight as 6°, the Flight Series is the ideal choice for emphasizing focused light from a distance to highlight feature items or aisle endcaps.





Squint Eyewear
North York, ON





GET THE LOOK

APPLICATION

RETAIL

LEDBAR

With 120V and no power supply required, link fixtures to a max of 50ft for continuous diffused lighting in cabinetry and coves.



LED TAPE LIGHT

Provide a subtle glow for undercabinet and highlights in product shelving with up to 550 lumens/foot.



SIGMA

The Sigma 2 lineup offers a wide range of trim styles while providing quiet optics for general lighting. Consider our deep regress trim style to add a splash of colour with baffle finishes.



MicroLED

MicroLEDs are tiny millwork fixtures that provide directional lighting capability. Available in singles or multiples with up to four fixtures in one housing, these are great 1W accent lights for product shelves.







GET THE LOOK

APPLICATION

RETAIL

SHADE

This fixture combines a decorative frame element with selectable CCT/wattage, auto-sensing voltage, multiple mounting and size options.



FORUM PANEL

Ideal for back of house, storage and warehouses, the FORUM LED panel provides a modern alternative to traditional troffers, while including a selectable CCT and wattage switch, 120-347V auto-sensing voltage, multiple mounting and size options.



A-BEAM

A single or two circuit track, with a rigid channel option to add structural integrity for fewer suspension points and a cleaner ceiling. A-Beam offers flexibility with adjusting track fixtures to accent new furniture.



ATF7425

With over 2000 lumens delivered you can highlight accent pieces from a higher ceiling height.





Whole Foods
Mississauga, ON





GET THE LOOK

APPLICATION

GROCERY

A-BEAM

A single or two circuit track, with a rigid channel option to add structural integrity for fewer suspension points and a cleaner ceiling.



ATF7425

With over 2000 lumens delivered you can highlight accent pieces from a higher ceiling height.



FLEX


Maintain a consistent appearance throughout your space with five different mounting options including pendant and track, as well as multiple accessories such as snoots and hex louvers.



FORUM PANEL

Ideal for back of house, and storage, the FORUM LED panel provides a modern alternative to traditional troffers, while including a selectable CCT and wattage switch, 120-347V auto-sensing voltage, multiple mounting and size options.



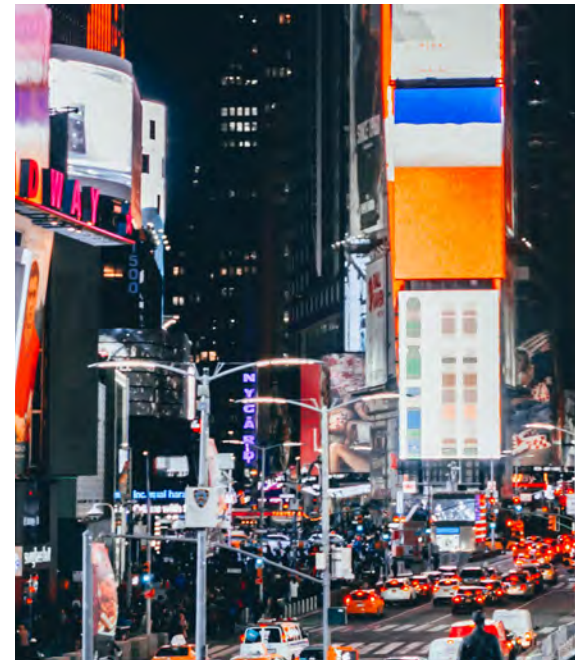



GET THE LOOK

APPLICATION

AUTO DEALERSHIP

FORUM LINEAR

A linear panel solution that bridges the gap between surface luminaire, a troffer, and a linear recessed downlight, available in 2', 4' and 6' lengths.



KLICK

A linear black strip that can extend from ceiling to wall with 4 mounting options and different modules that easily slide into place. Use this for featured accents near reception as a design element.



ATF7545

The ATF7545 is a 45W high powered LED track fixture that offers up to 4428 lumens, perfect for high ceilings.



ALR

An LED commercial downlight with a traditional look that can be used in retrofit, remodel or new construction environments for general illumination. Available with white or RGB tuning options.





Bar Burrito
Pickering, ON





GET THE LOOK

APPLICATION

FOOD

DELTA

A modern fixture in 9W or 10W variants. Offering full rotation, 90° tilt, with up to 1000 lumens delivered.



SORA & APOLLO

A classic look with modern technology, providing up to 611 lumens with 358° rotation and 90° tilt to give general illumination over food counters.



LUNA MULTIPLES

Offering quiet optics and impressive performance, this shallow, canless fixture has on-site control with a 5-position CCT switch (27 K, 30 K, 35 K, 40 K, 50 K) or Dim-To-Warm option. Available in two or three light multiples.




FORUM PANEL



Ideal for food prep areas, the FORUM LED panel includes a selectable CCT and wattage switch, 120-347V auto-sensing voltage, multiple mounting and size options.





Chotto Matte
Toronto, ON

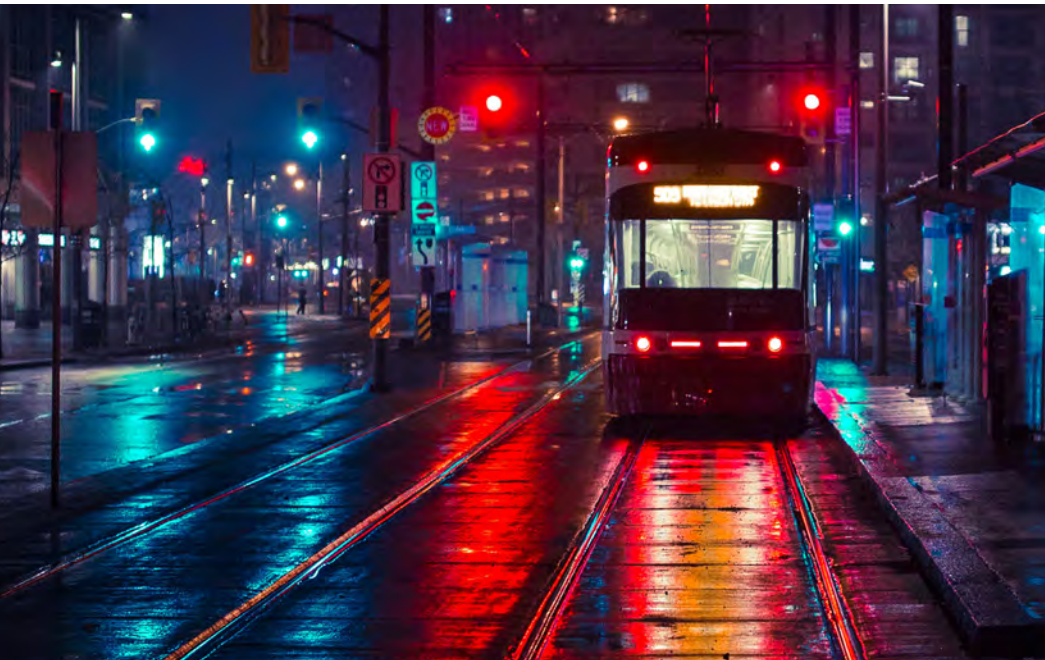

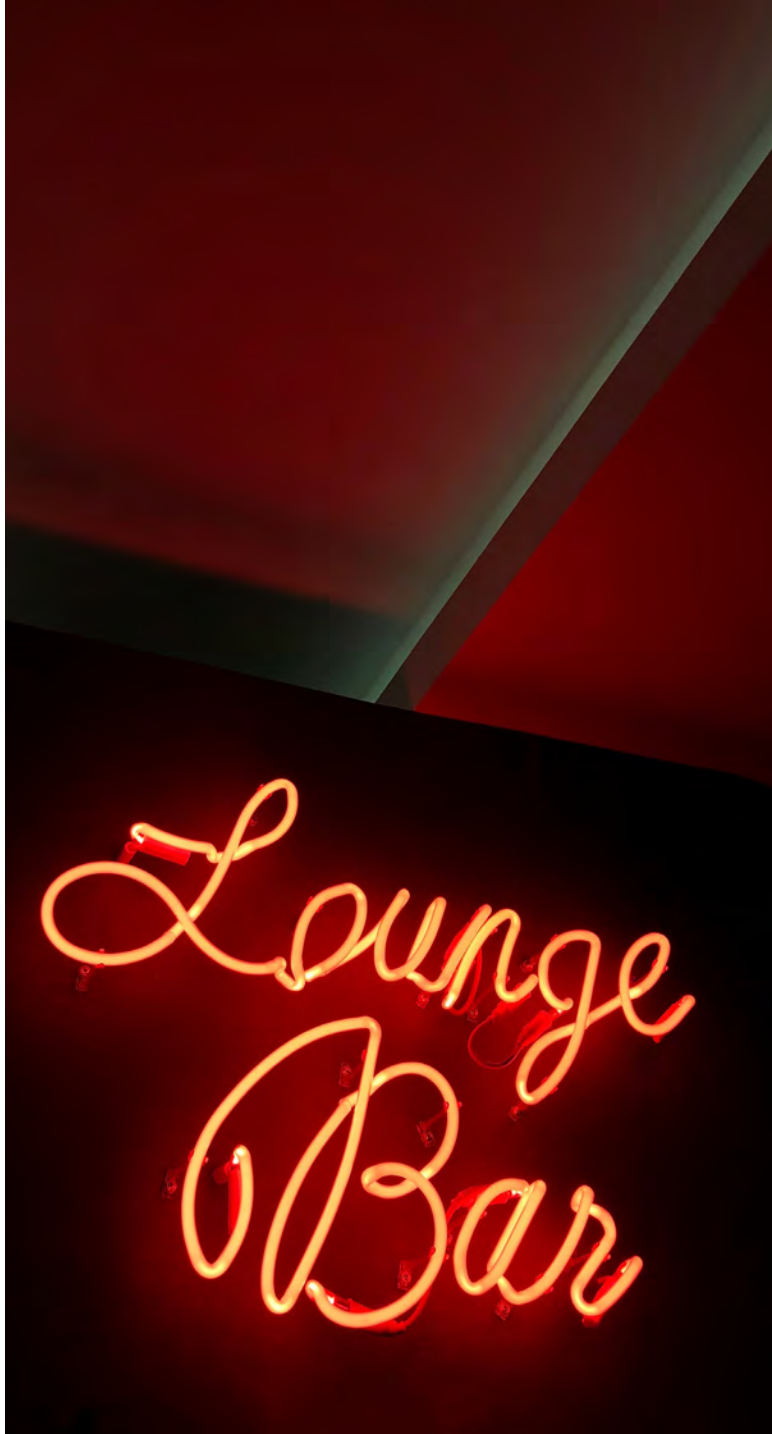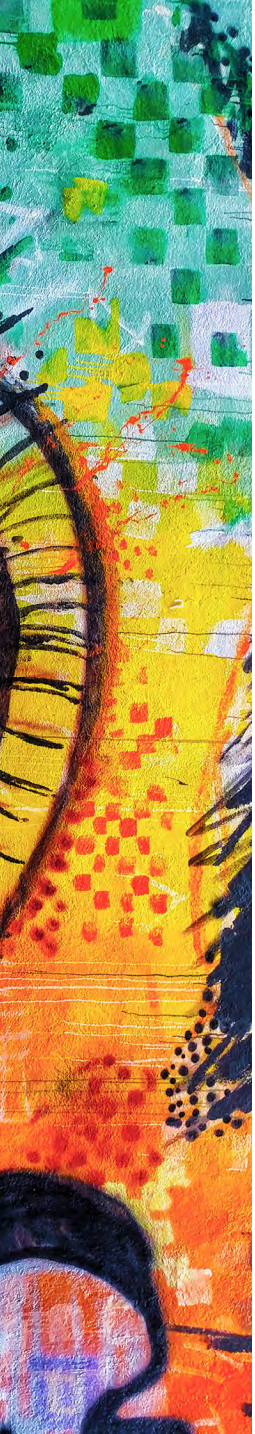

GET THE LOOK

APPLICATION

FOOD

DINE

Providing a warm and precise circle of light over dining tables, with four mounting options, including track, the Dine series enhances visual comfort in hospitality projects.



SIGMA

The SIGMA 2 deep recessed model is specifically designed for low-glare and quieter ceilings. It is available in both round and square, black and white trims, and a choice of reflector options to light up the dining experience.



LED TAPE LIGHT

Provide a glow of light under bar shelves, or as subtle accents around the restaurant.



TEARDROP SERIES

The unique body shape, wide range of color temperature options, and accessories allow for greater control to set the mood for your commercial space with up to 3000 lumens.



