







circular conduc. terminal TA1.4 6 AWG...350 kcmil 3 units accessory for:
3VA61/62



Model		
product brand name	SETRON	
product designation	Circular conductor terminal 1 cable 3 units	
accessories	Wire connector	
General technical data		
designation / of the terminal	TA1.4	
type of electrical connection / with control wire tap	No	
Connections according IEC		
connectable conductor cross-section		
<ul style="list-style-type: none"> • for copper cable / stranded / minimum • for copper cable / stranded / maximum • for aluminum cable / stranded / minimum • for aluminum cable / stranded / maximum 	16 mm ² 185 mm ² 16 mm ² 185 mm ²	
stripped length	20 mm	
tightening torque / when using copper cables		
<ul style="list-style-type: none"> • solid • stranded • finely stranded 	16 mm ² : 15.8 Nm 16 - 35 mm ² : 15.8 Nm, 50 - 185 mm ² : 31.1 Nm 25 - 35 mm ² : 15.8 Nm 50 - 150 mm ² : 31.1 Nm	
Connections according UL		
permissible temperature / of connectable conductor / according to UL 486A-486B	75 °C	
stripped length	0.8 in	
connectable conductor cross-section		
<ul style="list-style-type: none"> • for copper cable / stranded / minimum • for copper cable / stranded / maximum • for aluminum cable / stranded / minimum • for aluminum cable / stranded / maximum 	6 AWG 350 kcmil 6 AWG 350 kcmil	
tightening torque / when using copper cables		
<ul style="list-style-type: none"> • stranded 	6 - 2 AWG: 140 lb-in, 1 AWG - 350 kcmil: 275 lb-in	
Certificates		
General Product Approval	EMV	
     		
Marine / Shipping	other	Environment

Environment

[Environmental Con-
firmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3VA9243-0JB12>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3VA9243-0JB12>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3VA9243-0JB12

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

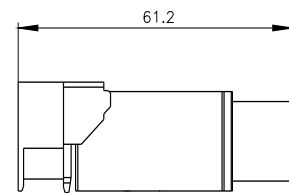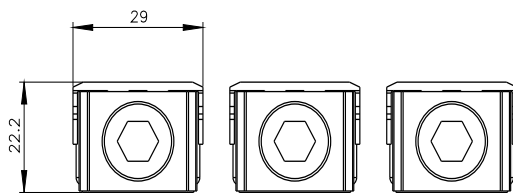

last modified:

7/5/2024 

