



6674-P0W

SureSlide Dimmer Switch for Dimmable LED, Halogen and Incandescent Bulbs

Replace a wall light switch with a SureSlide dimmer switch. 150W LED, 600W incandescent/halogen, 60Hz, single pole or 3-way installation. Can be installed with or without a neutral wire, use with Decora wallplate or Decora Plus Screwless Wallplate sold separately – White


- **CONVENIENT** – An easy way to create a big impact for a minimal cost and customize the light level in any room, for any occasion and in any home
- **EASY TO INSTALL** – Slim profile for easier installation. Works with existing wiring, no neutral wire required for installation
- **PRACTICAL** – Designed to dim LED bulbs. To find out which LED bulbs pair best, visit our online bulb compatibility tool by clicking the "find an LED bulb" button below
- **CUSTOMIZEABLE** – Adjustable minimum and maximum dimming range for LED bulbs to help eliminate flicker, maximize energy savings, and optimize ambiance
- **VERSATILE** – Control the lights from two locations using the 6674 in the main location and a 3-way switch (sold separately) in the second location
- **STYLISH** – Available in white, ivory, light almond, brown and black color options
- Now available in bulk pack - white color only

Color : ☐ White

UPC Code : 078477561942

Country Of Origin : China

Available Colors :

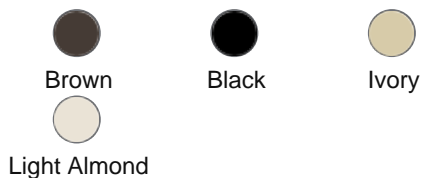

Technical Information

Product Features

Action : Standard ON/OFF

Available Colors : Ivry-I Wht-W Blk-E Brwn-B Light Almond-T

California Title 24 : Yes

Color : White

Frequency : 60 Hz

Light : None

Load Rating : 600W
Incandescent, 150W LED and CFL

Load Type : Incandescent,
Dimmable LED, Dimmable CFL

NEMA SSL 7A : Yes

Ordering Notes : White

Preset : Preset

Protection : Radio/TV Filter

Standards and Certifications : UL/CSA

Style Name : SureSlide

Switch Type : Single-Pole & 3-Way

Type : Electro-Mechanical

Voltage : 120 VAC

Wallplate : Order Separately

Warranty : 5-Year Limited

Features and Benefits

- Integrated linear full-range slide control for easy, precise operation
- Separate On/Off switch, to preserve set light level when turned off
- Slim, compact housing fits easily into a standard wall box
- Works with existing wiring, no neutral wire required for installation
- Designed to dim LED bulbs. To find out which LED bulbs pair best, visit our online bulb compatibility tool
- Adjustable minimum and maximum dimming range for LED bulbs to help eliminate flicker, maximize energy savings, and optimize ambiance
- Control the lights from two locations using the 6674 in the main location and a 3-way switch (sold separately) in the second location
- Available in white, ivory, light almond, brown and black color options

Patents *

US8664886

US9681526

This list is provided for patent marking purposes only. A good faith effort is made to maintain the accuracy and completeness of this list. No legal inference should be drawn from the omission of a patent from this list.

SPECIFICATION SUBMITTAL

JOB NAME: <input type="text"/>	CATALOG NUMBERS: <input type="text"/>	
JOB NUMBER: <input type="text"/>	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.

T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52) 5386- 1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2024 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts

© 2024 Leviton Manufacturing Co., Inc.