



# LED PAR38

## 10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

Philips LED spots with a single optic beam, provide a clean beam that's free from shadows with beam angles from 15 and 40 degrees to suit every general lighting application.

### Product data

General Information		Temperature	
Cap-Base	E26 [Single Contact Medium Screw]	Warm-up time to 60% light	0.5 s
Nominal lifetime	25,000 hour(s)	Power Factor (Fraction)	0.7
Switching Cycle	50,000	Voltage (Nom)	120 V
Lighting Technology	LED	<b>Temperature</b>	
<b>Light Technical</b>		Ambient temperature range	-40 to +45 °C
Color Code	930 [CCT of 3000K]	T-Case Maximum (Nom)	80 °C
Beam Angle (Nom)	40 degree(s)	<b>Controls and Dimming</b>	
Luminous Flux	1,000 lm	Dimmable	Only with specific dimmers
Luminous Intensity (Nom)	1,900 cd	<b>Mechanical and Housing</b>	
Luminous Efficacy (rated) (Nom)	100 lm/W	Bulb Finish	Clear
Color Designation	White (WH)	Bulb Material	Plastic
Correlated Color Temperature (Nom)	3000 K	Bulb Shape	PAR38
Color Consistency	<4	UL Wet/ damp/ dry location	Wet location
Color rendering index (CRI)	90	<b>Approval and Application</b>	
LLMF At End Of Nominal Lifetime (Nom)	70 %	Suitable For Accent Lighting	Yes
<b>Operating and Electrical</b>		EU RoHS compliant	Yes
Input Frequency	60 Hz	T20 compliant	Yes
Power Consumption	10 W		
Lamp Current (Nom)	120 mA		
Wattage Equivalent	90 W		
Starting Time (Nom)	0.5 s		

# LED PAR38

## Application Conditions


can it be used in closed luminaires Yes

## Product Data

Order product name	10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB
Full product name	10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB
Order code	929003738204


Material Nr. (12NC)	929003738204
Numerator - Quantity Per Pack	1
Net Weight (Piece)	0.130 kg
EAN/UPC - Product/Case	046677586249
Numerator - Packs per outer box	6
EAN/UPC - Case	50046677586244

## Dimensional drawing

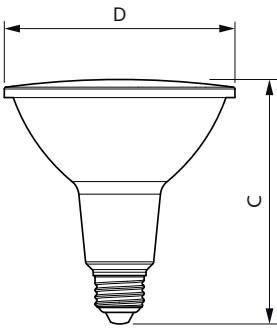


Product	D	C
10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB	123 mm	129 mm

## Photometric data

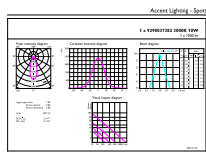

Spotlight Performance 111 Photo Lighting 2.0 Page 117


Accent Lighting Spots - 10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

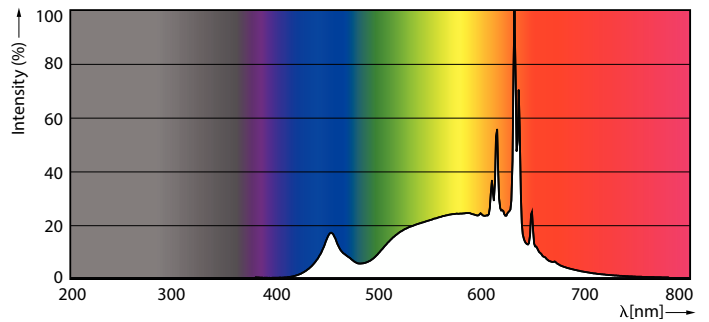

Spectral Power Distribution Colour -  
10PAR38/COR/930/F40/DIM/P/ULW/T20 6/1FB

# LED PAR38

## Photometric data

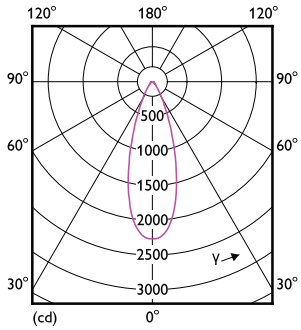

Light Distribution Diagram - 10PAR38/COR/930/F40/DIM/P/ULW/T20  
6/1FB

## Lifetime



Life Expectancy Diagram



Lumen Maintenance Diagram - 10PAR38/COR/930/F40/DIM/P/ULW/T20  
6/1FB

