


HUBBELL Premise Wiring

Net Select, Module, 6-Way Coax, 2.3GHz, Plastic

By Hubbell Premise Wiring
Catalog # [NSOVM62G](#)

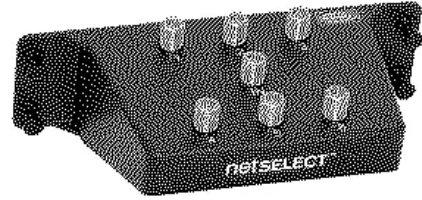

Net Select, Module, 6-Way Coax, 2.3GHz, Plastic.

Application

CATV

General

Catalog Number	NSOVM62G
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Enclosure Type	Integral
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	6-Way Coax, 2.3GHz
Material - Mounting Hardware Specifications	Screw Mounting <ul style="list-style-type: none">• Dimensions - 6.47 in. W x 2.09 in. H x 3.20 in. D• Material - High impact plastic
Style	Coaxial Splitter
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact
Type	Coaxial Splitter
UPC	883778504396

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	Plug-In
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">• RoHS Compliant• UL and cUL Listed
----------------------	--

Logistics

Carton Quantity 10

Product Assets

[Catalog Page - PREM V8 CatalogPage](#)
[Catalog Page - PREM S8 CatalogPage](#)
[Catalogs - Premise Wiring Catalog](#)
[Specifications - NSOVM62G Specification Sheet French](#)