



Southwire™

TOOLS & EQUIPMENT

PRE-FAB CATALOG



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

SOUTHWIRETOOLS.COM

OUR STORY

For over 60 years, Southwire has provided high quality electrical wire and cable to the commercial and industrial construction industries. Now, the name you trust provides durable, cutting-edge professional grade tools, designed with safety and productivity in mind. Look to Southwire® for solutions to all your electrical needs, from electrician's hand tools, meters, contractor equipment, temporary power, and extension cords.

SOUTHWIRE, THE COMPANY

Southwire Company, LLC is North America's leading manufacturer of wire and cable used in the distribution and transmission of electricity. Throughout its history, our company has sought to help provide power through our products, our service and by helping empower our customers, employees, and communities.

SOUTHWIRE, THE PEOPLE

With more than 6,800 people at customer service centers, manufacturing facilities and sales offices throughout North America, we are dedicated to developing the highest-quality products and legendary service.

THE DRIVE FOR EXCELLENCE

Driving for excellence starts with being responsive to our customers and the markets we serve. By creating business units, Southwire Company enables each to foster an entrepreneurial spirit, innovative solutions, and responsiveness required in today's business. At the same time each division can leverage the resources and rich history of Southwire Company as a whole.

THE PRODUCTS

To be successful requires products that give you solutions no matter what stage of the project cycle you are in. Our product teams and dedicated resources work together to listen to and work with our customers, creating solutions that deliver unparalleled value through product innovation, safety and efficiency.

THE SERVICE

Service is more than a word or a phone number; it's a tangible support system that assists you through the entire project cycle. Starting with our own knowledgeable customer service team, to our National Field Sales team, and our District Merchandising Specialists. In the office or in the field, we're there to lend a hand, just when you need it most. Feel free to reach us at 1-855-SWTTOOLS (855-798-6657)



TABLE OF CONTENTS

GARVIN

Conduit Boxes.....	6
Covers & Device Rings.....	22
Fittings.....	29
Hanging & Support	41
Low Voltage	48

CONDUIT BENDING

BEND ^{MAX} ™ Power Bender & BEND ^{station} ™ Common Cart Work Station.....	51
---	----

HOLE MAKING

Knockouts.....	53
----------------	----

MATERIAL HANDLING

Wire Wagon® & Mac Rack™	59
Stor Mac™	60

HAND TOOLS

Seatek™ Series & Hand Benders	63
-------------------------------------	----

DCN

DCN.....	66
----------	----

SIMP^{ush}™ FITTINGS

Rigid, EMT, PVC, and Liquid Tight.....	69
--	----

READY 2 HANG

Ready 2 Hang	71
--------------------	----

GARVIN

Garvin, A Southwire Business, manufactures to have complete control over the design and quality of the products. Recognized for continually designing innovative, labor saving products, and custom design.

- Electrical Junction Boxes
- Covers and Device Rings
- Hanging and Support
- Fittings
- Panel and Pulling
- Lighting
- Low Voltage
- Stainless Steel Products
- Customization
- Custom Painting



GARVIN



***INNOVATIVE LABOR
SAVING PRODUCT***

***NO OTHER MANUFACTURER
PRODUCES THIS PRODUCT***

CONDUIT BOXES

DATA CABLE BOX – RED

72181-DTARED



3" Deep Boxes

- K.O.s sides: (2) ½" & ¾", (2) 1" & 1¼", (2) 1", 1¼" & 1½" & 2"
- K.O.s bottom: (2) ½" & concentric (2) ¾" & 1"
- 3-screw ground hump
- Std. Pkg: 10

DATA CABLE BOX

72181-DTA



3" Deep Boxes

- K.O.s sides: (2) ½" & ¾", (2) 1" & 1¼", (2) 1", 1¼" & 1½" & 2"
- K.O.s bottom: (2) ½" & concentric (2) ¾" & 1"
- 3-screw ground hump
- Std. Pkg: 10

DATA CABLE BOX

72181-DTAB



3" Deep Boxes

- K.O.s sides: All concentric (2) ½" & ¾", (2) 1" & 1¼", (2) 1", 1¼", 1½" & 2"
- K.O.s bottom: (2) ½" & concentric (2) ¾" & 1"
- 3-screw ground hump & angle bracket
- Std. Pkg: 10

CONDUIT BOXES

1/2" & 3/4" K.O.S WITH HINGED DEVICE RING MOUNTING PLATE



PART #	DESCRIPTION	FAR SIDE STANDOFF	STD. PKG.
5PF5075	1/2" & 3/4" K.O.s Hinged plate accepts any 4" square cover or device ring	3-1/2"	10

1/2" & 3/4" K.O.S BRACKET BOX WITH HINGED DEVICE RING MOUNTING PLATE



PART #	BRACKET	DESCRIPTION	FAR SIDE STANDOFF	STD. PKG.
5PF5075AB	AB Vertical Angle	1/2" & 3/4" K.O.s. with angle bracket for stud walls, hinged plate accepts any 4" square cover or device ring	3-1/2"	4

1/2" & 3/4" K.O.S WITH HINGED BLANK COVER



PART #	BRACKET	DESCRIPTION	STD. PKG.
HP-0000	None	1/2" & 3/4" K.O.s Flat blank cover on hinged door	25

GARVIN | CONDUIT BOXES

CONDUIT BOXES

1/2" & 3/4" K.O.S WITH HINGED ONE-GANG DEVICE RING



PART #	FOR K.O. OPENING	STD. PKG.
HP-100	Flat	25
HP-125	1/4"	25
HP-150	1/2"	50
HP-158	5/8"	50
HP-175	3/4"	25
HP-1100	1"	25
HP-1125	1-1/4"	25
HP-1150	1-1/2"	25
HP-1200	2"	25

1/2" & 3/4" K.O.S WITH HINGED ONE-GANG ADJUSTABLE-DEPTH DEVICE RING



PART #	ADJUSTABLE DEPTH	DESCRIPTION	STD. PKG.
HP-AMR158	5/8"-1-1/4"	Device ring adjusts to wall depth, door opens for quick connect	25
HP-AMR1	3/4"-1-1/2"		25

GARVIN | CONDUIT BOXES

CONDUIT BOXES

1/2" & 3/4" K.O.S HINGED ONE-GANG DEVICE RING & ANGLE BRACKET



PART #	FOR K.O. OPENING	STD. PKG.
HPAB-100	Flat	25
HPAB-125	1/4"	25
HPAB-150	1/2"	25
HPAB-158	5/8"	25
HPAB-175	3/4"	25
HPAB-1100	1"	25
HPAB-1125	1-1/4"	25
HPAB-1150	1-1/2"	25
HPAB-1200	2"	25

1/2" & 3/4" K.O.S HINGED ONE-GANG ADJUSTABLE DEPTH DEVICE RING & ANGLE BRACKET



PART #	ADJUSTABLE DEPTH	STD. PKG.
HPAB-AMR158	5/8"-1-1/4"	25
HPAB-AMR1	3/4"-1-1/2"	25

CONDUIT BOXES

1/2" & 3/4" K.O.S WITH HINGED TWO-GANG DEVICE RING



PART #	FOR K.O. OPENING	STD. PKG.
HP-200	Flat	25
HP-225	1/4"	25
HP-250	1/2"	25
HP-258	5/8"	25
HP-275	3/4"	25
HP-2100	1"	25
HP-2125	1-1/4"	25
HP-2150	1-1/2"	25
HP-2200	2"	25

1/2" & 3/4" K.O.S HINGED TWO-GANG ADJUSTABLE-DEPTH DEVICE RING



PART #	ADJUSTABLE DEPTH	STD. PKG.
HP-AMR2	3/4"-1-1/2"	25

CONDUIT BOXES

1/2" & 3/4" K.O.S HINGED TWO-GANG DEVICE RING & ANGLE BRACKET



PART #	FOR K.O. OPENING	STD. PKG.
HPAB-200	Flat	25
HPAB-225	1/4"	25
HPAB-250	1/2"	25
HPAB-258	5/8"	25
HPAB-275	3/4"	25
HPAB-2100	1"	25
HPAB-2125	1-1/4"	25
HPAB-2150	1-1/2"	25
HPAB-2200	2"	25

1/2" & 3/4" K.O.S WITH HINGED INDUSTRIAL COVER



PART #	DEVICES	STD. PKG.
HP1933	(2) Single Receptacles, 1.406" Diameter	10
HP1936	(2) Toggle	10
HP1937	Toggle/Single Receptacle, 1.406" Diameter	10
HP1939	(2) Duplex	10
HP1940	Duplex/Single Receptacle, 1.406" Diameter	10
HP1941	Toggle/Duplex	10
HP1948	Toggle/GFCI	10
HP1950	(2) GFCI/DECOR	10
HP1951	Duplex/GFCI	10
HP1952	GFCI/Single Receptacle, 1.406" Diameter	10

GARVIN | CONDUIT BOXES

CONDUIT BOXES

1/2" & 3/4" K.O.S WITH HINGED TWO-GANG ADJUSTABLE-DEPTH DEVICE RING & ANGLE BRACKET



PART #	ADJUSTABLE DEPTH	STD. PKG.
HPAB-AMR2	3/4"-1-1/2"	25


1/2" & 3/4" K.O.S WITH HINGED INDUSTRIAL COVER



PART #	DEVICES	STD. PKG.
HP1929	Blank/No Device	10
HP1930	1/2" Knockout	10
HP1932	Single Receptacle, 1.406" Diameter	10
HP1934	30-50 Amp, 2.10" Diameter	10
HP1935	Toggle	10
HP1938	Duplex	10
HP1942	20 Amp, 1.594" Diameter	10
HP1943	30 Amp, 1.719" Diameter	10
HP1944	30 Amp, 2.141" Diameter	10
HP1947	GFCI/DECOR	10
HP1949	30-60 Amp, 2.437" Diameter	10

CONDUIT BOXES

GREEN GROUNDING PIGTAILS

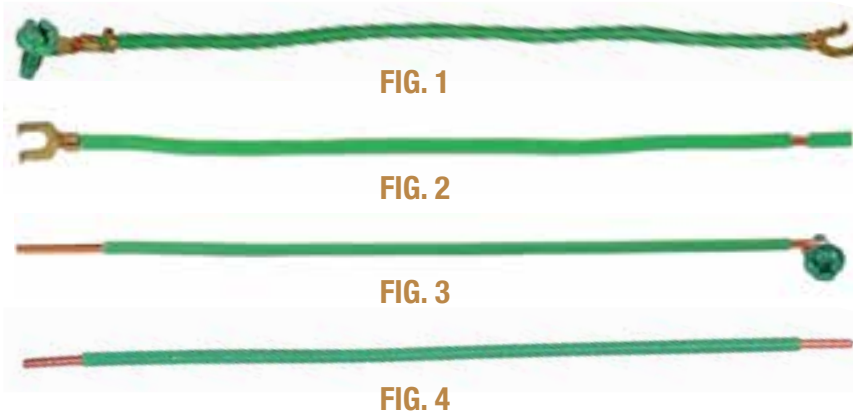

PART #	FIG	WIRE SIZE	WIRE TYPE	OVERALL LENGTH	ATTACHMENT	STD. PKG
PTST14GN	1	14 Gauge	Stranded	8"	Flanged Spade Terminal & Captive 10-32 Green Screw	100
PTST12GN	1	12 Gauge	Stranded	8"	Flanged Spade Terminal & Captive 10-32 Green Screw	100
PTST12GN-NGS	2	12 Gauge	Stranded	8"	Flanged Spade Terminal & Prestripped 5/8"	100
PTS014GN	3	14 Gauge	Solid	8"	Captive 10-32 Green Screw & Stripped 5/8"	100
PTS012GN	3	12 Gauge	Solid	8"	Captive 10-32 Green Screw & Stripped 5/8"	100
PTS012GN-S	4	12 Gauge	Solid	8"	Stripped 5/8" on both ends	100
PTS012GN-10	5	12 Gauge	Solid	10"	Captive 10-32 Green Screw & Stripped 5/8"	100


GARVIN | CONDUIT BOXES

CONDUIT BOXES

POWER PIGTAIL LEADS



STRANDED WIRE

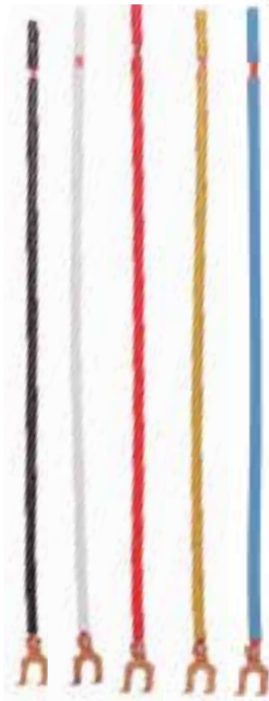

- Overall lead length: 8"
- Std. Pkg: 100


14 GAUGE STRANDED WIRE

PART #	COLOR	ATTACHMENT
PTST14BK	Black	Flanged Spade Terminal & Prestripped 5/8"
PTST14WH	White	
PTST14RD	Red	
PTST14YE	Yellow	
PTST14BU	Blue	

12 GAUGE STRANDED WIRE

PART #	COLOR	ATTACHMENT
PTST12BK	Black	Flanged Spade Terminal & Prestripped 5/8"
PTST12WH	White	
PTST12RD	Red	
PTST12YE	Yellow	
PTST12BU	Blue	

SOLID WIRE

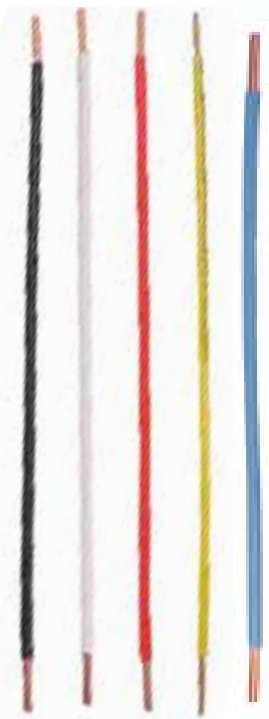

14 GAUGE SOLID WIRE

PART #	COLOR	ATTACHMENT
PTS014BK	Black	Both Ends Prestripped 5/8"
PTS014WH	White	
PTS014RD	Red	
PTS014YE	Yellow	
PTS014BU	Blue	

12 GAUGE SOLID WIRE

PART #	COLOR	ATTACHMENT
PTS012BK	Black	Both Ends Prestripped 5/8"
PTS012WH	White	
PTS012RD	Red	
PTS012YE	Yellow	
PTS012BU	Blue	

CONDUIT BOXES

GREEN GROUND SCREW

GS



- Size/thread: 10-32
- Length: 3/8"
- Style: Combo Phillips/slotted hex washer head
- Std. Pkg: 100

SELF-TAPPING GREEN GROUND SCREW

GS



- Self-drilling & tapping
- Size/thread: 10-32
- Length: 3/4"
- Style: Combo Phillips/slotted hex washer head
- Std. Pkg: 100

GROUND-WIRE CLIP

GC



- Snaps onto box edge
- Length: 1/4"
- Std. Pkg: 100

CONDUIT BOXES

KNOCKOUT REDUCING WASHERS



- Galvanized steel

PART #	FOR K.O. OPENING		STD. PKG.
	FROM	TO	
RW-7550	3/4"	1/2"	100
RW-10050	1"	1/2"	100
RW-10075	1"	3/4"	100
RW-12550	1-1/4"	1/2"	50
RW-12575	1-1/4"	3/4"	50
RW-125100	1-1/4"	1"	50
RW-15050	1-1/2"	1/2"	50
RW-15075	1-1/2"	3/4"	50
RW-150100	1-1/2"	1"	50
RW-150125	1-1/2"	1-1/4"	50
RW-20050	2"	1/2"	50
RW-20075	2"	3/4"	50
RW-200100	2"	1"	50
RW-200125	2"	1-1/4"	50
RW-200150	2"	1-1/2"	50
RW-25050	2-1/2"	1/2"	50
RW-25075	2-1/2"	3/4"	50
RW-250100	2-1/2"	1"	50
RW-250125	2-1/2"	1-1/4"	50
RW-250150	2-1/2"	1-1/2"	50
RW-250200	2-1/2"	2"	50
RW-30050	3"	1/2"	25
RW-30075	3"	3/4"	25
RW-300100	3"	1"	25
RW-300125	3"	1-1/4"	25

CONTINUE ON NEXT PAGE

CONDUIT BOXES

KNOCKOUT REDUCING WASHERS



- Galvanized steel

PART #	FOR K.O. OPENING		STD. PKG.
	FROM	TO	
RW-300150	3"	1-1/2"	25
RW-300200	3"	2"	25
RW-300250	3"	2-1/2"	25
RW-35050	3-1/2"	1/2"	25
RW-35075	3-1/2"	3/4"	25
RW-350100	3-1/2"	1"	25
RW-350125	3-1/2"	1-1/4"	25
RW-350150	3-1/2"	1-1/2"	25
RW-350200	3-1/2"	2"	25
RW-350250	3-1/2"	2-1/2"	25
RW-350300	3-1/2"	3"	25
RW-40050	4"	1/2"	10
RW-40075	4"	3/4"	10
RW-400100	4"	1"	10
RW-400125	4"	1-1/4"	10
RW-400150	4"	1-1/2"	10
RW-400200	4"	2"	10
RW-400250	4"	2-1/2"	10
RW-400300	4"	3"	10
RW-400350	4"	3-1/2"	10
RW-500400	5"	4"	1
RW-600400	6"	4"	1

CONDUIT BOXES

KNOCKOUT SEALS



- Galvanized steel

PART #	SIZE	STD. PKG.
KOS-50	1/2"	50
KOS-75	3/4"	50
KOS-100	1"	50
KOS-125	1-1/4"	10
KOS150	1-1/2"	10
KOS-200	2"	10
KOS-250*	2-1/2"	10
KOS-300*	3"	10
KOS-350*	3-1/2"	10
KOS-400*	4"	10
KOS-500*	5"	10
KOS-600*	6"	10

*Not UL Listed

AIR-TIGHT PLENUM KNOCKOUT SEALS



- Galvanized steel
- Gasketed
- Slide in for air-tight seal

PART #	SIZE	STD. PKG.
KOS-50-VT	1/2"	10
KOS-75-VT	3/4"	10
KOS-100-VT	1"	10
KOS-125-VT	1-1/4"	5
KOS150-VT	1-1/2"	5
KOS-200-VT	2"	5
KOS-250-VT*	2-1/2"	5
KOS-300-VT*	3"	5
KOS-350-VT*	3-1/2"	5
KOS-400-VT*	4"	5
KOS-500-VT*	5"	5
KOS-600-VT*	6"	5

*Not UL Listed

CONDUIT BOXES

OIL-TIGHT KNOCKOUT SEALS



- Galvanized steel
- Gasketed

PART #	SIZE	STD. PKG.
KOS-50-OT	1/2"	50
KOS-75-OT	3/4"	50
KOS-100-OT	1"	50
KOS-125-OT	1-1/4"	10
KOS150-OT	1-1/2"	10
KOS-200-OT	2"	10
KOS-250-OT*	2-1/2"	10
KOS-300-OT*	3"	10
KOS-350-OT*	3-1/2"	10
KOS-400-OT*	4"	10

*Not UL Listed

STAINLESS STEEL OIL-TIGHT KNOCKOUT SEALS



- 316 Stainless steel
- Gasketed

PART #	SIZE	STD. PKG.
KOS-50-OTSS	1/2"	50
KOS-75-OTSS	3/4"	50
KOS-100-OTSS	1"	50
KOS-125-OTSS	1-1/4"	10
KOS150-OTSS	1-1/2"	10
KOS-200-OTSS	2"	10
KOS-250-OTSS	2-1/2"	10
KOS-300-OTSS	3"	10
KOS-350-OTSS	3-1/2"	10
KOS-400-OTSS	4"	10

CONDUIT BOXES

PLASTIC KNOCKOUT INSULATING BUSHING



- Snaps in box K.O. hole
- Protects low-voltage wiring from sharp box edges

PART #	FOR K.O. OPENING	STD. PKG.
KOB-50	1/2"	50
KOB-75	3/4"	50
KOB-100	1"	50
KOB-125	1-1/4"	25
KOB-150	1-1/2"	25

PLASTIC KNOCKOUT BUSHING STAR CONFIGURATION



- Snaps in box K.O. hole
- Slits allow easy pull-through
- Protects cable from sharp box edges

PART #	BOX K.O.	STD. PKG.
KOBS-50	1/2"	50
KOBS-75	3/4"	50

RUBBER KNOCKOUT BUSHING

KOBR-50



- Fits: 1/2" K.O. opening
- Protects low-voltage wiring from sharp box edges
- Std. Pkg: 50

CONDUIT BOXES

UNIVERSAL BREAKER LOCKS

UBL1



- U.S. Patent: 8,598,477
- Std. Pkg: 25
- Locks any one-pole breaker



UBL1-RED



PART #	COLOR	ATTACHMENT
UBL1	Plated	Bryant, Cutler Hammer, General Electric, ITE Siemens, Square-D, Zinsco, Westinghouse, T&B, Challenger, Eaton & many more
UBL1-UPC	Plated	
UBL1-RED	Red	
UBL1-BLU	Blue	

UBL1-BLU



UBL1-UPC



UBL1-UPC (5-Pack)



FIRE-STOP PUTTY PAD

FSPAD



- Size: 7" x 7" x 1/8"
- Std. Pkg: 1

COVERS & DEVICE RINGS

ADJUSTABLE-DEPTH ONE-GANG DEVICE RINGS



- Std. Pkg: 25



PART #	ADJUSTABLE DEPTH
AMR158	5/8" to 1-1/4"
KOBS-75	3/4" to 1-1/2" Raised

ADJUSTABLE-DEPTH TWO-GANG DEVICE RING



- Telescoping ring adjusts to finished wall depth
- Std. Pkg: 25



PART #	ADJUSTABLE DEPTH
AMR2	3/4" to 1-1/2" Raised

SQUARE-TO-ROUND ADJUSTABLE-DEPTH DEVICE RING



- Telescoping ring adjusts to finished wall depth
- Std. Pkg: 25

PART #	ADJUSTABLE DEPTH
AMR0	3/4" to 1-1/2" Raised

COVERS & DEVICE RINGS

ADJUSTABLE-DEPTH ONE-GANG DEVICE RING

AMR111B



- Telescoping ring adjusts 3/4" to 1 1/2"
- Std. Pkg: 10

ADJUSTABLE-DEPTH TWO-GANG DEVICE RING

AMR211B



- Telescoping ring adjusts 3/4" to 1 1/2"
- Std. Pkg: 10

SQUARE-TO-ROUND ADJUSTABLE DEPTH DEVICE RING



- Telescoping ring adjusts to finished wall depth
- Std. Pkg: 10



PART #	ADJUSTABLE DEPTH
AMR011B	3/4" to 1-1/2" Raised

GARVIN | COVERS & DEVICE RINGS

COVERS & DEVICE RINGS

ONE-GANG ADJUSTABLE-DEPTH DEVICE RING



- Telescoping ring adjusts to finished wall depth
- Std. Pkg: 10



PART #	ADJUSTABLE DEPTH
61AMR-158	5/8" to 1-1/4" Raised
61AMR-1	3/4" to 1-1/2" Raised

ONE-GANG ADJUSTABLE-DEPTH DEVICE RING



PART #	RAISED	STD. PKG.
52AMR-2	3/4" to 1-1/2"	10

ONE-GANG ADJUSTABLE-DEPTH DEVICE RING



- Telescoping ring adjusts to finished wall depth
- Std. Pkg: 10



PART #	ADJUSTABLE DEPTH
62AMR-2	3/4" to 1-1/2" Raised

COVERS & DEVICE RINGS

THREE-GANG ADJUSTABLE-DEPTH DEVICE RING



- Telescoping ring adjusts to finished wall depth
- Std. Pkg: 10



PART #	ADJUSTABLE DEPTH
63AMR-3	3/4" to 1-1/2" Raised

ONE-GANG ADJUSTABLE-DEPTH DEVICE RING



PART #	RAISED	STD. PKG.
51AMR-158	5/8" to 1-1/4"	25
51AMR-1	3/4" to 1-1/2"	25

6" SQUARE TO 4" SQUARE CONVERSION PLATE

6CP



- Adapts 6" box to accept all 4" square covers & device rings
- NEW DESIGN! Works with adjustable-depth device rings
- Std. Pkg: 25



GARVIN | COVERS & DEVICE RINGS

COVERS & DEVICE RINGS

5" SQUARE TO 4" SQUARE CONVERSION PLATE



PART #	DESCRIPTION	STD. PKG.
5CP	Converts 5" Box to Accept 4" Square Covers	25

SQUARE-TO-OCTAGON DEVICE RING



- Converts 4" square box to 4" octagon opening
- Extra space for LED driver
- Std. Pkg: 25
- U.S. PATENT #10, 027, 099



PART #	RAISED
52C4-F	Flat
52C4-1/2	1/2"
52C4-5/8	5/8"
52C4-3/4	3/4"
52C4-1	1"
52C4-1-1/4	1-1/4"

ONE-GANG DEVICE RINGS



PART #	RAISED	STD. PKG.
5150	1/2"	25
5158	5/8"	25
5175	3/4"	25
51100	1"	25
51125	1-1/4"	25
51150	1-1/2"	25
51200	2"	25

COVERS & DEVICE RINGS

ONE-GANG SNAP-IN WIRE PROTECTOR SHIELD FOR STEEL DEVICE RINGS

WPP1



- Protects wires during drywall install
- Snaps into one-gang steel plaster rings
- Std. Pkg: 50

GANGABLE DEVICE PROTECTOR SHIELD

WPPU



- Protects toggle, duplex, decor, & GFCI devices
- Fits over pre-installed devices
- Std. Pkg: 50



GARVIN | COVERS & DEVICE RINGS

COVERS & DEVICE RINGS

DEVICE SEPARATOR PARTITIONS



- Break-off tabs for correct fit with device ring
- Std. Pkg: 50

PART #	FOR BOX DEPTH	FOR RAISED DEVICE RINGS
LVP41	1-1/2"	1/2", 3/4" & 1"
TM30B	1-1/2"	5/8", 1-1/4", 1-1/2" & 2"
SNAP100	2-1/8"	1/2", 3/4" & 1"
SNAP200	2-1/8"	5/8", 1-1/4", 1-1/2" & 2"

DEVICE SEPARATOR PARTITIONS



- For 2 1/8 deep boxes
- Break-off tabs for easy fitting
- Std. Pkg: 25

PART #	FOR RAISED DEVICE RINGS
LVP51	"Slide-In" Partition for Flat, 1/4", 1/2", 3/4" & 1" Raised Rings
LVP52	"Slide-In" Partition for 5/8", 1-1/4", 1-1/2" & 2" Raised Rings

SNAP-IN EMT CONNECTORS



1/2" TO 2"



2-1/2" TO 4"

- Snap on and twist off



NON-INSULATED

PART #	SIZE	STD. PKG.
SICN-50	1/2"	50
SICN-75	3/4"	50
SICN-100	1"	25
SICN-125	1-1/4"	25
SICN-150	1-1/2"	25
SICN-200	2"	10
SICN-250	2-1/2"	10
SICN-300	3"	5
SICN-350	3-1/2"	5
SICN-400	4"	5

INSULATED

PART #	SIZE	STD. PKG.
SICN-50I	1/2"	50
SICN-75I	3/4"	50
SICN-100I	1"	25
SICN-125I	1-1/4"	25
SICN-150I	1-1/2"	25
SICN-200I	2"	10
SICN-250I	2-1/2"	10
SICN-300I	3"	5
SICN-350I	3-1/2"	5
SICN-400I	4"	5

FITTINGS

SNAP-IN EMT COUPLINGS



1/2" TO 2"



2-1/2" TO 4"

- Snap on and twist off



PART #	SIZE	STD. PKG.
SICP-50	1/2"	50
SICP-75	3/4"	50
SICP-100	1"	25
SICP-125	1-1/4"	25
SICP-150	1-1/2"	25
SICP-200	2"	10
SICP-250	2-1/2"	10
SICP-300	3"	5
SICP-350	3-1/2"	5
SICP-400	4"	5

STEEL EMT COMPRESSION SLIP COUPLINGS



- Convenient sight hole ensures perfect placement



PART #	SIZE	STD. PKG.
CSLP-50	1/2"	50
CSLP-75	3/4"	50
CSLP-100	1"	25
CSLP-125	1-1/4"	25
CSLP-150	1-1/2"	25
CSLP-200	2"	10
CSLP-250	2-1/2"	10
CSLP-300	3"	5
CSLP-350	3-1/2"	5
CSLP-400	4"	5

SET SCREW SLIP COUPLINGS



- Convenient sight hole ensures perfect placement
- Huge labor saver



PART #	SIZE	STD. PKG.
SSLP-50	1/2"	50
SSLP-75	3/4"	50
SSLP-100	1"	50
SSLP-125	1-1/4"	25
SSLP-150	1-1/2"	25
SSLP-200	2"	10
SSLP-250	2-1/2"	10
SSLP-300	3"	10
SSLP-350	3-1/2"	10
SSLP-400	4"	5

FITTINGS

SNAP-ON EMT SETSCREW CONNECTOR



- No locknut required



PART #	SIZE	STD. PKG.
SOCN-50	1/2"	50

EMT SETSCREW VANDAL-RESISTANT CONDUIT CAPS



- Proven pipe protector



PART #	SIZE	STD. PKG.
CAPE50	1/2"	50
CAPE75	3/4"	50
CAPE100	1"	25
CAPE125	1-1/4"	25
CAPE150	1-1/2"	10
CAPE200	2"	10
CAPE250	2-1/2"	5
CAPE300	3"	5
CAPE350	3-1/2"	5
CAPE400	4"	5

VANDAL-RESISTANT RIGID CONDUIT CAPS



½" TO 4" STYLE



5" & 6" STYLE

- Proven pipe protector



PART #	SIZE	STD. PKG.
CAPR50	1/2"	50
CAPR75	3/4"	50
CAPR100	1"	25
CAPR125	1-1/4"	25
CAPR150	1-1/2"	10
CAPR200	2"	10
CAPE250	2-1/2"	5
CAPE300	3"	5
CAPE350	3-1/2"	5
CAPE400	4"	5
CAPR500	5"	1
CAPR600	6"	1

FITTINGS

BOX SPACER RIGID CONNECTORS



- Locknuts included

PART #	FITS K.O. SIZE	GAP LENGTH	STD. PKG.
BB-1/2	1/2"	0.20"	100
BB-3/4	3/4"	0.20"	50

*Not UL Listed

PREFAB BRACKET BOX SPACER CONNECTOR



- Fastest Connection for Caddy® & B-Line® Wall Brackets



PART #	FITS K.O. SIZE	GAP LENGTH	STD. PKG.
BB-1/2-1	1/2"	0.77"	100
BB-3/4-1*	3/4"	0.77"	50
BB-1-1*	1"	0.77"	50

*Not UL Listed

EXTRA-LONG BOX SPACER CONNECTOR



PART #	FITS K.O. SIZE	GAP LENGTH	STD. PKG.
BB-1/2-2	1/2"	2"	50

SPLIT PLASTIC EMT INSULATING BUSHINGS



- Wraps around existing cables

PART #	SIZE	STD. PKG.
IBS-50	1/2"	50
IBS-75	3/4"	50
IBS-100	1"	25
IBS-125	1-1/4"	25
IBS-150	1-1/2"	25
IBS-200	2"	25
IBS-250	2-1/2"	10
IBS-300	3"	10
IBS-350	3-1/2"	5
IBS-400	4"	5

PLASTIC EMT INSULATING BUSHINGS



- Solid bang-on

PART #	SIZE	STD. PKG.
IB-50	1/2"	50
IB-75	3/4"	50
IB-100	1"	25
IB-125	1-1/4"	25
IB-150	1-1/2"	25
IB-200	2"	25
IB-250	2-1/2"	10
IB-300	3"	10
IB-350	3-1/2"	5
IB-400	4"	5

FITTINGS

SNAP-IN MC CABLE CONNECTOR

EZ143102



- Snap-in cable, NO TOOLS required and snap on box
- Fits 14/3 & 10/2 cable
- Std. Pkg: 50

DOUBLE-SNAP STRAIGHT “CUT-IN” CONNECTOR

DSL38



- Snap-in cable, NO TOOLS required and snap on box
- Size 3/8"
- Std. Pkg: 50



DOUBLE-SNAP STRAIGHT CONNECTOR

DSL38



- Snap-in cable, NO TOOLS required and snap on box
- Size 3/8"
- Std. Pkg: 50



OPEN-BACK SNAP-IN DUPLEX CONNECTOR

DSL38



- Snap-in cable, NO TOOLS required and snap on box
- Size 3/8"
- Std. Pkg: 50



90° OPEN-BACK SNAP-IN CONNECTORS



- Snap-in cable, NO TOOLS required and snap on box
- Std. Pkg: 50



PART #	SIZE
DSL3890	3/8"
DSL5090	1/2"

SCREW-ON SNAP-IN CONNECTORS



- Screw-in cable, NO TOOLS required and snap on box
- Std. Pkg: 25



PART #	FLEX COND. SIZE	DESCRIPTION
SNLK-38	3/8"	Screws into the internal threads of 3/8" flexible metal conduits
SNLK-50	1/2"	Screws into the internal threads of 1/2" flexible metal conduits

SADDLE-TYPE SNAP-IN CONNECTOR

SNLK-38SD



- Clamps saddle on to the external ridges of flexible metal conduits with one screw
- Size 3/8"
- Std. Pkg: 25



FITTINGS

SETSCREW SNAP-IN CONNECTOR

SNLK-38SS



- Clamps saddle on to the external ridges of flexible metal conduits with one screw
- Size 3/8"
- Std. Pkg: 50



FAST-LOCK DUPLEX CONNECTOR

FLD-50



- Cast metal
- AL MC Interlocking (MCI) 10-3 (0.582) to 8-2 (0.650)
- Steel RWFMC, AL RWFMC, AL FMC 1/2"
- Steel AC 10-4 (0.625) to 6-3 (0.842) 3/4" 25 250
- AL AC 10-4 (0.625) to 8-4 (0.770)
- Steel MC Interlocking (MCI) 10-3 (0.594) to 6-2 (0.746)
- Size 3/8"
- Std. Pkg: 50



90° SNAP-IN SQUEEZE CONNECTORS



- Std. Pkg: 25



PART #	SIZE
SNLK-3890	3/8"
SNLK-5090	1/2"

SNAP-IN EMT CONNECTORS



Non-Insulated



Insulated

- Snap on and twist off

NON-INSULATED

PART #	SIZE	STD. PKG.
SQZ-38	3/8"	50
SQZ-50	1/2"	50
SQZ-75	3/4"	50
SQZ-100	1"	50
SQZ-125	1-1/4"	50
SQZ-150	1-1/2"	50
SQZ-200	2"	5
SQZ-250	2-1/2"	5
SQZ-300	3"	5
SQZ-350	3-1/2"	5
SQZ-400	4"	5

INSULATED

PART #	SIZE	STD. PKG.
SQZ-38I	3/8"	50
SQZ-50I	1/2"	25
SQZ-75I	3/4"	25
SQZ-100I	1"	25
SQZ-125I	1-1/4"	10
SQZ-150I	1-1/2"	10
SQZ-200I	2"	5
SQZ-250I	2-1/2"	5
SQZ-300I	3"	5
SQZ-350I	3-1/2"	5
SQZ-400I	4"	5

FITTINGS

DUPLEX SNAP-IN CONNECTOR

SNLK-38DU



- Made for two flexible metal conduits entering a single box or enclosure. One setscrew and saddle combine to securely fasten multiple conductors quickly.

- Saddle Clamp
- Size 3/8"
- Std. Pkg: 25



FAST-LOCK DUPLEX CONNECTOR



- Cast metal
- Std. Pkg: 50



GARVIN | FITTINGS

PART #	FITS BOX K.O.	SPECIAL FEATURES	STD. PKG.
FLC-50	1/2"	<ul style="list-style-type: none"> • Steel MC Interlocking (MCI) 14-2 (0.470) to 12-4 (0.520) • AL MC Interlocking (MCI) 14-2 (0.460) to 12-4 (0.590) • Steel AC 14-2 (0.454) to 12-4 (0.556) 1/2" 50 500 • AL AC 14-2 (0.485) to 12-4 (0.565) • Steel RWFMC, AL RWFMC, AL FMC 3/8" 	50
FLC-50L	1/2"	<ul style="list-style-type: none"> • AL MC Interlocking (MCI) 10-3 (0.582) to 8-2 (0.650) • Steel RWFMC, AL RWFMC, AL FMC 1/2" • Steel AC 10-4 (0.625) to 6-3 (0.842) 1/2" 50 500 • AL AC 10-4 (0.625) to 8-4 (0.770) • Steel MC Interlocking (MCI) 10-3 (0.594) to 6-2 (0.746) 	50
FLC-75L*	3/4"	<ul style="list-style-type: none"> • Steel MC Interlocking (MCI) 10-3 (0.594) to 6-2 (0.746) • AL MC Interlocking (MCI) 10-3 (0.582) to 8-2 (0.650) • Steel AC 10-4 (0.625) to 6-3 (0.842) 3/4" 25 250 • AL AC 10-4 (0.625) to 8-4 (0.770) • Steel RWFMC, AL RWFMC, AL FMC 1/2" 	50

*Not UL Listed

HANGING & SUPPORT

ADJUSTABLE-LENGTH SCREW-GUN BRACKETS



- Galvanized steel

PART #	ADJUSTABLE LENGTH	BOX DEPTHS	STD. PKG.
BHA16	11"-18"	1-1/2"-2-1/8"	50
BHAD16*		3"-3-1/2"	50
BHA24	17"-26"	1-1/2"-2-1/8"	50
BHAD24*		3"-3-1/2"	50

*Not UL Listed

BOX MOUNTING SLIDER BRACKET



- Galvanized steel
- Device ring secures bracket to box
- Box not included



PART #	ADJUSTABLE LENGTH	BOX DEPTHS	STD. PKG.
BMB16SL*	4", 4-11/16"	16"	50
BMB616SL	6"	16"	50

*Not UL Listed

ADJUSTABLE BAR HANGERS




- Galvanized steel

PART #	STUD SPAN	MOUNTING	STD. PKG.
BHA1C	16"-24"	Box-Lock Clip	50
BHA1		Box-Lock Clip & Threaded Stud	50

*Not UL Listed

HANGING & SUPPORT

BOX MOUNTING BRACKETS FOR STANDARD DEVICE RINGS

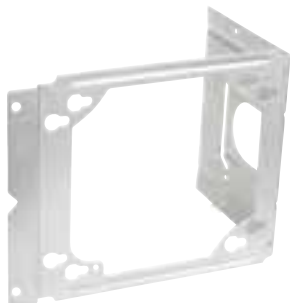

- Zinc-plated steel
- Std. Pkg: 50



PART #	FITS BOX SIZE	FAR SIDE STAND OFF
BB4-25	4" or 4-11/16" Square	2-1/2" or 3-5/8"
BB4-6	4" or 4-11/16" Square	2-1/2", 3-5/8", 5-1/2" or 6"
BB5-6*	4", 4-11/16" or 5" Square	2-1/2", 3-5/8", 5-1/2" or 6"

*Not UL Listed

BOX MOUNTING BRACKET FOR ADJUSTABLE-DEPTH DEVICE RINGS



- Zinc-plated steel
- Std. Pkg: 50

PART #	FITS BOX SIZE	SIDE STAND OFF	USE WITH
BMB1U	4" or 4-11/16" Square	2-1/2" or 3-5/8"	Adjustable-Depth Device Rings: AMR1, AMR2 & AMR0

BOX MOUNTING BRACKETS FOR STANDARD DEVICE RINGS (DUAL STANDOFFS)



- Mounts on either side of stud

PART #	FITS SQUARE BOX	FAR SIDE STAND OFF	STD. PKG.
BB4-26	4" or 4-11/16"	2-1/2" or 3-5/8"	25
BB6-26	6"	2-1/2" or 3-5/8"	50

HANGING & SUPPORT

3-POSITION BOX MOUNTING BRACKET FOR ADJUSTABLE DEPTH DEVICE RINGS



- Galvanized steel
- Std. Pkg: 25



PART #	FITS BOX SIZE	SIDE STAND OFF	USE WITH
BMB3U	4" or 4-11/16" Square	16"	Opening Works with Adjustable Depth Device Rings: AMR1, AMR2 & AMR0

3-POSITION BOX MOUNTING BRACKET FOR STANDARD DEVICE RINGS



- Galvanized steel
- Std. Pkg: 25

PART #	FITS BOX SIZE	SIDE STAND OFF	USE WITH
BMB4S3P	4" or 4-11/16"	16"	Three Box Locations, Use HC Nipples (HC- 50, HC-75, HC-100) for Prefab Wall Units

HANGING & SUPPORT

4-POSITION BOX MOUNTING BRACKET FOR STANDARD DEVICE RINGS



- Galvanized steel
- Std. Pkg: 25

PART #	FITS SQUARE BOX	STUDWALL SPACING
BMB4S4P	4" or 4-11/16"	24"

BOX FLOOR BRACKET FOR ADJUSTABLE-DEPTH DEVICE RINGS



- Galvanized steel
- Std. Pkg: 25

PART #	FITS SQUARE BOX	STUDWALL SPACING
KP18AMR	4" or 4-11/16" Square	18"

HANGING & SUPPORT

25" LONG RECESS DOWN LIGHT BRACKET



- Galvanized steel
- Std. Pkg: 25 Pairs

PART #	DESCRIPTION
BH3	25¼" Straight Bracket Mounts Architectural Recess Lights, Has Notches 24" Apart for Use on a T-Bar

24" LONG CEILING TILE SLIDER BRACKET

CTB-24



- Mounting: 4" square tabs
- Slides to any position on tile
- Std. Pkg: 20

24" LONG LOCKING CEILING TILE BRACKET

CTB-24LK



- 4 square tabs
- Locks into ceiling tile grid to secure device in place
- Prevents any shifting from vibration or seismic activity
- Std. Pkg: 20

24" LONG CEILING TILE SLIDER BRACKET/ BOX ASSEMBLY

 
CTB-244S



- 4" square box, 3-1/2" deep, 1/2" & 3/4" K.O.s
- Std. Pkg: 20

HANGING & SUPPORT

24" LONG CEILING GRID BRACKET



Box not included

- EASY snap-on design
- Std. Pkg: 50

PART #	DESCRIPTION
BHT1	24" Ceiling Grid T-Bar Bracket, Used with Boxes 1-1/2" or 2-1/8" Deep

24" LONG CEILING GRID BRACKET – HEIGHT ADJUSTABLE (0"–8")



- EASY snap-on design
- Std. Pkg: 50

PART #	DESCRIPTION
BHT1A	24" Long Ceiling Grid T-Bar Bracket, Adjustable Up To 8" Height

48" LONG CEILING GRID BRACKET – HEIGHT ADJUSTABLE (0"–8")



- EASY snap-on design
- Std. Pkg: 25
- Call for custom lengths



PART #	DESCRIPTION
BHT481A	48" Long Ceiling Grid T-Bar Bracket, Adjustable Up To 8" Height Above Ceiling Grid

HANGING & SUPPORT

HEAVY DUTY T-GRID BRACKET



- Zinc-plated steel
- Std. Pkg: 25

PART #	LENGTH	BOX DEPTH	LOAD CAPACITY	MTG. CLIP
BHT1HD	24"	1-1/2" or 2-1/8"	50 Lbs.	Yes

4" SQUARE BOX WITH 4-WAY ADJUSTABLE CEILING-GRID BRACKET



- Galvanized steel
- 4-way adjustable mounting



PART #	SIDE K.O.S BOTTOM K.O.S	BOX DEPTH	STD. PKG.
52181-VTBAR	(4) 1/2" & (2) 3/4" (3) 1/2" & (2) 3/4"	3-1/2"	10

LOW VOLTAGE

MAGNETIC FOR HEAVY CABLE BUNDLE



- Pull strength: 90 Lbs.
- Zinc-plated steel
- Std. Pkg: 50



PART #	LOOP SIZE	CAT5E CABLE CAPACITY
BRM150-HD	1-1/2"	42
BRM200-HD	2"	73
BRM400-HD	4"	250

GARVIN | LOW VOLTAGE

LOW VOLTAGE

SELF-CUTTING CABLE TIES



- Material: Nylon 6/6
- Std. Pkg: 50



PART #	LENGTH	COLOR	TENSILE STRENGTH
CT46-308UVBSC	8"	Black	50 Lbs.
CT46-308SC	8"	Natural	50 Lbs.
CT46-311UVBSC	11"	Black	50 Lbs.
CT46-311SC	11"	Natural	50 Lbs.
CT46-314UVBSC	11"	Black	50 Lbs.
CT46-314SC	11"	Natural	50 Lbs.

MAGNETIC CABLE-TIE MOUNTING BASE



- Sold in 10 Packs only
- Color: Black



PART #	FITS CABLE TIES	PULL OUT STRENGTH	STD. PKG.
CTMBK	Std. Nylon	10 Lbs.	10
CTMBVK	Velcro	30 Lbs.	10

CONDUIT BENDING

We don't just help you bend conduit, we change the way you do it. In addition to offering traditional conduit bending tools, Southwire has designed bending platforms that allow you to bend 1/2" to 2" EMT, IMC, and GRC conduit more efficiently, helping you do more work faster and stay fresh longer.

- BEND_{MAX}[™]
- BEND_{station}[™]



CONDUIT BENDING

BEND^{MAX}™ POWER BENDER

PB2000



Power Bender 3/4" - 2" EMT, IMC, GRC Conduit

- Easily adjustable to ergonomic working height
- 3/4" - 2" EMT, IMC/GRC Conduit Bender
- 2 degree leveling adjustment
- Industrial grade DC drive, and electrical components
- Push cart mounted platform
- Includes free standing conduit roller support
- Total lock casters
- Programmable spring back incorporated into digital readout
- Large analog protractor for accurate bends
- Backlit digital display
- Manual operation in the event of electronics failure

PART #	STOCK #	DESCRIPTION		
PB2000	598406	Powered Bender 3/4"- 2" EMT,IMC, GRC Conduit		
	DEPTH	WIDTH	HEIGHT	WEIGHT
PB2000	38"	30"	50"	600 lb.

BEND^{station}™ COMMON CART WORK STATION

RB1000



BEND^{station}™ COMMON CART WORK STATION

- More accurate measurements, bends, and cuts
- Measure, bend, clamp and cut at a comfortable 36" work table height for reduced labor fatigue
- Store up to 900 feet of conduit or strut dependent on size
- Extra shelf for storage of tools and materials
- Heavy duty casters for easy transportation and mobility
- Requires up to 40% less effort than other mechanical benders
- Built-in 60" ruler for quick and accurate measuring
- Eliminates the need to bend over to get a closer look at hand bends
- Speeds up the entire bending process up to 30%

PART #	STOCK #	DESCRIPTION		
RB1000	598407	BEND ^{station} ™ for 3/4" and 1" GRC and IMC		
MB1000	643069	BEND ^{station} ™ for 3/4" and 1" EMT		
	DEPTH	WIDTH	HEIGHT	WEIGHT
RB1000	69"	29"	38.5	180 lb.
MB1000	69"	29"	38.5	150 lb.

CONDUIT BENDING

HOLE MAKING

Southwire™ has developed industry leading tools for electrical contractors, including a comprehensive line of hole making solutions. With tools ranging from cutting dies to the original drill-powered knockout punch, you can make quick, accurate holes every time without the muscle or mess.

- Knockouts



MAX PUNCH® XD

MPXD



Heavy duty knockout punch driver for stainless and mild steel.

- No hydraulics, no ratcheting, no mess!
- Thread-in/thread-out removable drawstuds (universal to fit most common KO dies)
- Rated to cut 10 gauge mild and stainless steel up to 4"
- Minimum drill recommendations: 18v cordless, equivalent of 550 in. lbs. torque rated

MPXD-SD

Includes:

- MAX PUNCH® XD drive unit
- 1/2" – 2" MAX PUNCH® Pro cutting dies (rated for stainless steel)
- 2 drawstuds sizes 3/4" & 7/16"
- Marksman™ conduit layout tool
- Step drill bit (3/16" – 7/8", 2 nut drivers) (7/16")
- Heavy duty carrying case

MPXD-SD



MP-03PRO

Includes:

- 2 1/2" - 4" MAX PUNCH® Pro cutting dies
- 1 1/8" drawstud
- Heavy duty carrying case

MP-03PRO



PART #	STOCK #	DESCRIPTION		
MPXD	631597	MAX PUNCH® XD: drive unit only (no case)		
MPXD-SD	631599	MAX PUNCH® XD w/ stainless steel rated dies - 1/2" - 2" set (1 case)		
MP-03PRO	571772	MAX PUNCH® PRO STAINLESS STEEL 2 1/2" - 4" SET		
	LENGTH	WIDTH	DEPTH	WEIGHT
MPXD	5.5"	11.5"	4.25"	5.5 lb.
MPXD-SD	16.5"	8.5"	13"	14.5 lb.
MP-03PRO	16.5"	13"	5"	22.5 lb.

KNOCKOUTS

MAX PUNCH™ 360 HYDRAULIC KNOCKOUT TOOL

MP360HP

Heavy duty 12-ton hydraulic knockout with 360 degree articulation.

- Full 360 degree articulating head for tight spaces
- Lightweight aluminum head
- Compact pump with padded handle



PART #	STOCK #	DESCRIPTION		
MP360HP	591590	MAX PUNCH™ 360 DRIVE UNIT ONLY		
MP360SDPRO	589738	MAX PUNCH™ 360 STAINLESS STEEL 1/2" - 2" SET		
MP-03PRO	571772	MAX PUNCH™ PRO STAINLESS STEEL SET 2 1/2" - 4" SET		
	LENGTH	WIDTH	DEPTH	WEIGHT
MP360HP	4.5"	5.25"	3.75"	5.5 lb.
MP360SDPRO	21"	12"	4"	15 lb.
MP-03PRO	16.5"	13"	5"	22.5 lb.

MP360SDPRO



MP-03PRO



KNOCKOUTS

MAX PUNCH® STAINLESS STEEL CUPS & CUTTERS



Power Bender 3/4" - 2" EMT, IMC, GRC Conduit

- Easily adjustable to ergonomic working height
- 3/4" - 2" EMT, IMC/GRC Conduit Bender
- 2 degree leveling adjustment
- Industrial grade DC drive, and electrical components
- Push cart mounted platform
- Includes free standing conduit roller support
- Total lock casters
- Programmable spring back incorporated into digital readout
- Large analog protractor for accurate bends
- Backlit digital display
- Manual operation in the event of electronics failure

PART #	STOCK #	DESCRIPTION	CONDUIT & PIPE SIZE	HOLE SIZE ACTUAL "	MM	CAPACITY S.S. GA
MPK050PRO	571746	MAX PUNCH® Cutter for Stainless Steel 1/2"	1/2"	.89	23	10
MPC50PRO	571761	MAX PUNCH® Cup for Stainless Steel 1/2"	1/2"	.89	23	10
MPK075PRO	571747	MAX PUNCH® Cutter for Stainless Steel 3/4"	3/4"	1.12	28	10
MPC75PRO	571762	MAX PUNCH® Cup for Stainless Steel 3/4"	3/4"	.12	28	10
MPK100PRO	571748	MAX PUNCH® Cutter for Stainless Steel 1"	1"	1.36	35	10
MPC100PRO	571763	MAX PUNCH® Cup for Stainless Steel 1"	1"	1.36	35	10
MPK125PRO	571749	MAX PUNCH® Cutter for Stainless Steel 1 1/4"	1 1/4"	1.70	43	10
MPC125PRO	571764	MAX PUNCH® Cup for Stainless Steel 1 1/4"	1 1/4"	1.70	43	10
MPK150PRO	571750	MAX PUNCH® Cutter for Stainless Steel 1 1/2"	1 1/2"	1.95	50	10
MPC150PRO	571765	MAX PUNCH® Cup for Stainless Steel 1 1/2"	1 1/2"	1.95	50	10
MPK200PRO	571751	MAX PUNCH® Cutter for Stainless Steel 2"	2"	2.42	62	10
MPC200PRO	571766	MAX PUNCH® Cup for Stainless Steel 2"	2"	2.42	62	10
MPK250PRO	571753	MAX PUNCH® Cutter for Stainless Steel 2 1/2"	2 1/2"	2.92	74	10
MPC250PRO	571767	MAX PUNCH® Cup for Stainless Steel 2 1/2"	2 1/2"	2.92	74	10
MPK300PRO	571754	MAX PUNCH® Cutter for Stainless Steel 3"	3"	3.55	90	10
MPC300PRO	571768	MAX PUNCH® Cup for Stainless Steel 3"	3"	3.55	90	10
MPK350PRO	571755	MAX PUNCH® Cutter for Stainless Steel 3 1/2"	3 1/2"	4.04	103	10
MPC350PRO	571769	MAX PUNCH® Cup for Stainless Steel 3 1/2"	3 1/2"	4.04	103	10
MPK400PRO	571756	MAX PUNCH® Cutter for Stainless Steel 4"	4"	4.54	115	10
MPC400PRO	571770	MAX PUNCH® Cup for Stainless Steel 4"	4"	4.54	115	10
MP02PRO*	571771	Small Die Set 1/2"-2" in case (drive unit not included)	1/2" - 2"	.89-2.42	23-62	10
MP03PRO*	571772	MAX PUNCH® PRO STAINLESS STEEL SET 2 1/2" - 4"	2 1/2" - 4"	2.92-4.54	74-115	10

HOLE MAKING | KNOCKOUTS

KNOCKOUTS

MARKSMAN® CONDUIT LAYOUT TOOL

MM01



A conduit layout tool that will pinpoint a center knockout in seconds. The Marksman® Layout Tool also features a panel schedule showing the branch circuit number and its corresponding phase.

- Easy to use
- No math
- For KO sizes 1/2" to 4"
- Underground and overhead
- The Southwire® Marksman® conduit layout tool is constructed of tough durable anodized aluminum
- Markings are etched for maximum durability

PART #	STOCK #	DESCRIPTION			
MM01	582819	Marksman® Conduit Layout Tool			
	HEIGHT	WIDTH	DEPTH	WEIGHT	KNOCKOUT SIZES
MM01	6.5"	2"	0.25"	2.5 oz	1/2" - 4"

DRAW STUDS FOR MAX PUNCH® DRIVE UNITS

XDDS34
PRDS716
PRDS118
MPDS12



MAX PUNCH® PRO DRAW STUDS

- 3/4" - Main Draw Stud - Stock #648640 Model #XDDS34
- 7/16" - Medium Draw Stud - Stock #577179 Model #PRDS716
- 1 1/8" - Large Draw Stud (for 2 1/2" – 4" MAX PUNCH® and MAX PUNCH® PRO Dies) Stock #583061 Model #PRDS118

MAX PUNCH® DRAW STUDS

- 3/4" - Main Draw Stud - Stock #568259 Model #MPDS12

PART #	STOCK #	DESCRIPTION	LENGTH	WEIGHT	DIAMETER
XDDS34	648640	3/4" MAIN DRAW STUD MAX PUNCH® PRO	5"	8.7 oz	3/4"
PRDS716	577179	7/16" MEDIUM DRAW STUD - MAX PUNCH® PRO	4.25"	4.6 oz	7/16"-3/4"
PRDS118	583061	LARGE DRAW STUD - 1 1/8" (FOR MILD STEEL OR STAINLESS STEEL LARGE DIES)	4.4371"	15.6 oz	1 1/8"
MPDS12	568259	1/2" MAIN DRAW STUD - MAX PUNCH®	11.5"	4.4 oz	15/16"

MATERIAL HANDLING

As one of the most innovative tool lines in the industry, Southwire Tools and Equipment has provided material handling solutions that move material quickly, easily, and safely. With a product line that includes reel jacks, SIMpull™ CoilPAK™ carts, and Wire Wagon® carts, you can complete the job better than ever before while saving time and energy.

- Wire Wagon Carts
- Storage Containers



MATERIAL HANDLING

WIRE WAGON® 560

WW560



Conduit rack.

- Cart includes 6" casters
- Fast and simple collapsible design for storage and transportation
- Multipurpose conduit, pipe, and strut rack
- 1,000 lb. capacity



PART #	STOCK #	DESCRIPTION		
WW560	589868	Wire Wagon® 560		
	LENGTH	WIDTH	HEIGHT	WEIGHT
WW560	58.5"	34"	19"	140 lb.

MAC RACK I™ & MAC RACK II™

MRACK



The Mac Rack™ is a mobile jobsite conduit and pipe storage cart.

- 1,000 lbs. (450 Kg) weight capacity
- Double wall square tubing
- Eight storage sections
- Arms fold easily with plunger pins for compact storage
- Shipped assembled with 6" (150 mm) heavy duty casters
- Durable powder coat finish
- Patented stacking feature: Stack similar carts together or with other Stacking Macs
- Mac Rack II™ has a mesh deck for material storage

PART #	DESCRIPTION	ITEM #	LOAD CAPACITY
MRACKI	Mac Rack I™	783317	1000 lbs. (450 Kg)
MRACKII	Mac Rack II™	783299BRK	1000 lbs. (450 Kg)

MATERIAL HANDLING

STORAGE CONTAINERS

STOR MAC™ 60

SM60



Security storage cabinet.

- Tough steel wire mesh
- Four 6" heavy duty casters (standard)
- For high visibility storage
- Reinforced frame & door
- Removable shelves
- Lockable doors
- Load capacity 1,500 lb.

PART #	STOCK #	DESCRIPTION		
SM60	784920	STOR MAC™ 60		
	LENGTH	WIDTH	HEIGHT	WEIGHT
SM60	33.75"	63.5"	58"	345 lb.



STORAGE CONTAINERS



STORAGE CONTAINERS

STOR MAC™ 48

SM48



Security storage cabinet.

- Tough steel wire mesh
- Four 6" heavy duty casters (standard)
- For high visibility storage
- Reinforced frame & door
- Removable shelves
- Lockable doors
- Load capacity 1,500 lb.

PART #	STOCK #	DESCRIPTION		
SM48	785921	STOR MAC™ 48		
LENGTH	WIDTH	HEIGHT	WEIGHT	
SM48	33.75"	51.5"	58"	310 lb.



STOR MAC™ 30

SM30



A mobile, heavy-duty stacking container.

- Tough steel wire mesh
- Four 6" heavy duty casters (standard)
- For high visibility storage
- Reinforced frame & door
- Removable shelves
- Lockable doors
- Load capacity 1,500 lb.



PART #	STOCK #	DESCRIPTION		
SM30	785920	STOR MAC™ 30		
LENGTH	WIDTH	HEIGHT	WEIGHT	
SM30	33.75"	31.5"	58"	210 lb.

STORAGE CONTAINERS

HAND TOOLS

Your hands are your most important tools, the ones you need for every job. Equip them with high-quality, durable hand tools from Southwire. With a strong yet comfortable design and no-hassle lifetime warranty*, you can rely on these tools to make your life easier and last through years of hard work.





SEATEK™ SERIES

HAND BENDERS

ROTO-SPLIT® CUTTERS

- **RS-101** Original Roto-Split® Cutter
- **RS-101A** Super Roto-Split® Cutter
- **RS-101AC** Automatic Roto-Split® Cutter
- **MCCUT** MC Rotary Cutter

ACCESSORIES

- **LS-105** Lubricant Stick
- **101-110** Handle Kit
- **101-106** Retrofit Hardware Kit
- **101-107** Power Conversion Kit

BLADES

- **B-102** Roto-Split® Standard Blade
- **B-107** Offset Teeth Blade
- **B-108** Motorized Tool Blade



- **MCB1** 1" EMT Conduit Bender with Handle (Ductile Iron Head)
- **MCB3/4** 3/4" EMT Conduit Bender with Handle (Aluminum Head)
- **MCB1/2** 1/2" EMT Conduit Bender with Handle (Aluminum Head)


BLADES

ACCESSORIES

MCB1

MCB3/4

MCB1/2

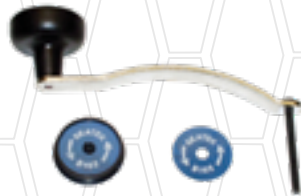

ROTO-SPLIT® CUTTERS



RS-101



RS-101A



RS-101AC

DCN

DCN, Data Center Solutions, provides customized cables to fit specific requirements with a 24 hour turn-around and an unprecedented number of receptacles, color choices, and variable lengths. Focused on developing the exact cabling solution for any environment, DCN also provides data services such as Hipot Testing, an Excel-Based Cable Builder, Load Bank Testing, and Optional Monitoring.

- MC Feeder Cables and Generator Cables
- Hipot Testing
- Excel Based Cable Builder
- Cable Labeling
- Packaging and Shipping
- Wireless Branch Circuit Monitoring & Reporting
- KoldLok® Raised Floor Airflow Management
- HotLok® Blanking Panels
- AisleLok® Aisle Airflow Management
- Circuit Breakers and Testing
- Ground Kits
- Specialized Labels







cULus LISTED

DCN Cables are UL Listed specifically for mission-critical data center environments. Our cables are manufactured with all UL Listed components as a complete UL Listed Wire Assembly. DCN Cables are not required to be secured or supported every 4.5 feet (in compliance with NEC, Article 645.5), making power distribution totally flexible and improving installation efficiency.



FAST TURN AROUND

With an available 24 hour turn around option, an unprecedented number of receptacles, color choices and variable lengths, we provide customized cables to fit your specific requirements. Our focus is developing the exact cabling solution for your environment.



CABLE LABELING

We attach a custom identification label — referencing PDU, Panel, Circuit Number, Equipment, Receptacle, Length and UL Certification — to each cable end for easy identification. These labels are secured in place with protective heat shrink. We offer optional face-plate labeling as well.

DCN CAN CREATE ANY CUSTOM CABLE AND ASSEMBLY YOU CAN IMAGINE

DCN specializes in custom cords of any kind.

- Feeder cables
- MC cables
- SO cord drop cables
- Daisy chain cables
- Custom welding and temp power cables
- OEM manufacturing support

Our team of sales engineers and technicians boast decades of experience in the field of electrical and power cable assemblies. DCN engineers are ready to assist you in the creation of a specific cable program for your project.

EASILY CUSTOMIZE YOUR ORDER WITH THE DCN CABLE BUILDER





QUALITY COMPONENTS

We use the highest quality components in the industry.

All Components are UL Listed & Tested

- UL Listed Liquid Tight with Integral Ground
- Hubbell Steel LT Connectors & Boxes
- Abrasion Resistant THHN Stranded Wire
- Hubbell Receptacles & Connectors
- Full Russell Stoll Line.



HIPOT AND LOAD BANK TESTING


HIPOT (Dielectric Withstand Voltage Test) testing is performed on every cable. Cables are HIPOT tested at twice-rated circuit voltage, plus 1500 Volts. This test ensures there will be no arcing or shorting of any conductor within the cable.

Every power whip is 100% factory tested through DCN Cables' proprietary automated testing process. Our load banks apply an electrical load that accurately mimics the max load a cable will see while in use within your data center.



INNOVATIVE CAMERA DETECTION

Our patent-pending camera detection system ensures proper wire gauge and phasing. Electronic and hard-copy test results are provided upon request.

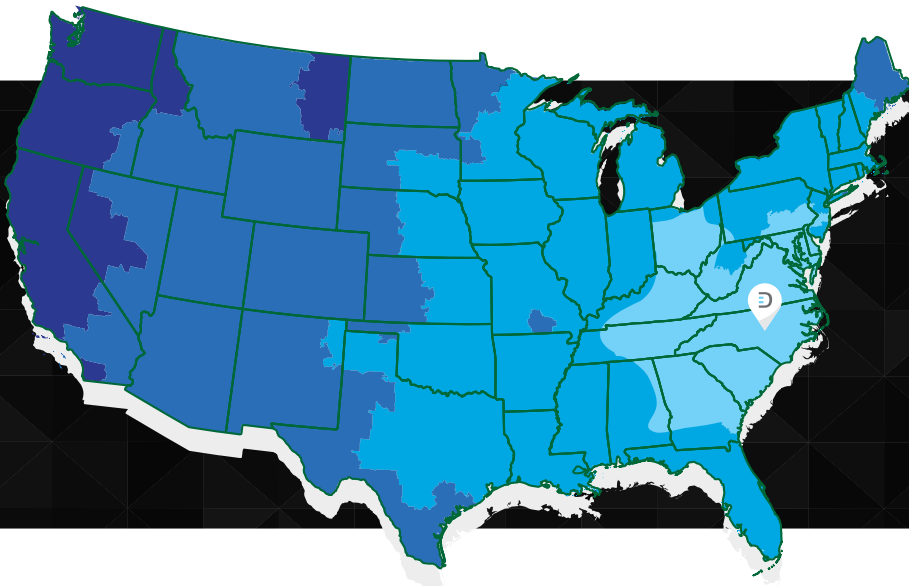

TRANSIT TIME

- 1 Day
- 2 Days
- 3 Days
- 4 Days

ADDITIONAL CABLES: MC FEEDER CABLES & GENERATOR CABLES

Our assemblies are available in custom cuts and configurations to power your mission critical facilities. Each cable is 100% tested and fully equipped to power your facility.



SIMPush™ FITTINGS

Southwire provides durable, cutting-edge, professional grade tools, designed with safety and productivity in mind.

- EMT SIMPush™ Conduit Fittings
- RIGID SIMPush™ Conduit Fittings
- Liquid Tight SIMPush™ Conduit Fittings
- PVC SIMPush™ Conduit Fittings
- SIMPush™ Removal Tools






SIMPUSH™

PUSH TO INSTALL CONDUIT FITTINGS

INSTALL CONDUIT FITTINGS FASTER

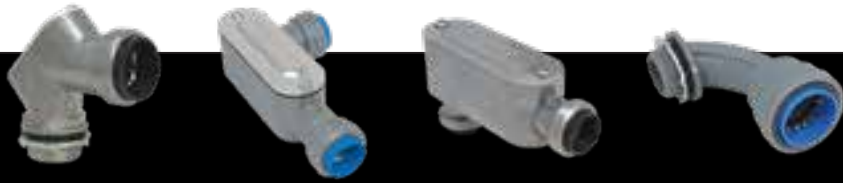

REMOVABLE AND REUSABLE WITH THE SIMPush™ REMOVAL TOOL

PUSH INSTALL RIGID

PUSH INSTALL EMT

PUSH INSTALL PVC

PUSH INSTALL LIQUID TIGHT



NEVER THREAD CONDUIT AGAIN

- » Works with RMC, IMC, and galvanized conduit
- » Works with threaded and non-threaded conduit
- » Watertight
- » Removable & reusable with SIMPush™ removal tool
- » Maintains ground
- » IP66, NEMA 3S, direct burial

AVAILABLE SIZES

1/2", 3/4", 1",
1-1/4", 1-1/2", 2"



FAST, NO TOOL INSTALLATION

- » Replaces compression and set screw fittings
- » No screws or moving parts to lose
- » Watertight couplings and connectors available
- » Removable & reusable with SIMPush™ removal tool
- » Maintains ground

AVAILABLE SIZES

1/2", 3/4", 1",
1-1/4", 1-1/2"



NO ADHESIVE NEEDED

- » Concrete tight and rated for burial
- » UV resistant resin
- » Removable & reusable with SIMPush™ removal tool
- » IP66, NEMA 3S, direct burial

AVAILABLE SIZES

1/2", 3/4", 1"



FAST PUSH ON INSTALLATION

- » Watertight, concrete tight
- » Works with FLNM-B conduit
- » Removable & reusable with SIMPush™ removal tool
- » IP66, NEMA 3S, direct burial

AVAILABLE SIZES

1/2", 3/4", 1"

READY 2 HANG

We know that unpacking lights and trash can clutter a jobsite and waste valuable time. Southwire's Ready 2 Hang program can assist you in producing a lighting layout, and prepping your lights efficient jobsite installation. We pack your lights in a bulk gaylord with minimal packaging and deliver it to you ready to hang. Need extension cords or temp power boxes to power your jobsite lighting? We can help you there too!



READY 2 HANG




READY2HANG LIGHTING PROGRAM

INCREASE YOUR LIGHTING INSTALL EFFICIENCY

BY REDUCING INSTALL TIME WITH SOUTHWIRE'S
READY2HANG LIGHTING PROGRAM.



Reduce job waste with
eliminated packaging

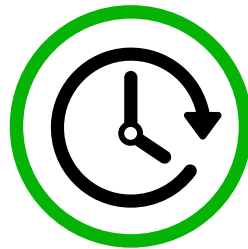

Eliminate light fixture
assembly time



Increase install speed with
custom light fixtures with
the perfect cord length



PROGRAM DETAILS

* Order minimum: 50+ pieces

Service includes:

- The Ready2Hang service does not extend lead times
- LED bulbs come fully installed to save you time
- Assembled fixtures are removed from cardboard boxes
- Safely shipped in easily removed bubble wrap packing

READY 2 HANG

READY 2 HANG



GARVIN LED JOB SITE LIGHTS


Garvin LED Job Site Lights come with a 60 Watt Corncob LED bulb and a steel cage when you need super-bright job site lighting. The Garvin LED Temp Light Lamp has an estimated 50,000 hour life which is 8 to 10 times longer than CFL or metal halide bulbs. Ready2Hang program available on any of the Garvin temporary lights listed in the chart below (Please contact your local Southwire Garvin salesperson for pricing).

PART #	UPC#	DESCRIPTION	VOLTS	WATTS	DIAMETER	HEIGHT	WEIGHT
TL60LED	785592115379	60 Watt Corncob LED Job Site Light with a Steel Cage	100-277V	60	6.75"	13"	4.05 lbs
TL80LED	785592114914	80 Watt Corncob LED Job Site Light with a Steel Cage	100-277V	80	6.75"	15.25"	4.05 lbs
TL100LED	785592115294	100 Watt Corncob LED Job Site Light with a Steel Cage	100-277V	100	6.75"	15.25"	7.5 lbs
TL150LED	785592125026	150 Watt Corncob LED Job Site Light with a Steel Cage	100-277V	150	6.75"	15.25"	4.05 lbs
TL200LED	785592127497	200 Watt Corncob LED Job Site Light with a Steel Cage	100-277V	200	6.75"	15.25"	9.4 lbs

6' and 10' cord lengths available.

MALE CORD END	FEMALE CORD END
none	none
515P-120V 15A 3 PRONG STRAIGHT BLADE	515P-120V 15A 3 PRONG STRAIGHT BLADE
L515-120V 15A TWIST LOCK	L515-120V 15A TWIST LOCK
L520-120V 20A TWIST LOCK	L520-120V 20A TWIST LOCK

*Custom cord lengths and sockets available on request

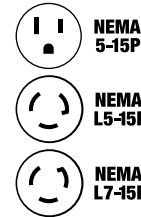

CORD OPTIONS
UP TO 50 FT. MALE OR FEMALE CORD LENGTHS
12/3, 14/3, AND 16/3 CORD GAUGE SIZES AVAILABLE



HANG-A-LIGHT

The next generation of temporary overhead lighting from Southwire is here with two new integrated LED products. These new Southwire Hang-A-Light® models are ready to be hung right out of the box, with no assembly required. As an additional convenience, you can daisy chain these products using the supplied 10 foot cord with a plug and 1 foot cord with a receptacle. Backing your investment is a 3 year warranty from Southwire.

PART #	UPC#	DESCRIPTION	VOLTS	WATTS	DIAMETER	HEIGHT	WEIGHT
T60100	32886792472	13,000 Lumen LED Overhead	120	100	6.5"	11.3"	6.5 lbs
T60150	32886792489	19,500 Lumen LED Overhead	120	150	6.5"	12.7"	7.75 lbs

READY 2 HANG

READY 2 HANG



GARVIN LED THEFT RESISTANT TEMPLIGHT

- Fits 4" octagon & square-to-round rings
- Vandal-resistant steel cage protects LED lamp from theft
- Std. Pkg: 1



PART #	WATTS	LUMENS	STD. PKG.
TLCO	9	1000	1


LIGHTING LAYOUT TOOL

We can handle your lighting layout needs!

Need a custom temporary lighting layout?

Information we need:

- Deck Height
- Width and Length of Area
- Foot Candles Required

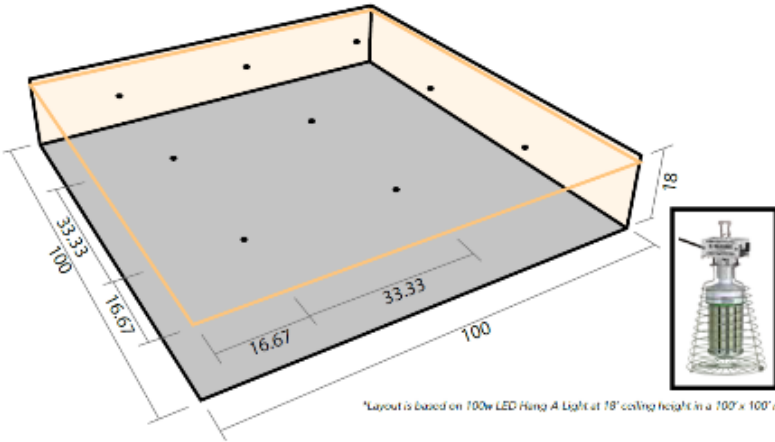

READY 2 HANG



Southwire™

TOOLS & EQUIPMENT

PRE-FAB CATALOG

GET SOCIAL WITH US:



[/SOUTHWIRETOOLS](#)
[/SOUTHWIRETOOLSLATINO](#)



[@SOUTHWIRETOOLS](#)



[@SOUTHWIRETOOLS](#)



[SOUTHWIRETOOLS](#)

[SOUTHWIRETOOLS.COM](#) | 1-855-SWTTOOLS

All Trademarks or Registered Trademarks (TM/®) are owned or licensed by Southwire Company.
Any other TM/®- Trademark or Registered Trademark of Southwire Company.



SQUILLIMORE

FOODS & BEVERAGE

PRE-FAB CATALOG